

PST 1,3/ 7-5,0

Order No.: 1933231

The figure shows a 10-position version of the product

<http://eshop.phoenixcontact.net/phoenix/treeViewClick.do?UID=1933231>Header, Nominal current: 12 A, Nom. voltage: 250 V, Pitch: 5 mm,
Number of positions: 7, Color: black, Assembly: Soldering

Commercial data

EAN	4017918918729
Pack	50 pcs.
Customs tariff	85366990
Weight/Piece	0.001301 KG
Catalog page information	Page 480 (CC-2009)

Product notes

WEEE/RoHS-compliant since:
01/01/2003

<http://www.download.phoenixcontact.com>
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

Technical data

Dimensions / positions

Length	2.8 mm
Pitch	5 mm
Dimension a	30 mm
Number of positions	7
Pin dimensions	1,3 mm

Hole diameter	1.5 mm
Technical data	
Insulating material group	IIIa
Rated surge voltage (III/3)	4 kV
Rated surge voltage (III/2)	4 kV
Rated surge voltage (II/2)	4 kV
Rated voltage (III/2)	320 V
Rated voltage (II/2)	400 V
Connection in acc. with standard	EN-VDE
Nominal current I_N	12 A (depends on the plug used)
Nominal voltage U_N	250 V
Maximum load current	12 A (depends on the plug used)
Insulating material	PA
Inflammability class acc. to UL 94	V0

Certificates / Approvals



Certification

CCA, CUL, GOST, SEV, UL

CUL


Nominal voltage U_N	300 V
Nominal current I_N	10 A

UL



Nominal voltage U_N	300 V
Nominal current I_N	10 A

Diagrams/Drawings


Drilling plan/solder pad geometry

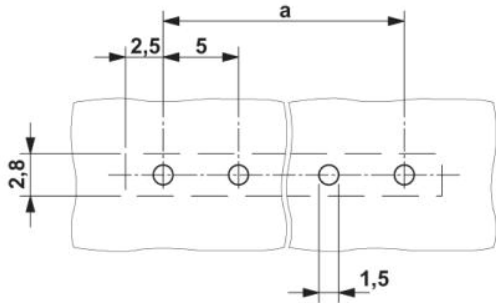

Diagram

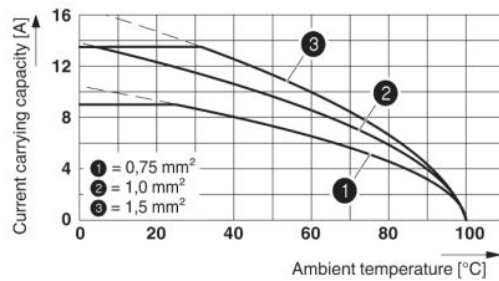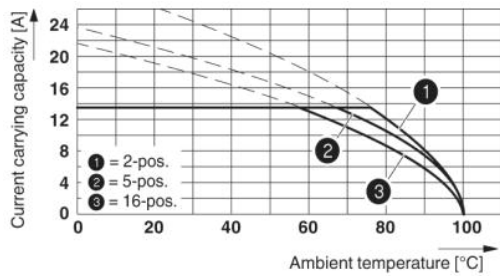

Dimensioned drawing

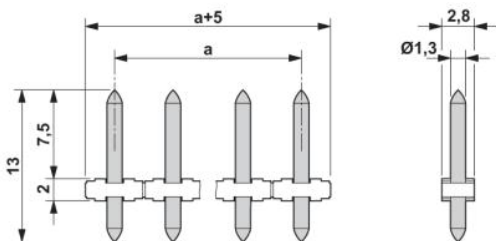

Address

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg, Germany
Phone +49 5235 3 00
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>



© 2010 Phoenix Contact
Technical modifications reserved;