


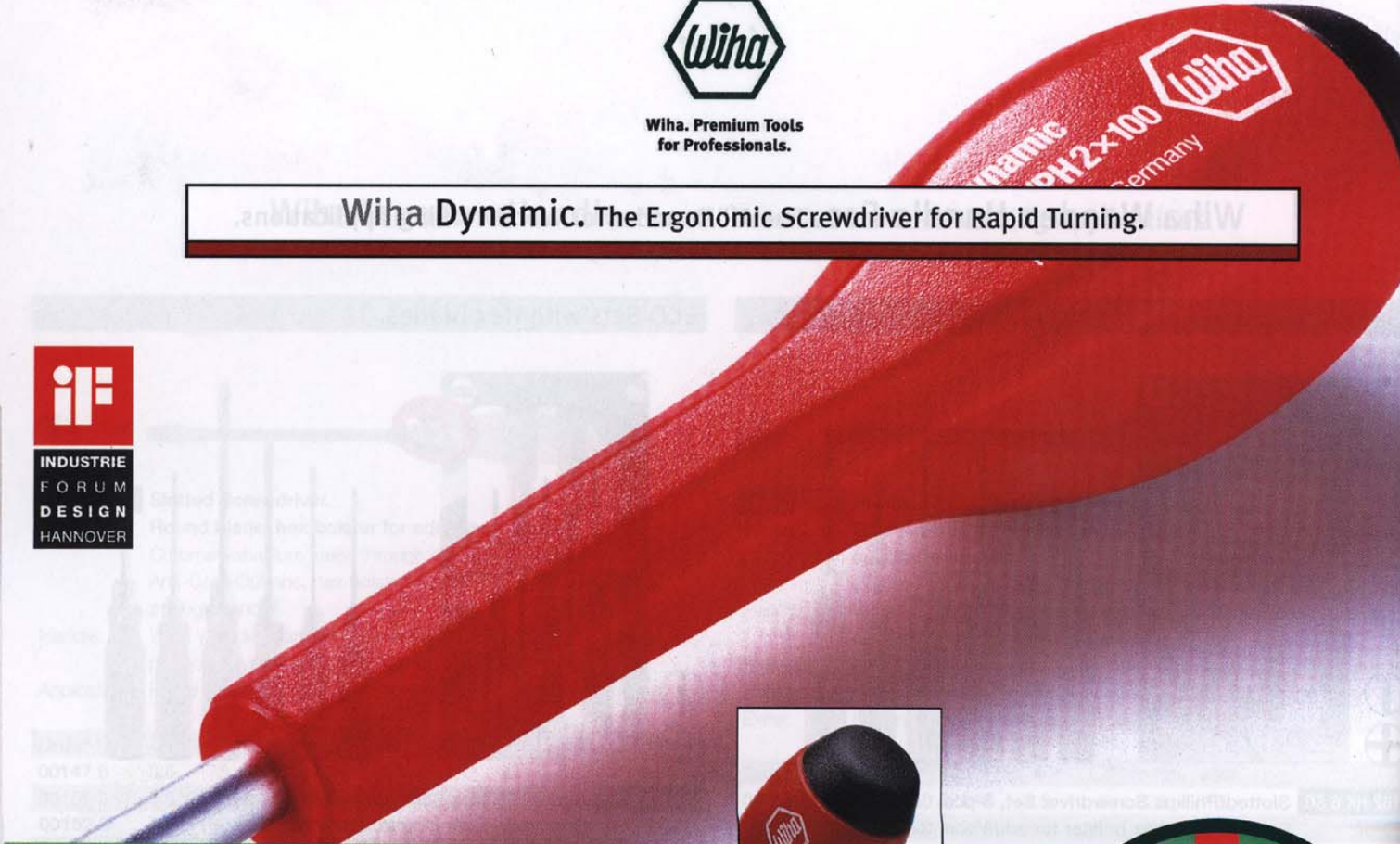

Wiha. Premium Tools
for Professionals.

Wiha Dynamic. The Ergonomic Screwdriver for Rapid Turning.



The rapid-turning zone in connection with the rotating cap allows optimum rotation with high torque.

Wiha ChromeTop-finish on tip for a perfect fit every time.




Dynamic Advantages:

- Unique handle, especially suited for fast and comfortable working
- Especially suitable for delicate applications, e.g. copiers, IT appliances or model building
- Ergonomically designed, palm saving rotating cap and rapid-turning zone enable gradual and careful rotation
- Wiha ChromeTop-finish on tip for a perfect fit every time

The unique Wiha Dynamic screwdriver demonstrates its strengths mainly in sensitive applications requiring an instant, fast twist. Due to the convex handle end, less power is required for high torque transmission to tighten or loosen the screw.

It is especially suitable for professionals and service engineers working on copiers, IT appliances or maintaining electronic equipment. It also demonstrates its strengths with design studies, prototypes and aeroplane models. The ergonomic rotating cap, as well as the rapid-turning zone, enable both fine adjustments and high torque transmission.

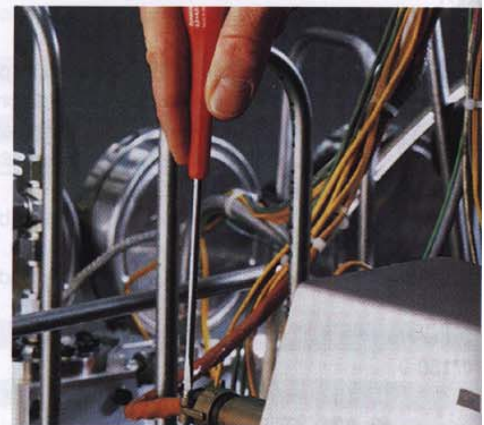



Wiha. Premium Tools
for Professionals.

Wiha Dynamic. The Ergonomic Screwdriver for Rapid Turning.

For Slotted, Phillips, and Pozidriv Screws.



510 Slotted Screwdriver.
With rotating cap.
Blade: High quality chrome-vanadium-molybdenum steel, through hardened, chrome-plated.
Wiha ChromTop finish on tip for a perfect fit every time.
Handle: Wiha Dynamic handle with rotating cap for rapid rotation.
Standards: DIN 5265, ISO 2380.
Application: For all delicate applications, e.g. copiers, printers, fax machines.


Order-No.	DI	Series	Length	Tip Length	Tip Width	Tip Height	Tip Thickness	Handwritten
01550 3	2.0	65	0.4	165	2.0	21	10	215-351
01551 0	2.5	75	0.4	175	2.5	21	10	
03753 6	3.0	80	0.5	180	3.0	21	10	215-363
01553 4	3.5	100	0.6	205	3.5	25	10	
01554 1	4.0	100	0.8	205	4.0	25	10	215-375
01556 5	5.5	125	1.0	236	5.5	28	10	215-387
01557 2	6.5	150	1.2	267	6.0	32	10	
01558 9	8.0	175	1.2	297	7.0	35	10	

• Non-DIN sizes.



511 Phillips Screwdriver.
With rotating cap.
Blade: High quality chrome-vanadium-molybdenum steel, through hardened, chrome-plated.
Wiha ChromTop finish on tip for a perfect fit every time.
Handle: Wiha Dynamic handle with rotating cap for rapid rotation.
Standards: ISO 8764.
Application: For all delicate applications, e.g. copiers, printers, fax machines.

Order-No.	Series	Length	Tip Length	Tip Width	Tip Height	Tip Thickness	Handwritten
03116 9	0	60	160	3.0	21	10	215-430
03126 8	1	80	191	4.5	28	10	215-442
03127 5	2	100	217	6.0	32	10	215-456

 

512 Pozidriv Screwdriver.
With rotating cap.
Blade: High quality chrome-vanadium-molybdenum steel, through hardened, chrome-plated.
Wiha ChromTop finish on tip for a perfect fit every time.
Handle: Wiha Dynamic handle with rotating cap for rapid rotation.
Standards: ISO 8764.
Application: For all delicate applications, e.g. copiers, printers, fax machines.

Order-No.	Series	Length	Tip Length	Tip Width	Tip Height	Tip Thickness	Handwritten
03133 6	0	60	160	3.0	21	10	215-399
03134 3	1	80	191	4.5	28	10	215-405
03135 0	2	100	217	6.0	32	10	215-417

For TORX® Screws and Dynamic Sets.



517 TORX® Screwdriver.
With rotating cap.
Blade: High quality chrome-vanadium-molybdenum steel, through hardened, chrome-plated.
Wiha ChromTop finish on tip for a perfect fit every time.
Handle: Wiha Dynamic handle with rotating cap for rapid rotation.
Standards: ISO 8764.
Application: For all delicate applications, e.g. copiers, printers, fax machines.

Order-No.	Series	Length	Tip Length	Tip Width	Tip Height	Tip Thickness	Handwritten
03205 0	T10	80	185	4.0	25	10	
03206 7	T15	80	185	4.0	25	10	215-533
03207 4	T20	100	205	4.0	25	10	215-545
03208 1	T25	100	211	4.5	28	10	
03210 4	T30	115	232	6.0	32	10	



510 HK 5 Slotted/Phillips Screwdriver Set, 5-pcs.
With rotating cap.
Blade: High quality chrome-vanadium-molybdenum steel, through hardened, chrome-plated.
Wiha ChromTop finish on tip for a perfect fit every time.
Handle: Wiha Dynamic handle with rotating cap for rapid rotation.
Application: For all delicate applications, e.g. copiers, printers, fax machines.

Order-No.	Series	Length	Tip Length	Tip Width	Tip Height	Tip Thickness	Handwritten
03104 6							1
	DI	510	3.0x80	4.0x100	5.5x125		
	+	511	PH 0	PH 1			



510 ZK 5 Slotted/Pozidriv Screwdriver Set, 5-pcs.
With rotating cap.
Application: For all delicate applications, e.g. copiers, printers, fax machines.

Order-No.	Series	Length	Tip Length	Tip Width	Tip Height	Tip Thickness	Handwritten
03497 9							1
	DI	510	3.0x80	4.0x100	5.5x125		
	+	512	PZ 0	PZ 1			