


 

 
 


Euromas II, lid with membrane area

Product no.:	63231200
Length:	160
Width:	80
Height:	87
Material:	ABS (acrylonitrile-butadiene-styrene)
Sealing material:	Neoprene
Color:	light grey
Ingress protection:	IP 65
PDF:	
DXF:	

Accessories:

Product no.	Model	Description
22009000	GF	 Rubber feet, Polyurethane, black, 65-75 Shore, 1 set = 4 pcs.
22080000	SA	screw covers (6 pcs), for Euromas II
22010000	EM-WL	 wall bracket set = 4 pcs, for Euromas II
22000600	M	 Mounting plate, for Euromas M/T 219/220/231/235
22151501	TS 15	top hat rail DIN EN 60715 TH 15 - 15 x 5, for Euromas II, EM/ET 220
22321501	TS 32	G-rail DIN EN EN 60715 G 32 - 32 x 15, for Euromas II, EM/ET 220/229/231/238
22351501	TS 35	top hat rail DIN EN 60715 TH 35 - 35 x 7,5, for Euromas II, EM/ET 220/231/238

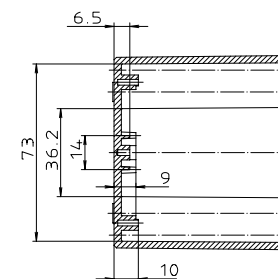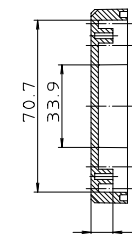

Maßstab: 1:1										
Zchn.Nr: 1G 5145.046.04										
Artikel: EM/ET 231(-LP) EM/ET 231 F(-LP) Katalogzeichnung										
<table><tr><td>-</td><td>-</td></tr><tr><td>3633</td><td>27.08.02</td></tr><tr><td>2762</td><td>18.01.03</td></tr><tr><td>2762</td><td>06.01.03</td></tr></table>	-	-	3633	27.08.02	2762	18.01.03	2762	06.01.03	 A Pignone Pizzaro Com.	
-	-									
3633	27.08.02									
2762	18.01.03									
2762	06.01.03									
Ag.Nr:	Datum:	DISK : 2 500 907 Datum: 17.08.92 SM								