



Sloped Steel & Aluminum Consoles (500, 515 & 519 Series)

[Home](#)

[Products](#)

[Distributors](#)

[Technical](#)

[Contact Us](#)

[Other Options](#)

Path: [Home](#) > [Enclosure Index](#) > **Sloped Steel & Aluminum Consoles**



[click to enlarge](#)

[15 Degree Slope \(Steel Back\)](#)



[click to enlarge](#)

[15 Degree Slope \(Aluminum Back\)](#)



[click to enlarge](#)

[30 Degree Slope \(Aluminum Back\)](#)

Key Features:

- 18 ga. steel base for extra strength
- Easy to machine - aluminum top panels are 0.064" thick aluminum.
- Sides include vertical rows of ventilation
- Sold pre-assembled with a two tone grey powder paint finish (base is dark satin grey, slope top is smooth light grey).
- Comes with four self adhesive rubber feet and required hardware.
-

Replacement screws **1421J6** (Pkg. of 6, 6-32 Philips head screws).








15 Degree Slope
(Aluminum Top Slope, Steel Base & Back)



click to enlarge
 Front View



click to enlarge
 Rear View

Part Number	Reader File	 Drawing File Size	AutoCAD .dwg Files (zipped)	.zip File Size	Units	Dimensions			
						Width	Depth	Rear Height	Front Height
500-0930		41K		27K	inch	7.0	7.0	2.13	1.2
					mm	178	178	54	30
500-0940		41K		27K	inch	7.6	7.0	3.78	2.86
					mm	190	178	96	73
500-0950		41K		27K	inch	11.7	7.83	2.13	1.2
					mm	297	199	54	30

15 Degree Slope












(Aluminum Top Slope & Back, Steel Base)



click to enlarge
Front View



click to enlarge
Rear View


Part Number	Reader File	 Drawing File Size	AutoCAD .dwg Files (zipped)	.zip File Size	Units	Dimensions			
						Width	Depth	Rear Height	Front Height
515-0910		38K		14K	inch	4.50	6.0	2.13	1.13
					mm	114	152	54	29
515-0920		41K		16K	inch	6.0	6.0	2.13	1.13
					mm	152	152	54	29
515-0930		40K		16K	inch	7.4	6.0	2.13	1.13
					mm	188	152	54	29
515-0940		40K		15K	inch	7.4	6.0	3.78	2.78
					mm	188	152	96	71
515-0950		41K		16K	inch	11.7	7.7	2.13	1.2
					mm	297	196	54	30

30 Degree Slope






(Aluminum Top Slope & Back, Steel Base)

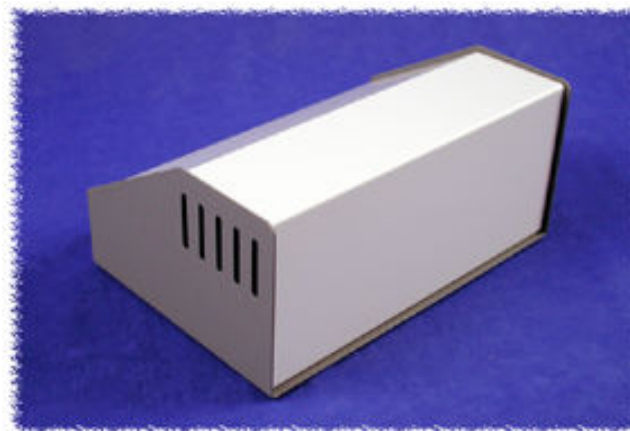

click to enlarge
Front View

 

click to enlarge
Rear View


Part Number	Reader File	 Drawing File Size	AutoCAD .dwg Files (zipped)	.zip File Size	Units	Dimensions			
						Width	Depth	Rear Height	Front Height
519-0910		41K		16K	inch	8.5	5.7	3.78	1.86
					mm	216	145	96	47
519-0920		41K		16K	inch	13.7	6.9	3.78	1.86
					mm	348	175	96	47

DOWNLOAD

catalog pages on this series (107K) [9C-500-519.pdf](#)

Exactly what you are looking for???

Link to our stocking distributors - most have "on-line" pricing, stock check and ordering!!!

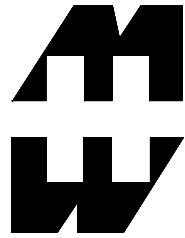

PART No. 500-0950

for more information visit
www.hammondmfg.com

Data subject to change without notice

ISOMETRIC VIEW NOT TO SCALE

