

Feed through and ground Terminal blocks

Screw clamp  DIN 1-3

M 10/10 - 10 mm² blocks - 10 mm .394" spacing

Characteristics

		IEC NFC DIN	UL	CSA
Wire size mm ² / AWG	Solid	0.5 - 16	20-6 AWG	18-6 AWG
	Stranded	0.5 - 10		
Voltage	V	800	600	600
Current	A	57	65	70
Short circuit current (M 10/10.PI)	A / s	1200A/1s		
Rated wire size	mm ² / AWG	10 mm ²	6 AWG	6 AWG
Wire stripping length	mm / inches	12 mm / .47"		
Recommended torque	Nm / lb.in	1.2-1.4 Nm / 10.6-12.4 lb.in		

Selection

Description	Type	Order P/N	Packaging Weight kg
Standard block grey	 M 10/10	1SNA 115 120 R1700	50
Standard block blue	 M 10/10.N	1SNA 125 120 R1100	50
Standard block yellow	 M 10/10	1SNA 105 120 R2600	50
Standard block beige V0	 M 10/10.V0	1SNA 195 120 R1000	50
Ground block yellow body/ green marking (without rail contact)	 M 10/10.PI	1SNA 165 452 R2200	50

Accessories

End stop		BAM 9.1 mm	1SNA 103 002 R2600	50
End section	grey	 FEM6 2.8 mm	1SNA 118 368 R1600	20
	blue	 FEM6 2.8 mm	1SNA 128 368 R1000	20
	orange	 FEM6 2.8 mm	1SNA 103 126 R1600	20
	yellow	 FEM6 2.8 mm	1SNA 103 062 R2100	20
	green	 FEM6 2.8 mm	1SNA 103 125 R1500	20
Separator end section	grey	 SCF6 3 mm	1SNA 118 707 R0300	20
Assembled jumper bar (with IP20 protection)	2 poles	BJMI10 57 A	1SNA 176 675 R0400	10
	3 poles	BJMI10 57 A	1SNA 176 676 R0500	10
	4 poles	BJMI10 57 A	1SNA 176 677 R0600	10
	5 poles	BJMI10 57 A	1SNA 176 678 R1700	10
	10 poles	BJMI10 57 A	1SNA 176 679 R1000	10

M 10/10.P - 10 mm² ground block with rail contact - 10 mm .394" spacing

Characteristics


		IEC NFC DIN	UL	CSA
Wire size mm ² / AWG	Solid	0.5 - 16	20-6 AWG	18-6 AWG
	Stranded	0.5 - 10		
Short circuit current	A / s	1200A/1s		
Rated wire size	mm ² / AWG	10 mm ²	6 AWG	6 AWG
Wire stripping length	mm / inches	12 mm / .47"		
Recommended torque	Nm / lb.in	1.2-1.4 Nm / 10.6-12.4 lb.in		

Selection


Description	Type	Order P/N	Packaging Weight kg
Ground block V2 green/yellow	 M 10/10.P	1SNA 165 115 R1000	50
Ground block V0 green/yellow	 M 10/10.P V0	1SNA 195 115 R0700	50

Accessories

Separator end section	grey	 SCFM6 3 mm	1SNA 114 825 R0500	20
-----------------------	------	--	--------------------	----

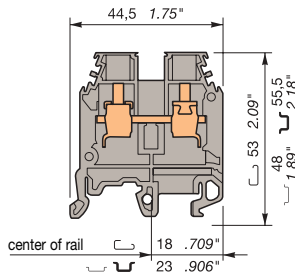


M 10/10

 


BAM



 
FEM6




SCF6

 

BJMI10

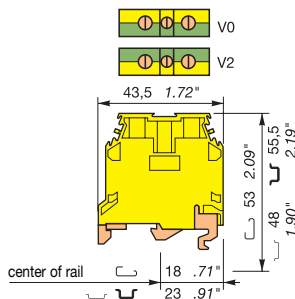

M 10/10.P

 

SCFM6