


# Spirit Fillings; Low Range; Cases; Safety Coatings

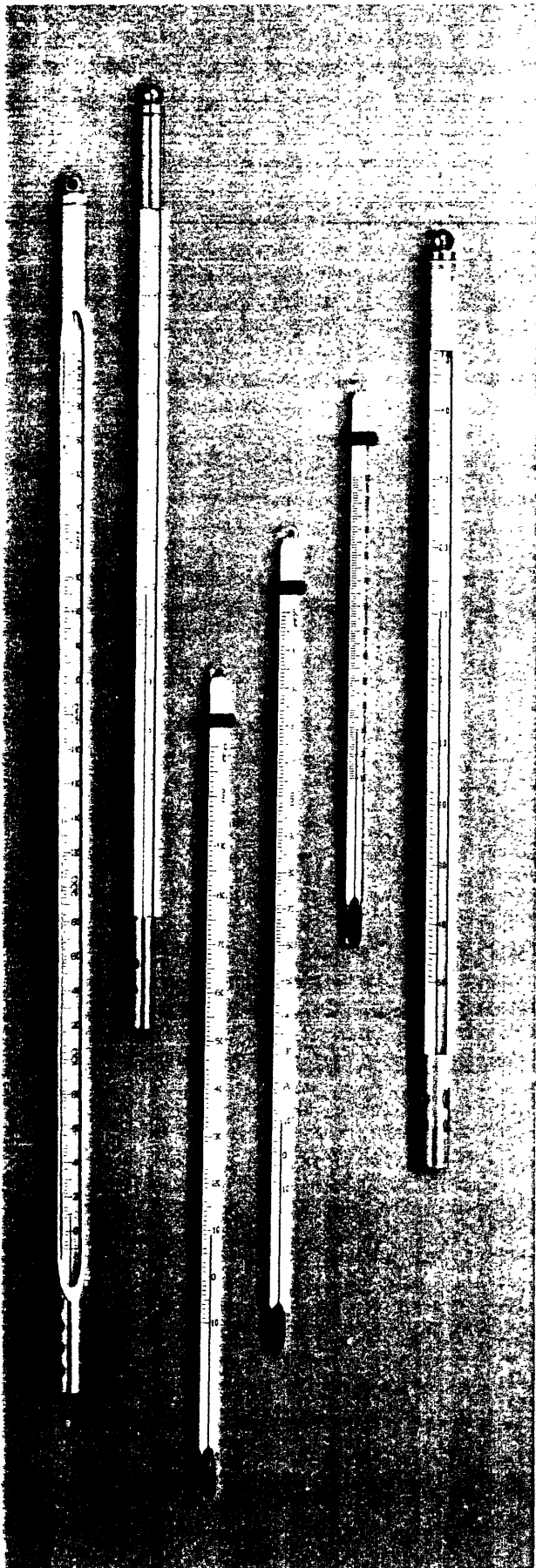

**305mm Red Spirit Filled Stirring Thermometers** with white-backed glass. Stirring bulbs. Non-roll fittings. Order in tens.

Range	Division	Imm.	Product No.
-10/50C	0.5	76mm	44/401 708132-
-10/110C	1	76mm	44/403 708133-
-10/150C	1	76mm	44/406 708134-

**205mm Stirring.** Order in tens.

-10/110C	1	76mm	44/423
----------	---	------	--------

**305mm Low Range Spirit Filled Thermometers** with white-backed glass.

-100/50C	1	Total	46/456
-50/50C	1	Total	46/539

**380mm Low Range Thermometer.** Clear pentane filled.

-200/30C	1	Total	46/440
----------	---	-------	--------

**Safety Coated Laboratory Thermometers.** 295mm 'Teflon'\* coated mercury filled thermometers.

-20/110C	1	76mm	41/903/0
-20/150C	1	76mm	41/906/0
-10/200C	1	76mm	41/908/0
-10/250C	1	76mm	41/910/0

**Slot Cases for Laboratory Thermometers.** Screw caps.

Thermometer Length	Product No.
<b>Brass</b>	
155mm	47/732/0 7031911
205mm	47/632/0
255mm	47/532/0
305mm	47/432/0 7081900
355mm	47/832/0
405mm	47/932/0
<b>Stainless Steel</b>	
155mm	47/734/0
205mm	47/634/0
255mm	47/534/0
305mm	47/434/0
355mm	47/834/0
405mm	47/934/0

\*Teflon\* Dupont registered trade mark