

## European Region

[Download Instructions](#) (multilingual)

## One Hour Battery Charger

### FAST

- Charges NiMH batteries in about one hour




### EASY TO USE

- LEDs indicating charging status
- Worldwide voltage: 100-240V AC 50/60 Hz



### VERSATILE

- Charges 1-4 "AA" or "AAA" NiMH rechargeable batteries at a time

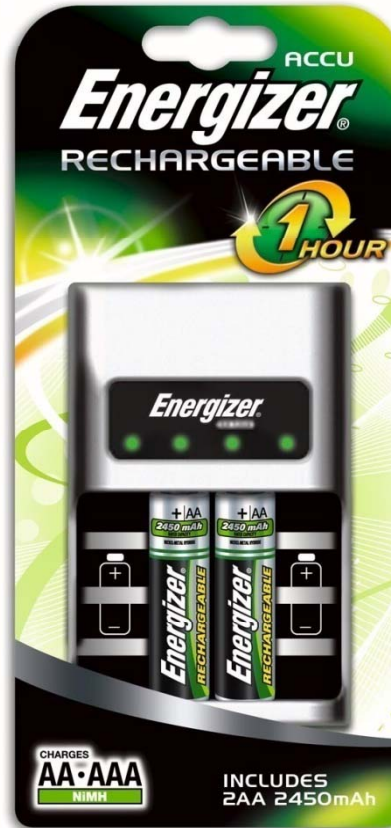

#### Before Using Your Charger:

Please read all instructions and cautionary markings on the battery charger, batteries, and device.

### Product Detail:

**Designation:** 1 Hour Charger

**Color:** Silver

**Charging Capability:** 1 to 4 "AA" / 1 to 4 "AAA"

**Charging Current:** "AA" 2500mA

"AAA" 1000mA

**Trickle Charge:** "AA" 50mA

"AAA" 20mA

Charging Times (estimated)	Battery (NiMH)	Capacity (mAh)	Estimated (time)
	AA	2000	60 mins
	AA	2450	72 mins
	AA	2650	78 mins
	AAA	900	60 mins
	AAA	1000	72 mins

**Shutoff Mechanism:** Timer Control

Max Timer Control 80 mins

**Charger Input :** DC 12-16V; 1.3A

**Weight (charger):** 119 grams

**Dimensions (mm):** 124 x 80 x 28 (H x L x W)

**Safety Features:** Reverse Polarity Protection  
Safety Timer to Prevent Over Charge  
Primary Battery Detection  
Temperature Control  
Minus Delta Voltage Control (-dV)

**NOTE:** Do not attempt to charge non-rechargeable batteries not specified by Energizer

### Important Notice

This datasheet contains information specific to products manufactured at the time of its publication.

© Energizer

**Contents herein do not constitute a warranty.**