

Friday 16 February 2007

Regarding the Vario Modules, these items are made up of 3 parts.

I have attached the data sheets that relate to these parts; also please see the following list of parts that make up the Vario Modules:

1052184 - 3982040 + 3982941 + 3982701
1052185 - 3985070 + 3982951 + 3982711
1052186 - 3982090 + 3982950 + 3982710
1052187 - 3982100 + 3982960 + 3982720
1052188 - 3982120 + 3982950 + 3982710
1052189 - 3982130 + 3982960 + 3982720
1052190 - 3982140 + 3982950 + 3982710
1052191 - 3982150 + 3982960 + 3982720


Rittal Limited
Braithwell Way
Hellaby Industrial Estate
Rotherham
S66 8QY
Tel: 01709 704028
Fax: 01709 701217

Master data

Details

Service

Downloads

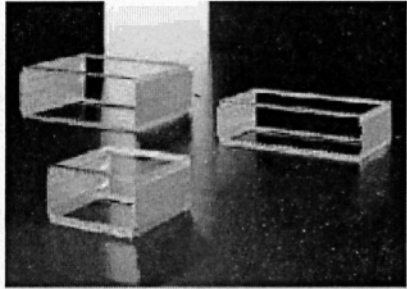


Model No.:	RP 3982.040
Designation:	VM basic enclosure, 3 U, 42 HP, 245 mm not EMC, RAL 7035
Variant:	n/a
Packs of:	1 ST
WHD:	n/a
Mounting surface:	n/a
Volume:	n/a
Net weight/ST:	1,98 kg
EAN:	4028177474079
Customs number:	85381000
Protection categories:	n/a
eClass 4.0	27-18-05-01
eClass 4.1	27-18-05-01
eClass 5.0	27-18-08-01
ETIM 2.0	EC000765
ETIM 3.0	EC000765

Master data


Details

Service

Downloads

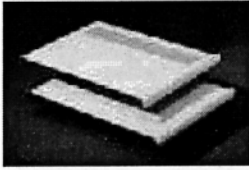

Model No.:	RP 3982.941
Designation:	VM cover plate, vented, 42 HP, 245 mm not EMC, RAL 7035
Variant:	n/a
Packs of:	1 ST
WHD:	n/a
Mounting surface:	n/a
Volume:	n/a
Net weight/ST:	0,33 kg
EAN:	4028177473515
Customs number:	72166900
Protection categories:	n/a
eClass 4.0	27-18-81-xx
eClass 4.1	27-18-81-01
eClass 5.0	27-18-25-01
ETIM 2.0	EC000744
ETIM 3.0	EC000744

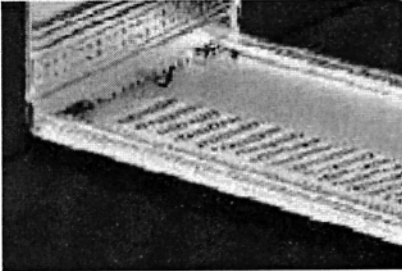Master data	Details	Service	Downloads																																
	<table><tr><td>Model No.:</td><td>RP 3982.701</td></tr><tr><td>Designation:</td><td>VM gland plate, unvented, 42 HP, 245 mm not EMC, RAL 7035</td></tr><tr><td>Variant:</td><td>n/a</td></tr><tr><td>Packs of:</td><td>1 ST</td></tr><tr><td>WHD:</td><td>n/a</td></tr><tr><td>Mounting surface:</td><td>n/a</td></tr><tr><td>Volume:</td><td>n/a</td></tr><tr><td>Net weight/ST:</td><td>0,34 kg</td></tr><tr><td>EAN:</td><td>4028177473270</td></tr><tr><td>Customs number:</td><td>72166900</td></tr><tr><td>Protection categories:</td><td>n/a</td></tr><tr><td>eClass 4.0</td><td>27-18-81-xx</td></tr><tr><td>eClass 4.1</td><td>27-18-81-01</td></tr><tr><td>eClass 5.0</td><td>27-18-25-01</td></tr><tr><td>ETIM 2.0</td><td>EC000745</td></tr><tr><td>ETIM 3.0</td><td>EC000745</td></tr></table>	Model No.:	RP 3982.701	Designation:	VM gland plate, unvented, 42 HP, 245 mm not EMC, RAL 7035	Variant:	n/a	Packs of:	1 ST	WHD:	n/a	Mounting surface:	n/a	Volume:	n/a	Net weight/ST:	0,34 kg	EAN:	4028177473270	Customs number:	72166900	Protection categories:	n/a	eClass 4.0	27-18-81-xx	eClass 4.1	27-18-81-01	eClass 5.0	27-18-25-01	ETIM 2.0	EC000745	ETIM 3.0	EC000745		
Model No.:	RP 3982.701																																		
Designation:	VM gland plate, unvented, 42 HP, 245 mm not EMC, RAL 7035																																		
Variant:	n/a																																		
Packs of:	1 ST																																		
WHD:	n/a																																		
Mounting surface:	n/a																																		
Volume:	n/a																																		
Net weight/ST:	0,34 kg																																		
EAN:	4028177473270																																		
Customs number:	72166900																																		
Protection categories:	n/a																																		
eClass 4.0	27-18-81-xx																																		
eClass 4.1	27-18-81-01																																		
eClass 5.0	27-18-25-01																																		
ETIM 2.0	EC000745																																		
ETIM 3.0	EC000745																																		