

Friday 16 February 2007

Regarding the Vario Modules, these items are made up of 3 parts.

I have attached the data sheets that relate to these parts; also please see the following list of parts that make up the Vario Modules:

1052184 - 3982040 + 3982941 + 3982701
1052185 - 3985070 + 3982951 + 3982711
1052186 - 3982090 + 3982950 + 3982710
1052187 - 3982100 + 3982960 + 3982720
1052188 - 3982120 + 3982950 + 3982710
1052189 - 3982130 + 3982960 + 3982720
1052190 - 3982140 + 3982950 + 3982710
1052191 - 3982150 + 3982960 + 3982720


Rittal Limited
Braithwell Way
Hellaby Industrial Estate
Rotherham
S66 8QY
Tel: 01709 704028
Fax: 01709 701217

Master data

Details

Service

Downloads

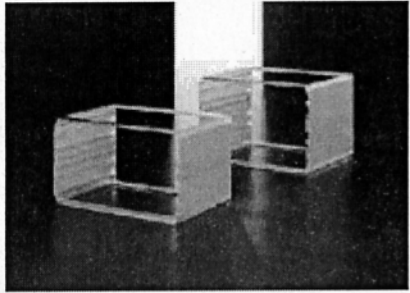


Model No.:	RP 3982.140
Designation:	VM basic enclosure, 6 U, 84 HP, 305 mm not EMC, RAL 7035
Variant:	n/a
Packs of:	1 ST
WHD:	n/a
Mounting surface:	n/a
Volume:	n/a
Net weight/ST:	4,78 kg
EAN:	4028177474239
Customs number:	85381000
Protection categories:	n/a
eClass 4.0	27-18-05-01
eClass 4.1	27-18-05-01
eClass 5.0	27-18-08-01
ETIM 2.0	EC000765
ETIM 3.0	EC000765

Master data

Details

Service

Downloads

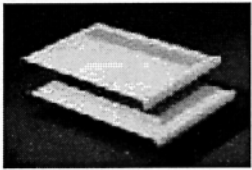


Model No.:	RP 3982.950
Designation:	VM cover plate, vented, 84 HP, 305 mm not EMC, RAL 7035
Variant:	n/a
Packs of:	1 ST
WHD:	n/a
Mounting surface:	n/a
Volume:	n/a
Net weight/ST:	0,75 kg
EAN:	4028177473560
Customs number:	72166900
Protection categories:	n/a
eClass 4.0	27-18-81-xx
eClass 4.1	27-18-81-01
eClass 5.0	27-18-25-01
ETIM 2.0	EC000744
ETIM 3.0	EC000744

Master data

Details

Service

Downloads

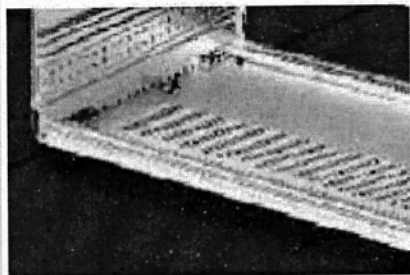

Model No.:	RP 3982.710
Designation:	VM gland plate, unvented, 84 HP, 305 mm not EMC, RAL 7035
Variante:	n/a
Packs of:	1 ST
WHD:	n/a
Mounting surface:	n/a
Volume:	n/a
Net weight/ST:	0,77 kg
EAN:	4028177473324
Customs number:	72166900
Protection categories:	n/a
eClass 4.0	27-18-81-xx
eClass 4.1	27-18-81-01
eClass 5.0	27-18-25-01
ETIM 2.0	EC000745
ETIM 3.0	EC000745