

Receptacle Housings

Technical Features


No. of Positions:
18 Positions (2nd Generation)

Housing Material:
PBT GF20

Wire Size Range:
0.35–0.75 mm²

Product Specification:
108-15134

Application Specification:
411-15554

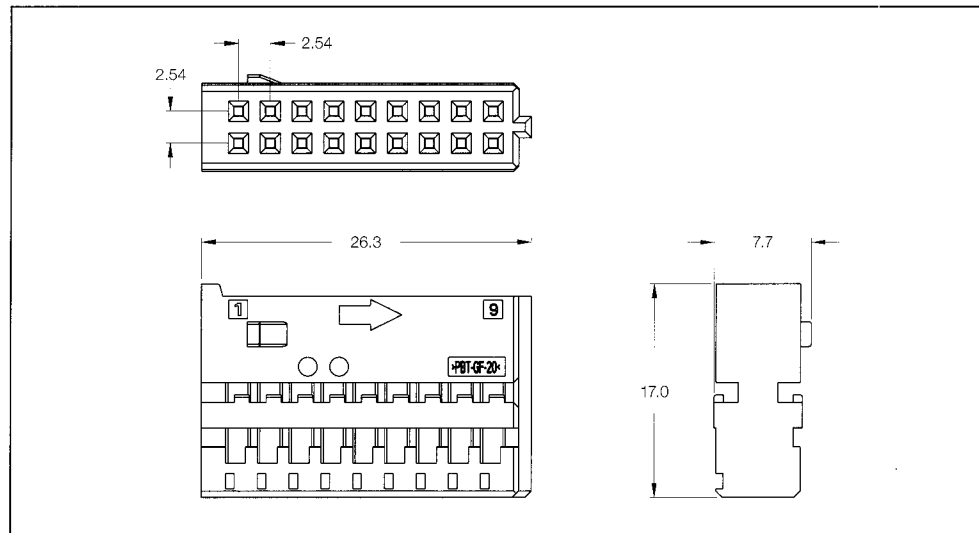

18 Position Receptacle Housings

No. of Pos.	Keying Options	Housing Color	Part Numbers							
			Receptacle Housing	Cover	Locking Device	Cover and Lever	Retainer Housing	Mating Tab Housing	Mating PCB Header Right-Angle	Mating PCB Header Vertical
18	-	Black	1379102-1	-	-	-	-	-	-	-
		Black	-	-	-	1379100-1 (Wire Output 0°)	-	-	185683	185458
		White	-	-	-	1379100-2 (Wire Output 0°)	-	-	185680	953302
		Black	-	-	-	1379101-1 (Wire Output 90°)	-	-	1379731	953264
		White	-	-	-	1379101-2 (Wire Output 90°)	-	-	-	-

Technical Features


No. of Positions:
18 Positions + 6 Shorting Bars

Housing Material:
PBT GF20

Wire Size Range:
0.2–0.6 mm²

Product Specification:
108-15111

Application Specification:
411-15533

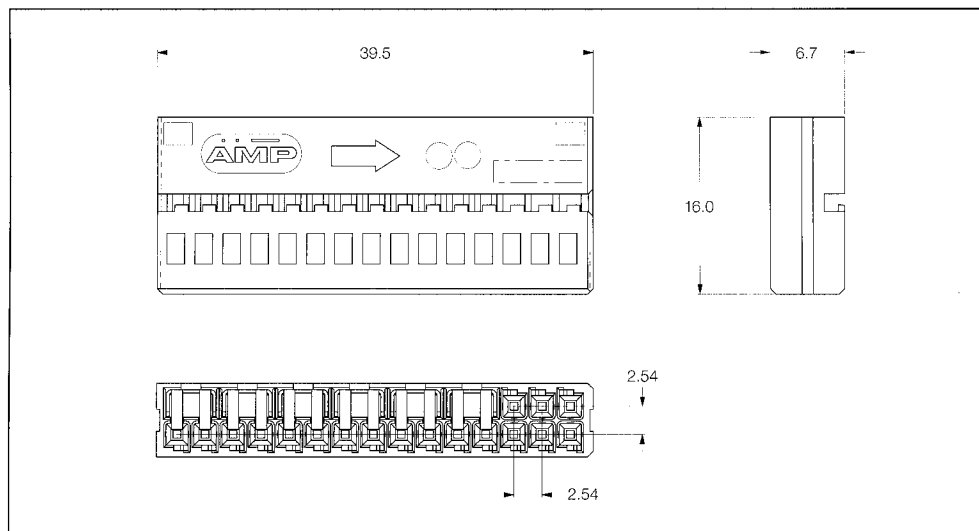

18 Position Receptacle Housings

No. of Pos.	Keying Options	Housing Color	Part Numbers							
			Receptacle Housing	Cover	Locking Device	Cover and Lever	Retainer Housing	Mating Tab Housing	Mating PCB Header Right-Angle	Mating PCB Header Vertical
18	-	Black	144952-1	-	144936-1	-	-	-	-	-
		Orange	-	-	-	144951-1	-	-	144950	-
		Yellow	-	-	-	144951-2	-	-	185180	-
		Red	-	-	-	144951-3	-	-	-	-
		Green	-	-	-	144951-4	-	-	-	-