


## Multiadapters

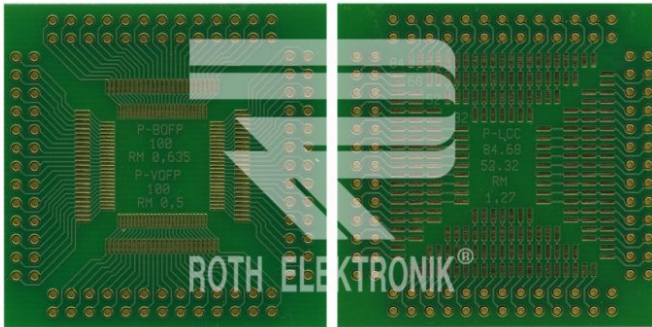

### RE460-05

- Epoxy FR4 1.50 mm, two-sided 35 µm CU (through plated)
- Chem. AU and solder resist mask
  
- Hole diameter 1.00 mm
- Grid spacing from 0.50 mm to 1.27 mm
- Adaption circuit board for PLCC 32, 52, 68.84 (1.27 mm) and QFP 100 (0.635 mm) and QFP 100 (0.50 mm)
- Size 45,60 x 45,60 mm