


# Coated Abrasives

## Paper and Cloth Sheets

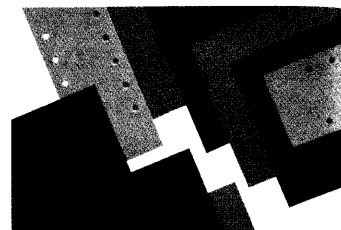

### Waterproof Sheets

Range	Abrasives	Cap code	Grit	Backing	Colour	Special	Main applications and attributes
★★	Silicon Carbide	T489	P180 to P1200	A/b	Black		First choice for wet and dry waterproof latex paper with a very flexible non curling paper
★★★	Silicon Carbide	T402	P1500, P2000	A	Black		Ultimate finish in wet applications. Highly flexible. No curling

### Waterproof Sheets

Size (mm)	Product Range	Abrasive Type	Product	Weight	Grit Size	SAP Part No.	Former Mac Pac Part No.	Stock Status	Pack Qty	List Price £ per 100
230 x 280	★★	Sic	T489	A	180	<b>63642532957</b>	755882	STK	50	47.74
					220	<b>63642532992</b>	771053	STK	50	47.74
					240	<b>63642532993</b>	771054	STK	50	47.74
					280	<b>63642532994</b>	771055	STK	50	47.74
					320	<b>63642532995</b>	771056	STK	50	47.74
					360	<b>63642532996</b>	771057	STK	50	47.74
					400	<b>63642532997</b>	771058	STK	50	47.74
					500	<b>63642532998</b>	771059	STK	50	47.74
					600	<b>63642532999</b>	771060	STK	50	47.74
					800	<b>63642533000</b>	771061	STK	50	47.74
					1000	<b>63642533001</b>	771062	STK	50	47.74
					1200	<b>63642533002</b>	771064	STK	50	47.74
	T489 C	C	Sic	C	60	<b>63642532956</b>	755881	STK	50	79.12
					80	<b>63642532988</b>	771048	STK	50	68.59
					100	<b>63642532989</b>	771050	STK	50	60.79
					120	<b>63642532990</b>	771051	STK	50	54.95
					150	<b>63642532991</b>	771052	STK	50	49.81
					180	<b>63642532002</b>	313888	STK	50	47.74
					220	<b>63642532003</b>	313889	STK	50	47.74
					240	<b>63642532004</b>	313890	STK	50	47.74
					280	To be created on order	313891	MTO	50	47.74
					320	<b>63642532006</b>	313892	STK	50	47.74
★★★	Sic	T402	A	1500	66261139379	414434	MTO	50	71.76	
				2000	66261139378	414408	MTO	50	71.76	

Stock status

STK - Stocked in the UK MTO - Made to order STK\* (MTO) - Stocked in the UK while supplies last and will then be MTO EUR - European stock

Product Range

★ Standard ★★ Advanced ★★★ Premium