


DURACELL® Rechargeable



Rechargeable StayCharged AA

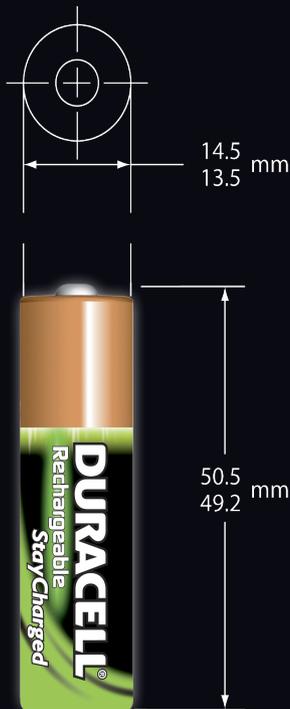

BENEFITS

- Stays Charged Longer*
- Recharge Less*
- Pre-Charged and ready to use straight out of the pack
- Retains up to 75% of charge up to 1 year (365 days) while not in use
- Up to 5000 pictures over the life of two batteries
- 100s of charges for 1000s of pictures

TECHNICAL

| | |
|------------------------------|--|
| Type: | NiMH Pre-charged AA 2000 mAh |
| Nominal Voltage | 1.2V |
| Nominal Internal Impedance: | 20 m-ohm @ 1kHz |
| Rated capacity: | 2000 mAh |
| Average Weight: | 30.2 grams (1.07 ounces) |
| Volume | 8.3 cm ³ (0.50 in ³) |
| Operating Temperature Range: | 0° C to 50° C (32° F to 122° F) |
| ANSI: | 1.2H2 |
| IEC: | HR6 |
| Product Codes: | Clamshell x2 – EU/UK SAP Code: 75052473 EU/UK EAN Code: 5000394087811 Clamshell x4 – EU/UK SAP Code : 75052474 EU/UK EAN Code : 5000394087828 |

Dimensions shown are IEC standards

Product can be charged on most NiMH or NiCd chargers utilizing standard dV, dV/dt, time and temperature dynamic charge termination methods. Duracell brand NiMH chargers are recommended for best results.

Delivered capacity is dependent on the applied load, operating temperature, and cut-off voltage. Please refer to the charts and discharge data shown for example of the energy/service life that the battery will provide for various local conditions.

This data is subject to change. Performance information is typical. Contact Duracell for latest information.

StayCharged batteries can be rapidly charged using Duracell 15 minute Charger

*vs. ordinary rechargeable batteries.

