

PS Series Range Specifications



6 VOLT

PART NO.	BATTERY MODEL	VOLTS	AH ¹	L	W	H	TOTAL H	WEIGHT	TERMINALS
15278	PS612	6	1.2	97	24	51.5	57.5	0.28	T1
22437	PS628	6	2.8	66	33	97	103	0.59	T1
15281	PS632	6	3.2	134	34	60	66	0.67	T1
15282	PS640	6	4	70	47	100	106	0.81	T1
15283	PS650	6	5	67	67	96	109	0.81	SPRING
15285	PS670	6	7	151	34	94	100	1.26	T1
15288	PS6100	6	10	151	51	94	100	1.70	T1
15290	PS6120	6	12	108	71	141	141	2.40	T1/T2
22438	PS6120W	6	12	151	51	94	100	2.05	T2
22439	PS6130	6	13	108	70	140	140	2.40	T1/T2
20700	PS6200	6	20	157	83	125	125	3.21	T3

¹ Rated AH capacity at 20 hour rate

12 VOLT

PART NO.	BATTERY MODEL	VOLTS	AH ¹	L	W	H	TOTAL H	WEIGHT	TERMINALS
15293	PS1208	12	0.8	96	25	62	62	0.34	AMP MATE-N-LOCK
15294	PS1212	12	1.2	97	43	52	58	0.57	T1
15295	PS1220	12	2	178	35	60	66	1.00	T1
22440	PS1223	12	2.3	178	35	60	66	1.00	T1
19624	PS1229	12	2.9	79	56	99	105	1.10	T1
22441	PS1230	12	3	141	33	102	108	1.20	T1
15297	PS1232	12	3.2	134	67	60.5	66.5	1.35	T1
15299	PS1240	12	4	90	70	101	107	1.60	T1
22442	PS1250L	12	5	151	51	93	99	1.80	T2
22443	PS1250S	12	5	151	51	93	99	1.80	T1
15302	PS1270S	12	7	151	65	94.5	100	2.45	T1
22444	PS1270L	12	7	151	65	94.5	100	2.45	T2
22445	PS1290	12	9	151	98	95	101	3.30	T2
22446	PS12100	12	10	151	65	111	117	3.30	T2
22447	PS12120S	12	12	151	98	95	101	3.80	T1
15306	PS12120L	12	12	151	98	95	101	3.80	T2
15309	PS12180	12	18	181.5	77	167.5	167.5	5.70	T3
15310	PS12240	12	24	166.5	175	125	125	8.10	T3
22434	PS12260H	12	26	165	125	175	182	8.70	T10
15312	PS12330	12	33	195	130	164	180	11.20	T5
15313	PS12400	12	38	197	165	170	170	13.20	T10
15316	PS12650	12	65	348	167	178	178	19.20	T6

¹ Rated AH capacity at 20 hour rate



 
SPRING Terminal




T1 Terminal




T2 Terminal




T3 Terminal

 


T5 Terminal

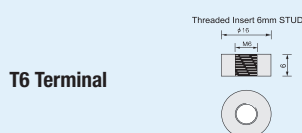

T6 Terminal

 

T10 Terminal

 

AMP MATE-N-LOCK Terminal

Trade Enquiries 1300 362 287
www.centurybatteries.com.au



CB109-449b