


Alkaline Manganese Dioxide Battery

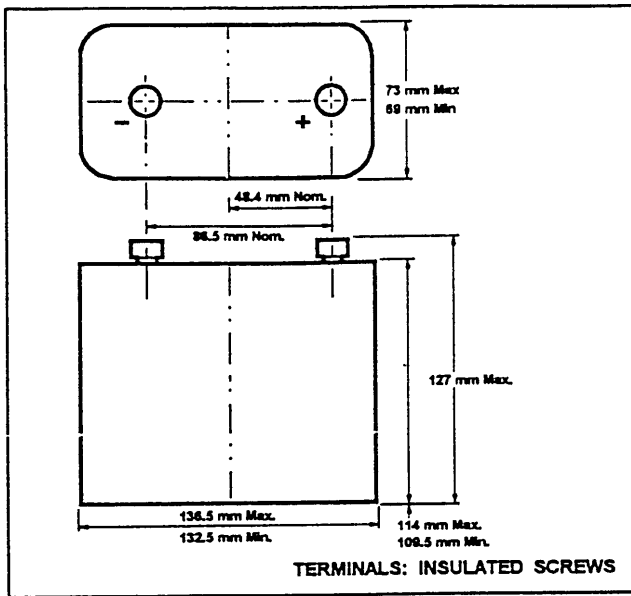

SPECIFICATIONS

Min. No Load Voltage	12V
Min. On Load Voltage	10.8V on 24Ω at 200ms
Rated Capacity	13000mAh on 30 Ω to 6.4V
Min. Life	36.5Hrs on 30 Ω to 6.4V
Volume	1066 cm ³
Weight	1389 g

