

Epson Stylus S22

PRODUCT GUIDE



This no-nonsense printer is perfect for all your home documents and photos and saves you money with individual ink cartridges.

This reliable, economical printer makes home photo and document printing simple and effortless.

Prints look great and last longer on any paper because Epson DURABrite Ultra ink is water, smudge, fade and even highlighter resistant. You can remove red-eye and adjust colour and contrast in a flash with the included software to ensure your photos always look their best.

Individual ink cartridges save you money as you only replace the colour used, and this power-efficient ENERGY STAR® qualified printer will also help to reduce your energy bills and environmental impact.

WHAT'S IN THE BOX

- Epson Stylus S22 printer
- 4 individual ink cartridges
- Software CD
- 'Start Here' guide
- Warranty document
- Power cable

FOR THE BEST RESULTS ALWAYS USE GENUINE EPSON INK AND PAPER.

Epson DURABrite Ultra Ink is perfect for all your home printing because it gives you long-lasting Epson quality on a wide range of media.

- Outstanding text documents and lab-quality photos
- Instant-drying prints are water, smudge, highlighter and fade resistant
- Resin-coated pigment technology works perfectly on a range of papers
- Lab-quality glossy photos last over 200 years in a photo album*¹



EPSON[®]
EXCEED YOUR VISION

PRODUCT SPECIFICATIONS

PRINT TECHNOLOGY	
Printing method	4-colour inkjet printer, Epson Micro Piezo™ print head
Nozzle configuration	90 nozzles black / 29 nozzles, each colour (cyan, magenta, yellow)
Droplet size	4 pl (minimum) with Variable-sized Droplet Technology
Ink system	Epson DURABrite Ultra Ink
PRINT RESOLUTION	
	Up to 5760x1440 optimised dpi on suitable media using RPM (Resolution Performance Management)
PRINT SPEED	
Black text A4	Up to 28 ppm ^{*1}
Colour text A4	Up to 15 ppm ^{*1}
Photo 10x15 cm	Approx. 89 secs ^{*1}
INTERFACE	
	USB – Compatible with the USB 2.0 Specification ^{*2}
PAPER HANDLING	
Capacity	Input: 100 sheets A4 plain paper (75 g/m ²)
Media size	A4, A5, A6, B5, 10x15 cm, 13x18 cm, 16:9 wide size, Letter, Legal, 9x13 cm, 13x20 cm, 20x25 cm, 100x148 mm, Envelopes: No.10, DL, C6
Print margin	0 mm top, left, right, bottom via custom settings in printer driver ^{*3}
INK CARTRIDGES	
	4 individual ink cartridges
Fox series	Black T1281 Cyan T1282 Magenta T1283 Yellow T1284
ELECTRICAL SPECIFICATION	
Power consumption	Approx. 10.1W (while printing, ISO/IEC 24712 pattern) Approx. 1.2W (sleep mode) ENERGY STAR® qualified printer
Voltage	AC 220-240V
OPERATING SYSTEMS	
	Windows 2000/XP/XP-x64/Vista, Win 7, Mac OS 10.4.11 or later
WARRANTY^{*4}	
	1 year standard warranty Optional extension to 3 years subject to availability
GENERAL	
Dimensions (WxDxH)	415x227x135 mm
Weight	2.4 kg (excluding ink cartridges and power cable)
Noise level	5.6 B(A) (according to ISO7779 pattern with Epson Premium Glossy Photo Paper/ Photo RPM mode) 42 dB(A) (according to ISO9296)
SOFTWARE	
	Epson Web Support Epson Easy Photo Print

^{*1} For more information please visit www.epson-europe.com

^{*2} USB cable required for PC/MAC use (not supplied in box).

^{*3} Otherwise 3 mm top, left, right, bottom.

^{*4} Warranty offers are not available for all countries. Please contact your local Epson representative

Epson Stylus S22


INK CARTRIDGE COMPATIBILITY



- T1281
- T1282
- T1283
- T1284
- T1285

RECOMMENDED PAPER

Epson's Micro Piezo™ inkjet technology gives great results on a wide range of paper types, giving you the flexibility to print whatever you want. And Epson produces a range of paper to help you do this, from A4 inkjet paper through to glossy photo paper in a variety of sizes.

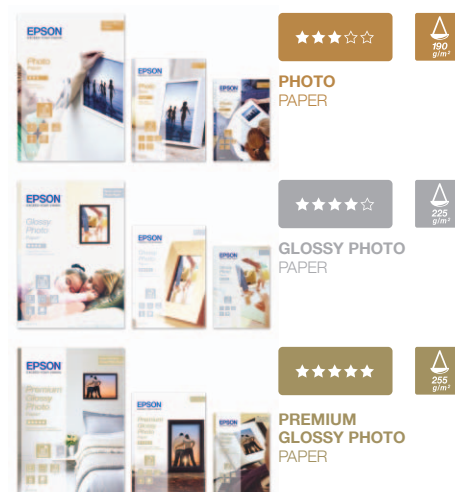

For further information please contact your local Epson office or visit www.epson-europe.com
Austria 0810/20 01 13 (0,07 €/Min.) **Belgium** 070/350120 (0.1735 €/min.) **Czech** 800/142 052 **Denmark** 44 50 85 85 **Finland** 0201 552 091
France 09 74 75 04 04 (Cost of local call, operator charges may apply) **Germany** 01805/23 41 10 (0,14 €/Min. aus dem dt. Festnetz, Mobilfunkpreise abweichend. Ab 1.3.2010 Mobilfunkpreis max. 0,42 €/Min.) **Greece** 210-8099499 **Hungary** 06800 147 83 **Ireland** 01 436 7742 **Italy** 02-660321 10 (0,12 €/min.) **Luxembourg** 900/43010 (0,24 €/min.) **Middle East** +9714 8818934 **Netherlands** 0900-5050808 (0,05 €/oproep + 0,15 €/min.)
Norway +47 67 11 37 00 **Poland** 0-0-800 4911299 (0,16 zł/min.) **Portugal** 707 222 111 **Russia** (095) 777-03-55 **Slovakia** 0850 111 429 **South Africa** (+2711) 465-9621 **Spain** 93 582 15 00 **Sweden** 0771-400135 (Mobilsamtal – 0,99 kr/min, Lokala samtal – 0,30 kr/min, Utlandssamtal – 0,89 kr/min)
Switzerland 0848 448820 (4–8 cent./min.) **Turkey** (0212) 3360303 **United Kingdom** 0871 222 6702

Trademarks and registered trademarks are the property of Seiko Epson Corporation or their respective owners.
 Product information is subject to change without prior notice.

