


303-2036 to 303-2322

# 1.27mm (.050") Pitch Picoflex™ PF-50 Custom Cable Harness, 92315



## Features and Benefits

- Cable assembly with two 90327 connectors
- Sizes 4 to 20 and 26 (see 90327)
- UL 2651, 28 AWG (7 strand) ribbon cable
- Lengths from 7 to 120cm

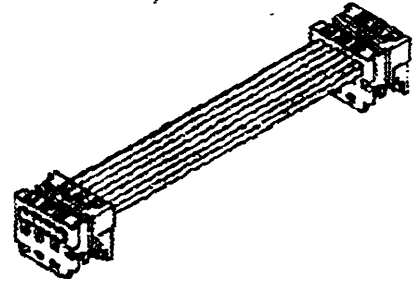

## Reference Information

- Packaging: Bag
- Mates With:

<b>Wire-to-Board</b>	<b>Picoflex PF-50 Header</b>	<b>Low Profile 90325</b>
		<b>Low Profile, Vertical, Kinked PC Tails, Polarizing Peg 90715</b>
		<b>Low Profile, Right Angle 90800</b>
		<b>Low Profile, Surface Mount Compatible, High Temperature 90779</b>
	<b>Picoflex Header</b>	<b>SMT 90814</b>

- Designed In: Millimeters

## Electrical

- Voltage: 250V
- Current: 1.2A

## Mechanical

- Mating Force: 1.7N
- Unmating Force: 0.25N
- Durability: 30 cycles max.

## Physical

- Housing: 6/6 nylon, UL 94V-0
- Contact: Phosphor Bronze Alloy
- Plating: 3-6µ" Tin/Lead
- Temperature: -20 to +105°C
- Insulation: Cable--Gray PVC
- Wire Range: 28 AWG

See 90327 and 6800 cable pages for more specifications



**DRAWING: Top, Front, Side View**

<b>ORDERING INFORMATION AND DIMENSIONS</b>	
<b>Circuits</b>	<b>Order No.</b>
4	92315-04XX
6	92315-06XX
8	92315-08XX
10	92315-10XX
12	92315-12XX
14	92315-14XX
16	92315-16XX
18	92315-18XX
20	92315-20XX
26	92315-26XX

<b>Length</b>	<b>XX</b>
7-99cm	07-99
100cm	01
105cm	02
110cm	03
115cm	04
120cm	05

Replace XX with length in cm (min. 7cm, max. 120cm), see table  
 Example: 92315-0832 is a cable with two 90327-0308, 32cm long

[ [Section Index](#) | [Fax Back](#) | [Order No. Index](#) | [Trade name Index](#) ]

[ [Welcome!](#) | [About Us](#) | [New](#) | [Products](#) | [Contact Us](#) | [Financial](#) | [Jobs](#) | [Feedback](#) ]

Top↑ © Copyright 1999 Molex Incorporated

