

Hospital Grade Devices GFCI Receptacles

15 & 20A, 125VAC

Pass & Seymour



Features


- SafeLock™ Protection: if critical components are damaged and ground fault protection is lost, power to receptacle is disconnected.
- Prevents line-load reversal miswire: no power to the face or downstream receptacles if wired incorrectly.
- Exceeds UL943 voltage surge requirements; survives 100x the required UL 3kA/6kV voltage surge test cycles.
- FSUL Listed (Federal Specification WC596).
- Trip indicator light (red LED).
- Side or internal screw-pressure-plate back wire with #10 – #14 AWG solid or stranded copper wire.
- Two back wire holes per terminal.
- Ground screw has a back wire clamp for easy installation.
- 1/4" thinner than competitors' GFCIs; leaves more room for wires in the box.
- Mounting screws are shipped captive in the device and wall plate for easier installation.
- High-impact-resistant thermoplastic construction.
- Extra-long strap.
- Button colors match the device face.
- Dual-direction test and reset buttons.
- Class A rated GFCI.
- Supplied with matching TP26 nylon wall plate.
- Tri-drive screws.

Tamper-Resistant Models


- Protects children: patented shutter system helps prevent improper insertion of foreign objects.
- Meets 2008 National Electrical Code® Tamper-Resistant requirements.

Specifications


- Supply Voltage: 125VAC, 60 Hz
- Supply Voltage Range: 102-132 VAC
- Trip Threshold: 5± 1mA
- Trip Time: 0.025 sec., nominal per UL Standard
- 20 Amp feed-thru capacity

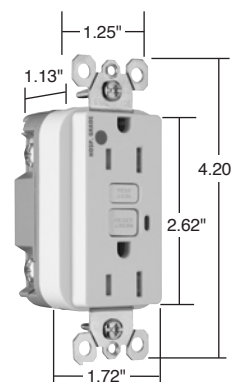

1595HGTRW

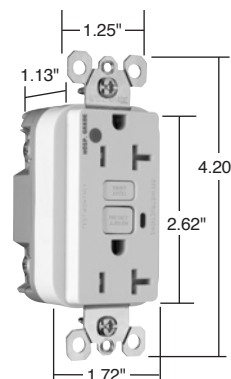


2095HGTRW

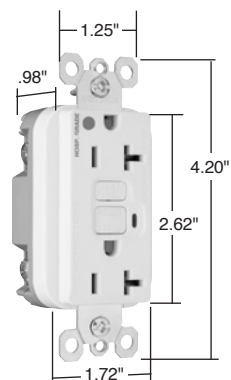

2095HGW

2 Pole, 3 Wire

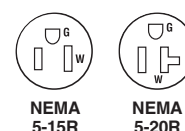

NEMA 5-15R

NEMA 5-20R

Catalog Number	Rating A. VAC		Color	NEMA Config. No.	3rd Party Compliance		
					 UL943 C22.2 No. 144	 UL498 C22.2 No. 42	FSUL WC596
Tamper-Resistant 15 Amp Duplex GFCI							
1595HGTRI	15	125	Ivory	5-15R	•	•	•
1595HGTRW	15	125	White	5-15R	•	•	•
1595HGTR	15	125	Brown	5-15R	•	•	•
1595HGTRGRY	15	125	Gray	5-15R	•	•	•
1595HGTRRED	15	125	Red	5-15R	•	•	•
1595HGTRLA	15	125	Light Almond	5-15R	•	•	•
Tamper-Resistant 20 Amp Duplex GFCI							
2095HGTRI	20	125	Ivory	5-20R	•	•	•
2095HGTRW	20	125	White	5-20R	•	•	•
2095HGTR	20	125	Brown	5-20R	•	•	•
2095HGTRGRY	20	125	Gray	5-20R	•	•	•
2095HGTRRED	20	125	Red	5-20R	•	•	•
2095HGTRLA	20	125	Light Almond	5-20R	•	•	•
15 Amp Duplex GFCI							
1595HGI	15	125	Ivory	5-15R	•	•	•
1595HGW	15	125	White	5-15R	•	•	•
1595HG	15	125	Brown	5-15R	•	•	•
1595HGGRY	15	125	Gray	5-15R	•	•	•
1595HGRED	15	125	Red	5-15R	•	•	•
1595HGLA	15	125	Light Almond	5-15R	•	•	•
20 Amp Duplex GFCI							
2095HGI	20	125	Ivory	5-20R	•	•	•
2095HGW	20	125	White	5-20R	•	•	•
2095HG	20	125	Brown	5-20R	•	•	•
2095HGGRY	20	125	Gray	5-20R	•	•	•
2095HGRED	20	125	Red	5-20R	•	•	•
2095HGLA	20	125	Light Almond	5-20R	•	•	•

For Configurable Solutions, see Page U-1.

All devices listed on this page conform to NEMA WD-1 and WD-6.