


### FEATURES:

- Converts BNC (Male) cables/connectors to stackable pin tip plugs for versatility
- BNC connector and pin tip plugs are molded directly onto the wire for pull strength durability and dust and moisture resistance.
- BNC center contact is Gold-plated Beryllium Copper for corrosion resistance, low contact resistance and long insertion life

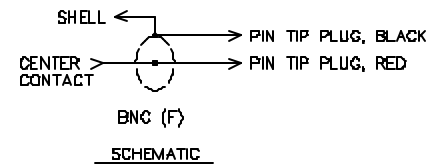

### MATERIALS:

BNC: Nickel-plated brass

Center Contact: Gold-plated Beryllium Copper

Insulation: black polypropylene

Wires: 20 AWG, PVC

Marking: "POMONA 3221"

Pin Tip Plugs: Gold-plated brass

Spring: Gold-plated Beryllium Copper

Insulation: polypropylene, black and red

### RATINGS:

Operating Voltage: Hand-Held testing: 30VAC/60VDC Max.

Hands free testing in controlled voltage environments: 500VRMS Max.

Operating Temperature: +55°C (+131°F) Max.

### ORDERING INFORMATION: Model 3221

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA

Sales: 800-490-2361 Fax: 888-403-3360  
Technical Assistance: 800-241-2060

PomonaACCESS 90336 (800) 444-6785 or (425) 446-6010469-2991  
More drawings available at [www.pomonaelectronics.com](http://www.pomonaelectronics.com)