




This is a sample photo.

<b>Order symbol</b>	PC 150/35 LG		
<b>EI. number</b>	<b>EAN-code</b>	6418074022134	
Sweden			
Denmark			
Finland	3420343		

**Including**  
Enclosure cover with cover screws, body with mounting screws and gasket.

**Product Properties**  
USA: UL Type 1, 4, 4X, 6  
EURO: IP 66/67 (EN 60529); IK 08 (EN 50102)

MNX PC

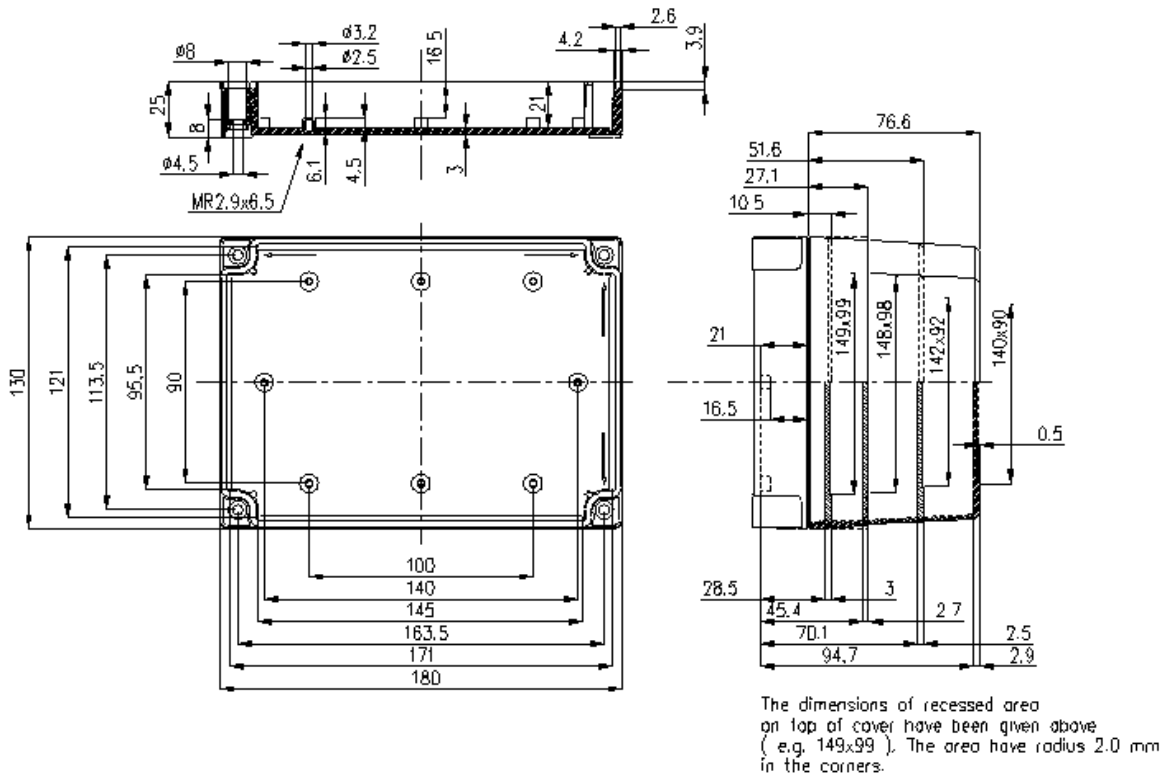

**Technical Information of Product Group**

Standard colour:	RAL 7035	Temp. range-in cont. use:	Max. +80 °C
Flame resistance:	UL94-5V (UL 746 C 5)	Temp. range-of material:	- 40 °C - + 120 °C

**Accessories**

Sealing bushing	DP 14553
Condensation water plug	MB 12189
Mounting screw	MR ZN2.9x6.5
Ventilation device	MB 10631
Inspection window	L 08
Cover screw	SS 14550L
Mounting plate	MIV 150
Swing door kit	HFP 180
DIN-Rail	MIV 15
DIN-Rail	MIN 10
DIN-Rail	MIN 15
DIN-Rail	MIV 10
Front plate	FP A 150/180
Hinge	TH A