


# 2108i

MODEL

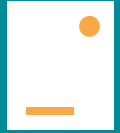


EUROTHERM  
CONTROLS


- Temperature indication
- Process indication
- Over-temperature protection
- Process value trip unit

Indicator  
and Alarm  
Unit

## Dimensions

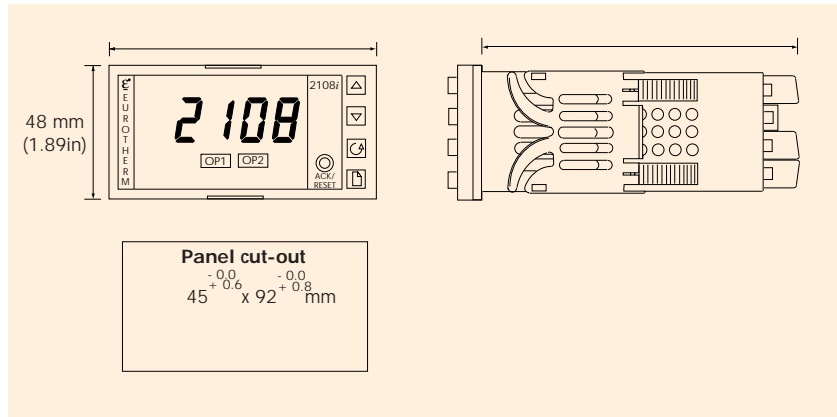

## Electrical connections

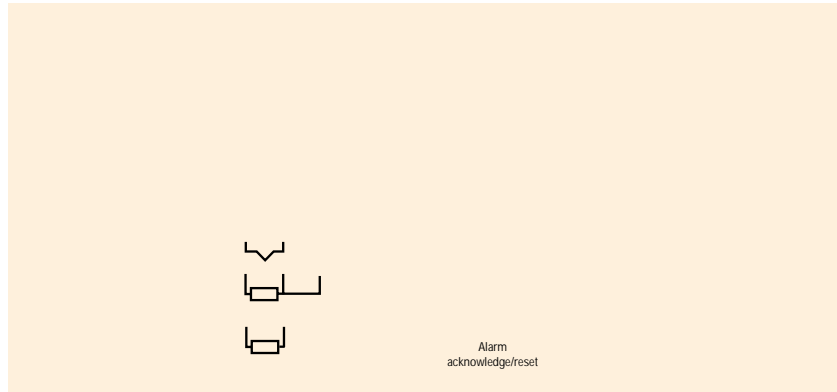

## Specifications

### Display:

4 digit, red or green. 15.9mm high characters

### Supply voltage:

100 to 240Vac -15%, +10%

### Operating ambients:

0-55°C, 5-95%RH non-condensing

### Panel sealing:

IP54, plug-in from front panel

### Relay ratings:

2A, 240Vac resistive

### Calibration accuracy:

$\pm 0.25\%$  of reading, or  $\pm 1^\circ\text{C}$ , or  $\pm 1\text{LSD}$  whichever is the greater

### Cold junction compensation:

> 15 to 1 rejection of ambient temperature change

### Input filtering:

Off-999.9 seconds

### EMC standards:

EN50081-2 and EN50082-2 generic standards for industrial environments

### Safety standard:

Meets EN61010, installation category II. Pollution degree 2

### Atmospheres:

Not suitable for use above 2000m or in explosive or corrosive atmospheres