



This is a sample photo.


Order symbol	PC 150/75 HG		
EI. number	EAN-code	6418074022189	
Sweden			
Denmark			
Finland	3420353		

Including
Enclosure cover with cover screws, body with mounting screws and gasket.

Product Properties
USA: UL Type 1,4, 4X, 6

EURO: IP 66/67 (EN 60529); IK 08 (EN 50102)

MNX PC

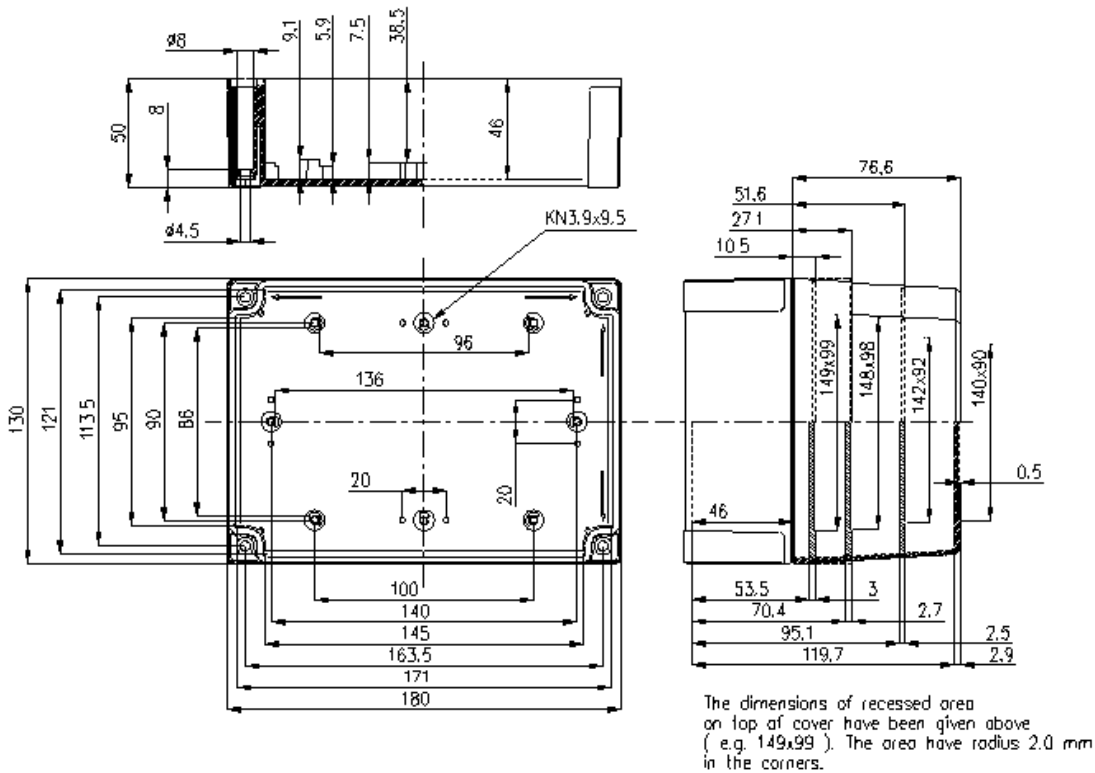

Technical Information of Product Group

Standard colour:	RAL 7035	Temp. range-in cont. use:	Max. +80 °C
Flame resistance:	UL94-5V (UL 746 C 5)	Temp. range-of material:	- 40 °C - + 120 °C

Accessories

Sealing bushing	DP 14553
Condensation water plug	MB 12189
Mounting screw	KN 3.9x9.5
Ventilation device	MB 10631
Inspection window	L 08
Cover screw	SS 14551H
Mounting plate	MIV 150
Swing door kit	HFP 180
DIN-Rail	MIV 15
DIN-Rail	MIN 10
DIN-Rail	MIN 15
DIN-Rail	MIV 10
Front plate	FP A 150/180
Hinge	TH A