

Cable and Cord Reels

Weatherproof and Static Discharge Reels



HBL501431W



HBL50SD



HBL14PB

Weatherproof Cable & Static Discharge Reels

Description	Catalog Numbers	Cable Feet	Meters	Volts	Cable Type	Amps	Weight lbs.	kg
14" weatherproof reel.	HBL501431W†	50	15.2	600	14/3 SOW-A	15	55	24
16" weatherproof reel.	HBL501232W†	50	15.2	600	12/3 SOW-A	20	80	36.3
16" weatherproof reel.	HBL501242W†	50	15.2	600	12/4 SOW-A	16	86	38.7
16" weatherproof reel.	HBL501032W†	50	15.2	600	10/3 SOW-A	25	86	38.7
16" weatherproof reel.	HBL501042W†	50	15.2	600	10/4 SOW-A	20	92	41.1
Static discharge reel.	HBL50SD	50	15.2	—	Single 3/32" Steel	—	12	5.4
Static discharge reel.	HBL50YSD	50♦	15.2	—	Dual (Y) 3/32" Steel	—	13	5.9
14" pivot base.	HBL14PB	—	—	—	—	—	5	2.27
16" pivot base.	HBL16PB	—	—	—	—	—	13	5.9


Notes: † All weatherproof cable reels are supplied with wire leads.

♦ 35ft./10.6m + Dual 15ft./4.5m for "Y".

Power supply cable not supplied.


Specifications

Weatherproof Reel										
In (mm)	A	B	C	D	E	F	G	H	I	J
14" reel	6.50" (165)	8.12" (206)	16.25" (413)	13.75" (349)	3.00" (76)	12.19" (310)	3.00" (76)	3.00" (76)	3.00" (76)	6.50" (165)
16" reel	6.50" (165)	9.12" (232)	18.25" (464)	15.75" (399)	3.00" (76)	14.19" (360)	6.00" (152)	6.00" (152)	4.94" (125.5)	6.50" (165)

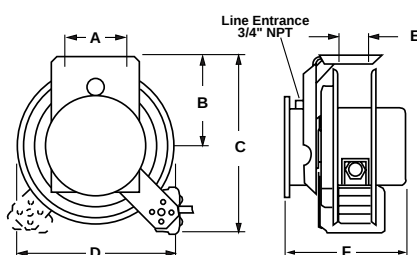

Weatherproof Cable Reels	
Listings/Certifications	UL 355 and CSA C22.2 No. 21. Type 4X enclosure CAN/CSA - C22.2 No. 21.
Operation	Dry indoor & wet and damp outdoor non-hazardous location.
Classification	Agriculture, automotive, commercial and industrial applications.

Static Discharge Reel

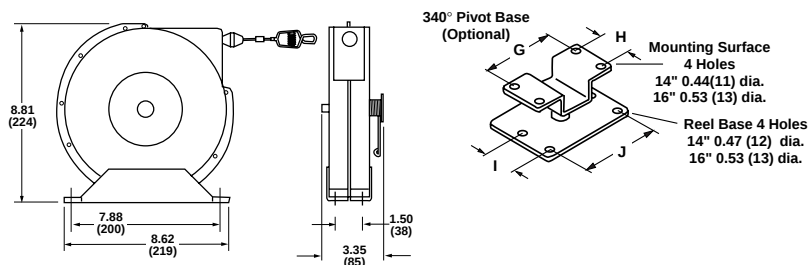

Pivot base for use only with Weatherproof Cable Reel.