

# industrial boxes 24300, steel IP 55

## safety boxes

### technical characteristics

- Resistance to external mechanical impact: IK 09.
- Textured epoxy polyester powder paint finish, colour grey RAL 7032 or red RAL 3000 for safety enclosures.
- Closure by screw or side key lock with 3 mm double bar insert. Possibility of mounting lock ref. **51259** or **51258** and insert shape ref. **51282** (to be ordered separately.).
- Sealing cap fitted as standard.
- 4 nuts welded in rear of enclosure. These enable attachment of a mounting plate (supplied as an accessory) or a customised chassis
- Polyurethane sealing gasket.
- M 6 x 8 earthing screw on both body and cover to maintain continuity.

### applications

- Safety and alarm systems (fire alarm for example) which can be fitted with mounting plates and modular equipment



### boxes selection table




internal dimensions in mm			box reference		box with side key lock 3 mm double bar ref.		
			plain door	glazed door	plain door	glazed door	glazed door 2 mm thick window
height	width	depth					
180	130	96	<b>24310</b>	<b>24510</b>	<b>24311</b>	<b>24511</b>	<b>24512</b>
180	165	96	<b>24320</b>	<b>24520</b>	<b>24321</b>	<b>24521</b>	<b>24522</b>
230	210	126	<b>24340</b>	<b>24540</b>	<b>24341</b>	<b>24541</b>	<b>24542</b>

### accessories selection table

- Mounting plates in zinc plated steel, with fixings.
- Kit for modular equipment, with fixings.

internal dimensions in mm			mounting plate reference	kit for modular equipment reference	number of modules
height	width	depth			
180	130	96	<b>24210</b>	<b>80151</b>	4
180	165	96	<b>24220</b>	—	—
230	210	126	<b>24230</b>	<b>80154</b>	8

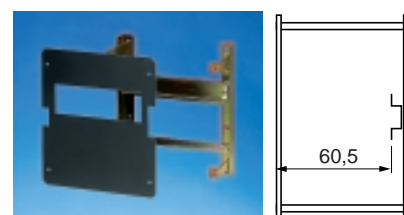

### accessoires

- Set of 2 wall fixing lugs, zinc plated steel, and fixings (without sealing washer, downgraded IP).
- Break glass assembly (hammer with holder).

reference	description
<b>21243</b>	Set of 2 wall fixing lugs
<b>21329</b>	Break glass assembly