
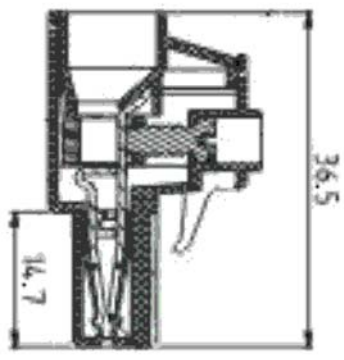
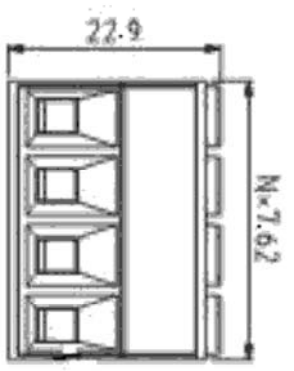


Rev	AWO #	Description	Date	Appr
-	9427	RELEASED	3/20/09	

APPROVED: \_\_\_\_\_

DATE: \_\_\_\_\_ TITLE: \_\_\_\_\_

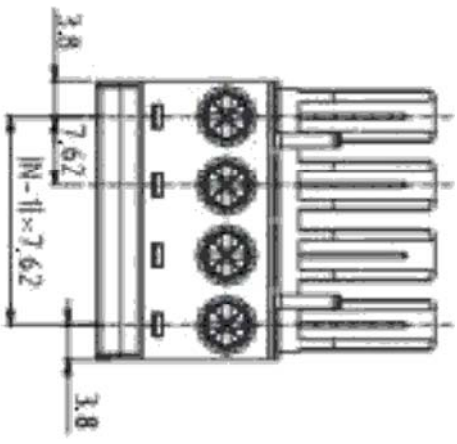

**SPECIFICATIONS:**

- Material: Insulator: PA66, rated UL 94V-0
- Insulator color: Green
- Contact: Bronze, Tin plated
- Screw: Steel, M3.5/Zn plated
- Electrical: Operation voltage: 300 VAC max
- Current rating: 32 Amps max per Pole
- Dielectric withstanding voltage: 1600 VAC for 1 minute
- Mechanical: Torque (Lb-in): 7
- Solid wire: 24-8 AWG
- Environmental: Operating temperature: -40°C to +105°C
- Lead free, RoHS compliant.
- Recommended soldering temp: 235°C for 5 sec.



UNLESS OTHERWISE SPECIFIED	
ALL DIMENSIONS ARE MM	
TOLERANCES: EXCEPT AS NOTED	
INCHES	HOLDS
.X ± .10	ØX ± .10
.XX ± .020	ØXXX ± .015
.XXX ± .015	ØXXX ± .010
APPROVALS	DATE
DRAWN	DY
CHECKED	
APPROVED	

<b>ADAM TECH</b>	
909 Railway Avenue, Union, NJ 07083	
Phone: 908-687-5000 Fax: 908-687-5710	
TITLE	7.62MM PITCH
TERMINAL BLOCK, PLUGS FOR PLUGGABLE,	
SIZE	PART NO.
X	EB44-XX-G
REF:	S00007T
SCALE:	NTS
SHEET	1 OF 1