

Material Specification

Plug & Socket housing:
Polyamide 6.

Colour:
White

Terminal insert:
Brass, chemically tinned.

Optional Wire Protector:
'402A' - Phosphor bronze.

Terminal screw:
Zinc plated steel.

Fire Performance

Flammability:
UL94-V2.

Maximum working temp:
150°C

Continuous working temp:
110°C

Approvals

See pages CO21-22.

Screw Size

4212 Series: M 3

Removable Shroud on Socket.

Cat Ref.	Pack
----------	------

Length of pins: 19.0 mm

4212-1/19	50
4212-1/19/402A	50

Length of pins: 20.5 mm


4212-1/20.5	50
4212-1/20.5/402A	50

Length of pins: 22.0 mm

4212-1/22	50
4212-1/22/402A	50



- Raised Base Plug

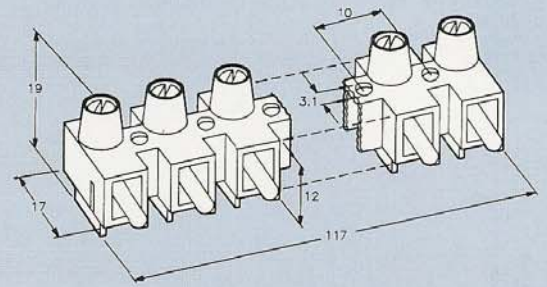

Cat Ref.	Pack
----------	------

Length of pins: 19.0 mm

4212L-1/19	50
4212L-1/19/402A	50

Length of pins: 20.5 mm


4212L-1/20.5	50
4212L-1/20.5/402A	50

Length of pins: 22.0 mm

4212L-1/22	50
4212L-1/22/402A	50



- Level Base Plug

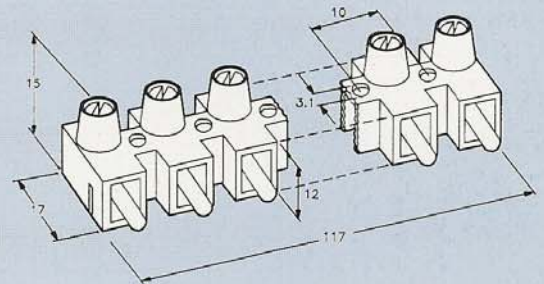

Cat Ref.	Pack
----------	------

4212-2


4212-2/402A

50

50



- Raised Base Socket

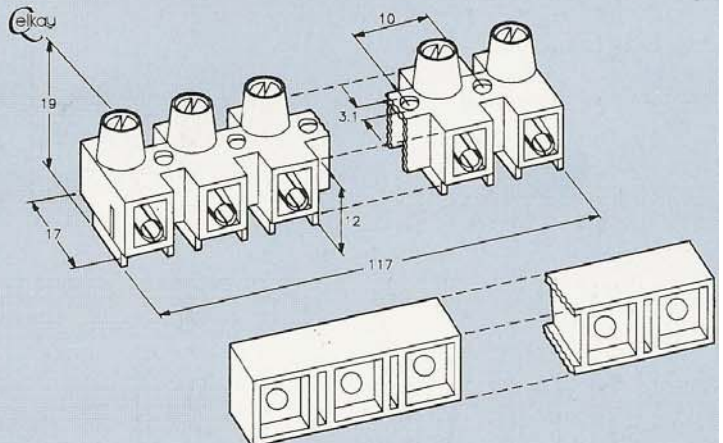

Application	Applicable Standard	Wire Capacity	Rating	Voltage
Installation	BS EN 60598 - 1: 1993	4.0mm ²	20 - 25A	250V
Domestic Appliances	EN 60 335 Part 1: 1988	1.5 - 2.5mm ²	10A	250V

Cut & marked versions of these terminal block and connector products are available to special order

All dimensions given in millimetres