

## RockStar® Housings IP65 / NEMA Type 4X

End locking, lower side

Size 3


Hood



Hood, Cable Entry sideways



a	Version	Cover	b (mm)	Designation	Order No.
M20	with thread		52	HDC 06B TSLU 1M20G	1788100000
M20	with thread		52	HDC 06B TSLU 1M20G	1805930000
M25	with thread		52	HDC 06B TSLU 1M25G	1788090000
M25	with thread		72	HDC 16D TSLU 1M25G	1787480000
M32	with thread		72	HDC 16D TSLU 1M32G	1787470000
PG 13.5	with thread		52	HDC 06B TSLU 1PG13G	1670530000
PG 16	with thread		52	HDC 06B TSLU 1PG16G	1652520000
PG 21	with thread		72	HDC 16D TSLU 1PG21G	1652560000
PG 29	with thread		72	HDC 16D TSLU 1PG29G	1652580000

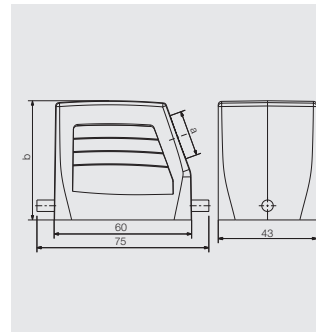


D

Hood, Cable Entry at top




a	Version	Cover	b (mm)	Designation	Order No.
M20	with thread		52	HDC 06B TOLU 1M20G	1788120000
M25	with thread		52	HDC 06B TOLU 1M25G	1788110000
M25	with thread		72	HDC 16D TOLU 1M25G	1787500000
M32	with thread		72	HDC 16D TOLU 1M32G	1787490000
PG 13.5	with thread		52	HDC 06B TOLU 1PG13G	1670500000
PG 16	with thread		52	HDC 06B TOLU 1PG16G	1652640000
PG 21	with thread		72	HDC 16D TOLU 1PG21G	1652680000
PG 29	with thread		72	HDC 16D TOLU 1PG29G	1652700000

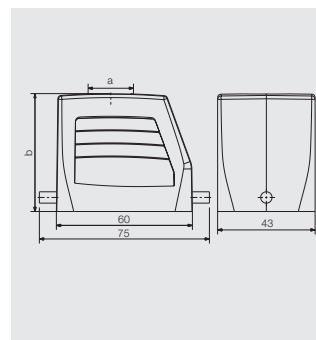

Cover



Version	Designation	Order No.
for hoods	HDC 06B DMDL 1LB	1665210000

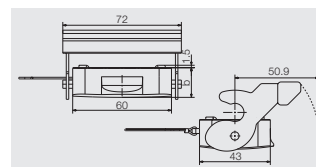

End locking, lower side

Size 3


Base



Bulkhead housing




Version	Cover	b (mm)	Designation	Order No.
	without cover	29	HDC 06B ALU	1202100000
	with cover	47	HDC 06B ADLU	1202500000

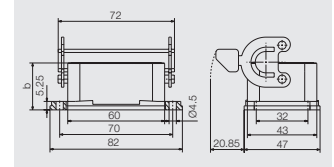

Base housing



a	Version	Cover	b (mm)	Designation	Order No.
M20	with thread	without cover	54	HDC 06B SLU 1M20G	1900460000
M20	with thread	with cover	72	HDC 06B SDLU 1M20G	1900360000
M20	with thread	without cover	54	HDC 06B SLU 2M20G	1788140000
M20	with thread	with cover	72	HDC 06B SDLU 2M20G	1788170000
M25	with thread	without cover	54	HDC 06B SLU 1M25G	1900480000
M25	with thread	with cover	72	HDC 06B SDLU 1M25G	1900380000
M25	with thread	without cover	74	HDC 16D SLU 1M25G	1900880000
M25	with thread	with cover	92	HDC 16D SDLU 1M25G	1900820000
M25	with thread	without cover	54	HDC 06B SLU 2M25G	1788130000
M25	with thread	without cover	74	HDC 16D SLU 2M25G	1787520000
M25	with thread	with cover	92	HDC 16D SDLU 2M25G	1787540000
M25	with thread	with cover	72	HDC 06B SDLU 2M25G	1788160000
M32	with thread	without cover	74	HDC 16D SLU 1M32G	1900900000
M32	with thread	without cover	74	HDC 16D SLU 2M32G	1787510000
PG 16	with thread	without cover	54	HDC 06B SLU 1PG16G	1652750000
PG 16	with thread	with cover	72	HDC 06B SDLU 1PG16G	1652980000
PG 16	with thread	without cover	54	HDC 06B SLU 2PG16G	1652760000
PG 16	with thread	with cover	72	HDC 06B SDLU 2PG16G	1652990000
PG 21	with thread	without cover	74	HDC 16D SLU 2PG21G	1652840000

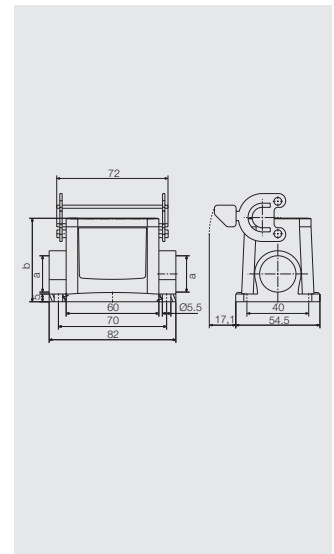


D

Coupling hood



a	Version	Cover	b (mm)	Designation	Order No.
PG 16	with thread		55	HDC 06B KLU 1PG16G	1653200000
PG 21	with thread		75	HDC 16D KLU 1PG21G	1653230000

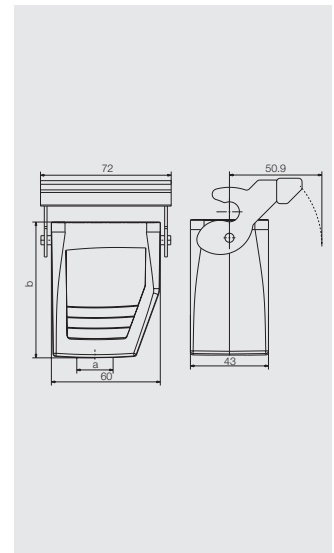

Cover



Version	Designation	Order No.
for bases	HDC 06B DODL 2BO	1665200000

