

RockStar® Housings IP65 / NEMA Type 4X

End locking, lower side

Size 10


Hood



Hood, Cable Entry sideways



a	Version	Cover	b (mm)	Designation	Order No.
M32	with thread		79	HDC 32B TSLU 1M32G	1788420000
PG 29	with thread		79	HDC 32B TSLU 1PG29G	1667120000

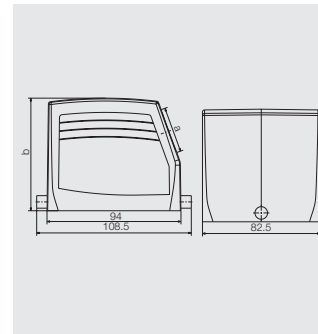


D

Hood, Cable Entry at top



a	Version	Cover	b (mm)	Designation	Order No.
M32	with thread		79	HDC 32B TOLU 1M32G	1788450000
PG 29	w. cable gland		79	HDC 32B TOLU 1PG 29G	1219300000

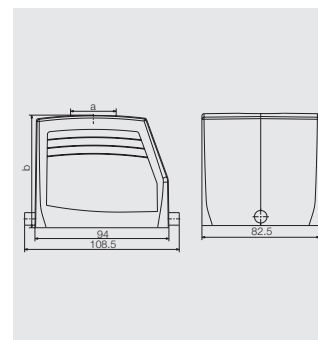

End locking, lower side

Size 10


Base



Bulkhead housing




Version	Cover	b (mm)	Designation	Order No.
	with cover	55	HDC 32B ADLU	1219800000
	without cover	38	HDC 32B ALU	1219500000

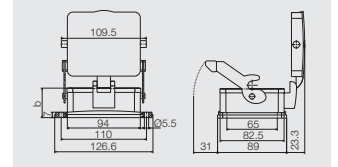

Base housing



a	Version	Cover	b (mm)	Designation	Order No.
M32	with thread	without cover	79	HDC 32B SLU 1M32G	1902670000
M32	with thread	with cover	96	HDC 32B SDLU 1M32G	1902650000
M32	with thread	without cover	79	HDC 32B SLU 2M32G	1788470000
M32	with thread	with cover	96	HDC 32B SDLU 2M32G	1788490000

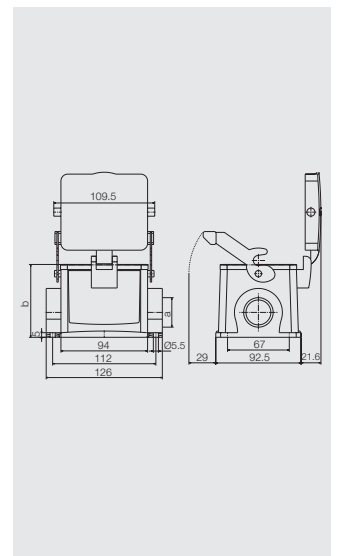

D

Coupling hood



a	Version	Cover	b (mm)	Designation	Order No.
M32	with thread		83	HDC 32B KLU 1M32G	1788500000

