

# 12 Self-Adjusting Insulation Strippers

patented




12 40 200




0.03 - 10.0 mm<sup>2</sup>



Adjustable length stop

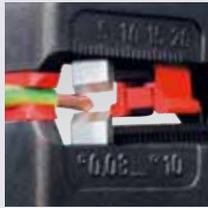

Precise stripping prevents damage to the conductor

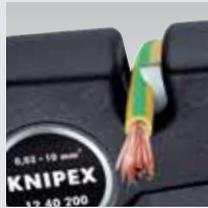

Wire cutter for multiple strand wire cables up to 10.0 mm<sup>2</sup>

- ▶ for single, multiple and fine-stranded wire cables with plastic or rubber insulation
- ▶ adjusts automatically to the respective cable cross-section, which prevents damage to the conductor
- ▶ cutting depth can be adjusted for different insulation materials
- ▶ with wire cutter for copper and aluminium wires, multiple strand up to 10 mm<sup>2</sup> and single strand up to 6 mm<sup>2</sup>
- ▶ smoothly operating mechanism
- ▶ easily interchangeable blades and plastic jaws
- ▶ low weight
- ▶ body made of tough fibreglass reinforced plastic

**KNIPEX** special

KNIPEX Self-Adjusting Insulation Strippers are indispensable for the electrical installation; fast and secure working in a large range of application.

### Model 12 40 200:

- ▶ range of application: conductors 0.03 - 10.0 mm<sup>2</sup>
- ▶ for thin ribbon cables up to 10.0 mm width in a single pass
- ▶ length stop adjustable from 3.0 - 18.0 mm and easily interchangeable

### Model 12 50 200:

- ▶ range of application: conductors 2.5 - 16.0 mm<sup>2</sup>

Article-No.	EAN-	Stripping capacities		Length stop	
Length	Code				
mm	4003773-	mm <sup>2</sup>	AWG	mm	g
12 40 200	026662	0.03-10.0	32 - 7	3.0-18.0	200
12 49 01	026679	spare blades	for 12 40 200		
12 49 02	026686	spare clamping jaws	for 12 40 200		
12 49 03	026693	spare length stop	for 12 40 200		
12 50 200	034407	2.5-16.0	13 - 5		200
12 59 01	034414	spare blades	for 12 50 200		
12 59 02	034421	spare clamping jaws	for 12 50 200		

# 12 Self-Adjusting Insulation Stripper



12 60 135

- ▶ for single, multiple and fine-stranded wire cables with plastic or rubber insulation of 0.08 - 1.0 mm<sup>2</sup>
- ▶ adjusts automatically to the respective cable cross-section, which prevents damage to the conductor
- ▶ for thin ribbon cables in a single pass
- ▶ with wire cutter for copper and aluminium wires, multiple strand up to 1.0 mm<sup>2</sup>
- ▶ length stop adjustable from 2.5 - 7.0 mm

- ▶ easily exchangeable blades
- ▶ smoothly operating mechanism
- ▶ low weight
- ▶ body made of tough fibreglass reinforced plastic

Article-No.	EAN-	Stripping capacities		Length stop	
Length	Code				
mm	4003773-	mm <sup>2</sup>	AWG	mm	g
12 60 135	022169	0.08-1.0	28 - 17	2.5-7.0	90
12 69 135	022176	spare blades for 12 60 135			



Adjusts automatically to the respective cable cross-section from 0.08 - 1.0 mm<sup>2</sup>