

40

40 Universal Grip Pliers



40 04 250

- holds round, section and flat material securely
- heavy duty model
- with adjustment screw and release lever
- one-hand operation
- high clamping pressure due to toggle lever action

- plier body: high strength special grade steel
- inserted jaws made from Chrome Vanadium steel, drop forged

| Article-No. | EAN- | Head | Handles | Clamping width | |
|------------------|------------------|---------------|---------------|---|-----|
| Length mm | Code 4003773- | | | <div>○</div> mm <div>□</div> mm <div>⬡</div> mm | g |
| 40 04 180 | 022190 | nickel plated | nickel plated | 8 - 35 25 6 - 26 | 325 |
| 250 | 002710 | nickel plated | nickel plated | 8 - 35 30 8 - 30 | 530 |

41

41 Grip Pliers



41 04 250

Style 0: jaws for round workpieces, with wire cutter


- holds round, section and flat material securely
- heavy duty model
- with adjustment screw and release lever
- one-hand operation
- high clamping pressure due to toggle lever action

- plier body: high strength special grade steel
- inserted jaws made from Chrome Vanadium steel, drop forged



41 14 250

Style 1: jaws with double prism for round, section and flat material

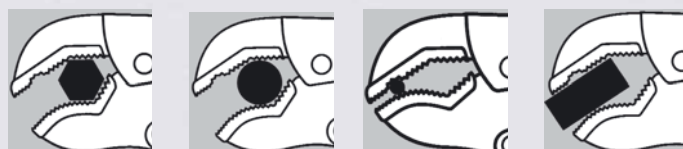

Example 41 14 250



41 24 225

Style 2: straight jaws for flat material



41 34 165

Style 3: Long-Nose Grip Plier, narrow, long jaws

| Article-No. | EAN- | Style | Head | Handles | Clamping width | |
|------------------|------------------|----------|---------------|---------------|---|-----|
| Length mm | Code 4003773- | | | | <div>○</div> mm <div>□</div> mm <div>⬡</div> mm | g |
| 41 04 180 | 002741 | 0 | nickel plated | nickel plated | 8 - 30 20 6 - 24 | 360 |
| 250 | 002758 | | | | 8 - 40 20 8 - 30 | 530 |
| 300 | 022183 | | | | 10 - 65 30 10 - 34 | 930 |
| 41 14 250 | 023470 | 1 | nickel plated | nickel plated | 36 36 13 - 36 | 560 |
| 41 24 225 | 023487 | 2 | nickel plated | nickel plated | 42 16 0 - 24 | 505 |
| 41 34 165 | 047858 | 3 | nickel plated | nickel plated | 6.5 - 30 10 6 - 24 | 200 |