




Tamper-Resistant, Rear Keystone Mounting.

Nylon Plates Virtually Unbreakable.

## Angled Plates

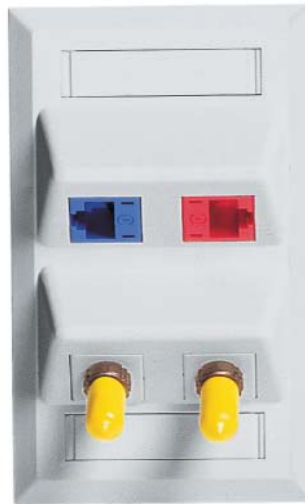

Provides application flexibility at the workstation.

TIA/EIA-606-A label fields.

Consistent color match.

### FEATURES

- Jacks or A/V connectors snap mount at 45° angle - ST-style, SC duplex and coax outlets.
- Provide for 606 location labeling compatible with today's needs and future moves, adds, and changes.
- Supports multiple applications at station site.
- Available in four colors.

### SPECIFICATIONS

- ◆ High-impact, UL 94V-0 rated thermoplastic.
- ◆ Plates are 2.75" x 4.5" (69.8 mm x 114.3 mm).

### STANDARDS/LISTINGS/VERIFICATIONS

- UL and cUL listed.
- ANSI/TIA/EIA-606A station labeling capability.

Hubbell Premise Wiring's angled wall plates offer 45° jack and Audio/Video connector mounting along with TIA/EIA-606A station labeling ability and the traditional features of HPW's standard flush wall plates.

The AFP plates are designed for flush mounting any of Hubbell's **XCELERATOR™** jacks or Audio/Video connectors.

The design of the AFP plate positions the patch cord down at an angle of 45°, which provides additional protection against exceeding the minimum bend radius. The 45° angle also protects the patch cord/jack connection from being damaged from office furniture. AFP plates include 2 smooth locations for adhesive labels or can be fitted with optional snap in clear label covers and paper inserts.

## ORDERING INFORMATION


## Angled Face Plates, 4-port



AFP14W

| Color        | Catalog No.   |
|--------------|---------------|
| Gray         | <b>AFP14G</b> |
| Office White | <b>AFP14</b>  |
| Telco Ivory  | <b>AFP14I</b> |
| White        | <b>AFP14W</b> |

## DIMENSIONS

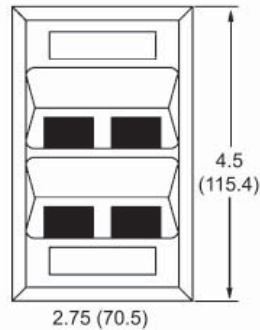

## ACCESSORIES

## XCELERATOR™ Jacks, Category 6 and 5e

|             | Catalog No.    |
|-------------|----------------|
| Category 5e | <b>HXJ5EXX</b> |
| Category 6  | <b>HXJ6XX</b>  |

XX = Color:

'AL' = Almond

'B' = Blue

'BK' = Black

'EI' = Electric Ivory

'GL25' = Gold\*

'GY' = Gray

'GN' = Green

\* 25-packs only.

'OW' = Office White

'OR' = Orange

'P25' = Purple\*

'R' = Red

'TI' = Telco Ivory

'W' = White

'Y' = Yellow



## Patch Cords, Category 6 and 5e

|             | Catalog No.     |
|-------------|-----------------|
| Category 5e | <b>PCX5EXX*</b> |
| Category 6  | <b>PCX6XX**</b> |

XX = Standard Color:

'B' = Blue; 'BK' = Black;

'GY' = Gray; 'Y' = Yellow

For other colors replace color designation with one of the following:

OR = Orange, R = Red, GN = Green, P = Purple, W = White

\* = Standard Length: '01' = 1'; '03' = 3'; '05' = 5'; '07' = 7'; '10' = 10'; '15' = 15'; '20' = 20';

'25' = 25'; '30' = 30'; '35' = 35'; '40' = 40'; '45' = 45'; '50' = 50'; '55' = 55'; '60' = 60';

'75' = 75'; '100' = 100'

\*\* = Standard Length: '03' = 3'; '06' = 6'; '08' = 8'; '10' = 10'; '12' = 12'; '16' = 16';

'20' = 20'



## Audio/Video Connectors

| Description (Office White)  | Catalog No.   |
|-----------------------------|---------------|
| Blank Module                | <b>SFB10</b>  |
| F-Type Coupler Bulkhead F/F | <b>SFFX</b>   |
| RCA Solder Coupler (Red)    | <b>SFRCR</b>  |
| S-Video F/F Coupler (Black) | <b>SFSVBK</b> |
| SC Simplex, SM/MM           | <b>SFSC</b>   |
| ST Style, SM/MM             | <b>SFST</b>   |

\* Consult the Full Line Catalog (pages B8-B11) for a complete listing of Hubbell's family of Audio/Video Connector options and colors.



## UTP Cable, SPEEDGAIN® Category 5E, 4-Pair



| Color  | Catalog No. Spool | Riser REELEX*   | Catalog No. Plenum Spool | REELEX*         |
|--------|-------------------|-----------------|--------------------------|-----------------|
| Blue   | <b>C5EPSRB</b>    | <b>C5EPRRB</b>  | <b>C5EPSPB</b>           | <b>C5EPRPB</b>  |
| Gray   | <b>C5EPSRGY</b>   | <b>C5EPRRGY</b> | <b>C5EPSPGY</b>          | <b>C5EPRPGY</b> |
| White  | <b>C5EPSRW</b>    | <b>C5EPRRW</b>  | <b>C5EPSPW</b>           | <b>C5EPRPW</b>  |
| Yellow | <b>C5EPSRY</b>    | <b>C5EPRRY</b>  | <b>C5EPSPY</b>           | <b>C5EPRPY</b>  |

\* REELEX is licensed and patented by Windings Inc.

## Hubbell Labeling Solutions\*

|                                   |                  |
|-----------------------------------|------------------|
| Face Plate Labels, white adhesive | <b>XPLFPA10W</b> |
| Face Plate Labels, white paper    | <b>XPLFP10W</b>  |
| Face Plate Labels, clear adhesive | <b>XPLFPA10C</b> |
| Port Icon Labels, white adhesive  | <b>XPLIPA10W</b> |
| Port Icon Labels, clear adhesive  | <b>XPLIPA10C</b> |

## Pre-Printed Icon Label Booklets (5-packs)

|                                             |                 |
|---------------------------------------------|-----------------|
| Icon Labels, clear adhesive with black text | <b>XPICONS</b>  |
| Icon Labels, clear adhesive with white text | <b>XPICONSW</b> |

\* Contact our website at [www.hubbell-premise.com](http://www.hubbell-premise.com) for our unique Labeling Software.

## UTP Cable, NEXTSPEED® Category 6, 4-Pair



| Color  | Catalog No. Spool | Riser REELEX* | Catalog No. Plenum Spool | REELEX*       |
|--------|-------------------|---------------|--------------------------|---------------|
| Blue   | <b>C6SRB</b>      | <b>C6RRB</b>  | <b>C6SPB</b>             | <b>C6RPB</b>  |
| Gray   | <b>C6SRGY</b>     | <b>C6RRGY</b> | <b>C6SPGY</b>            | <b>C6RPGY</b> |
| White  | <b>C6SRW</b>      | <b>C6RRW</b>  | <b>C6SPW</b>             | <b>C6RPW</b>  |
| Yellow | <b>C6SRY</b>      | <b>C6RRY</b>  | <b>C6SPY</b>             | <b>C6RPY</b>  |

\* REELEX is licensed and patented by Windings Inc.



## Hubbell Premise Wiring

HUBBELL INCORPORATED (Delaware)

14 Lord's Hill Road • Stonington, CT 06378-0901 • (860) 535-8326 • 800-626-0005

Fax: (860) 535-8328 • Internet site: <http://www.hubbell-premise.com>

## Worldwide Locations

|                                         |                   |                        |
|-----------------------------------------|-------------------|------------------------|
| Hubbell Premise Wiring, Asia Pacific    | 852-2836-7131     | Fax: 852-2836-7132     |
| Hubbell Canada Inc.                     | 905-839-1138      | Fax: 905-839-9108      |
| Hubbell Premise Wiring, Central America | 506-309-4158      | Fax: 506-260-1616      |
| Hubbell Premise Wiring, China           | 8621-6309-0119    | Fax: 8621-6309-0122    |
| Hubbell Premise Wiring, Colombia        | 571-245-8940      | Fax: 571-340-0925      |
| Hubbell Premise Wiring, Europe          | 44-01283 500500   | Fax: 44-01283 500400   |
| Hubbell Int'l. Inc., Korea Branch       | 82-2-(0)2607-1363 | Fax: 82-2-(0)2603-7386 |

|                                       |                  |                       |
|---------------------------------------|------------------|-----------------------|
| Hubbell Premise Wiring, Latin America | 305-408-4501     | Fax: 305-408-8201     |
| Hubbell de Mexico, S.A. de C.V.       | (5255) 9151-9999 | Fax: (5255) 9151-9989 |
| Hubbell Premise Wiring, Middle East   | 971-4-393-4192   | Fax: 971-4-393-4194   |
| Hubbell-Taian Co., Ltd., Taiwan       | 886-2-2522-1862  | Fax: 886-2-2522-1872  |
| Hubbell Premise Wiring, Turkey        | 90-216-313-5016  | Fax: 90-216-414-8148  |
| Hubbell Premise Wiring, Venezuela     | 58-416-680-7453  | Fax: 58-281-274-7900  |