




A3 Horizontal

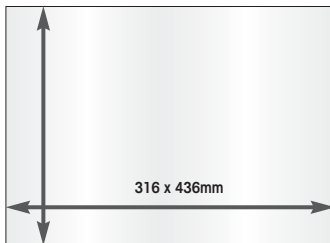


A3 Vertical

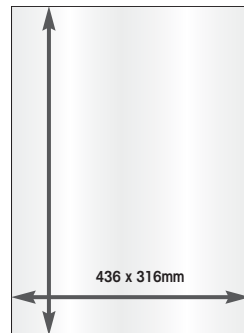


A4 Horizontal

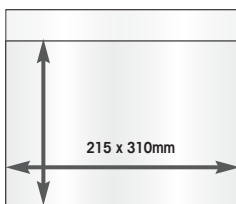


A4 Vertical

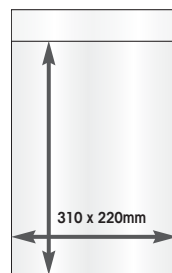


A5 Horizontal

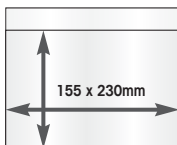


A5 Vertical

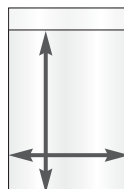

A6 Horizontal

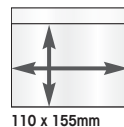


A6 Vertical

 


A7 Horizontal



 +1122 Horizontal



+1111

 


Pockets shown not to scale

**INDUSTRIAL
STRENGTH
POCKETS**

- Industrial quality pockets with folded edges
- Ideal for when documentation needs to be kept clean
- For use with various sized inserts from A3-A7 in vertical and horizontal formats


A range of document pockets to suit most environments with magnetic or self-adhesive strips also available as clip on and tie on to suit wire bins and cages. The adhesive pockets are supplied with an aggressive adhesive tape along the top and bottom edge (A7 pocket has tape along the top edge only) for a permanent fixing. The magnetic pockets are supplied with a magnetic edge along the top, so that they can be simply lifted and relocated when necessary. The tie-on pockets can secure around a maximum diameter of 60mm, whilst clip-on pockets are ideal for use on wire bins and cages.

Magnetic Pockets

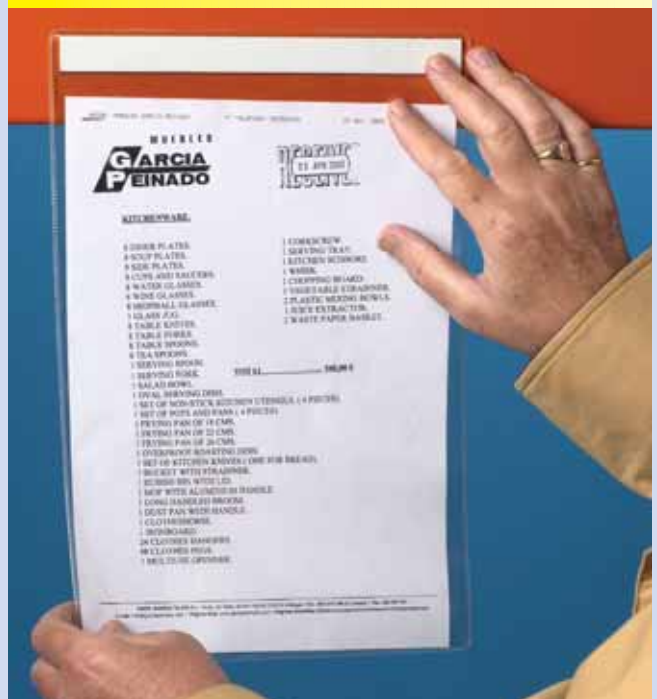

Ref	Size (H x W)	Pack
MP1122/10	110mm x 215mm	10
MP1111/10	110mm x 110mm	10
MP3H/10	316mm x 436mm	10
MP3V/10	436mm x 316mm	10
MP4H/10	215mm x 310mm	10
MP4H/50	215mm x 310mm	50
MP4V/10	310mm x 220mm	10
MP4V/50	310mm x 220mm	50
MP5H/10	155mm x 230mm	10
MP5H/50	155mm x 230mm	50
MP5V/10	215mm x 160mm	10
MP5V/50	215mm x 160mm	50
MP6H/10	110mm x 155mm	10
MP6V/10	150mm x 110mm	10
MP7H/100	60mm x 110mm	100

Self-adhesive Pockets

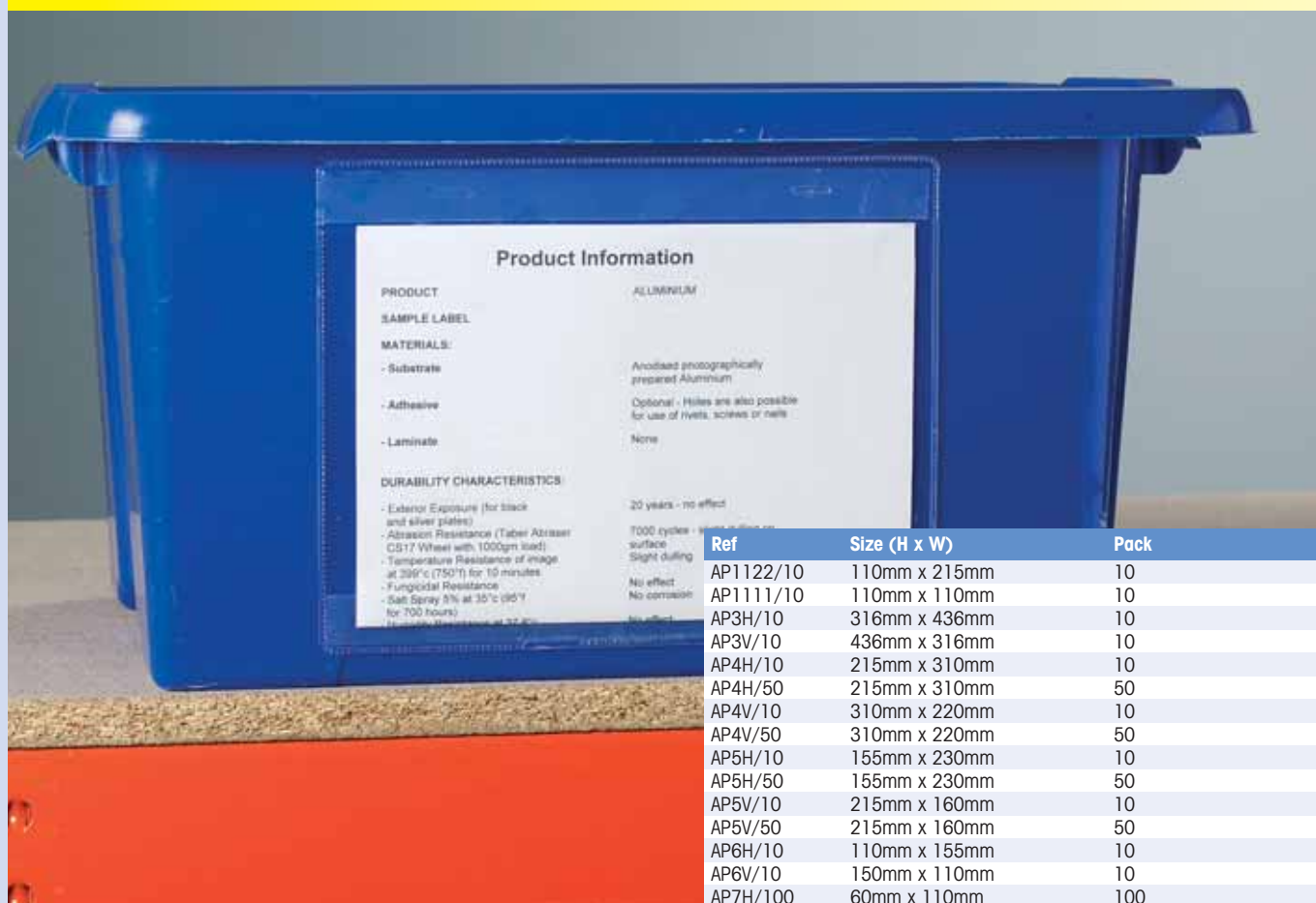

Clip On Pockets



Ref	Size (H x W)	Pack
CP1122/10	110mm x 215mm	10
CP1111/10	110mm x 110mm	10
CP4H/10	215mm x 310mm	10
CP4V/10	310mm x 220mm	10
CP5H/10	155mm x 230mm	10
CP5V/10	215mm x 160mm	10
CP6H/10	110mm x 155mm	10
CP6V/10	150mm x 110mm	10
CP7H/100	60mm x 110mm	100

Tie On Pockets



Ref	Size (H x W)	Pack
TP1122/10	110mm x 215mm	10
TP1111/10	110mm x 110mm	10
TP4H/10	215mm x 310mm	10
TP4V/10	310mm x 220mm	10
TP5H/10	155mm x 230mm	10
TP5V/10	215mm x 160mm	10
TP6H/10	110mm x 155mm	10
TP6V/10	150mm x 110mm	10
TP7H/100	60mm x 110mm	100