


PREMIUM STAINLESS STEEL TWEEZERS

High quality electronics tweezers manufactured from anti-magnetic, anti-acid stainless steel. Working tips are hand finished for precise alignment.

Cat. No.	Description	Net Price
XSST3V	Straight Point	\$14.48
XSST3CV	Straight Point Small	14.48
XSST4V	Fine Tapered Point	14.31
XSST5V	Extra Fine Tapered Point	16.67

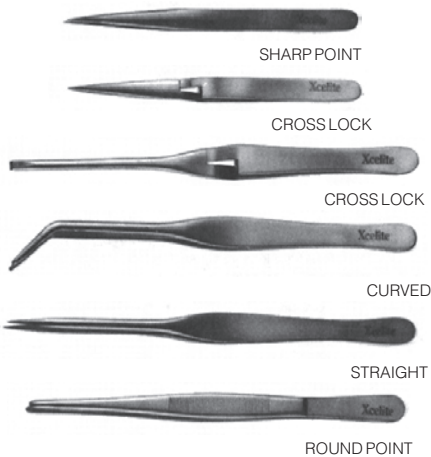

GENERAL DUTY TWEEZERS

Tweezers for most exacting work on models, small parts, soldering projects, positioning and hard to reach areas.

Cat. No.	Description	Net Price
XHT434	Sharp Point Tweezers—Smooth sharp points, for holding small parts. Size 4 $\frac{3}{4}$ "	\$6.18
XHT412	Cross Lock Tweezers—Self closing, smooth sharp points for holding small parts. Size 4 $\frac{1}{2}$ "	7.43
XHT612	Cross Lock Tweezers—Self closing, especially good for soldering and gluing. Size 6 $\frac{1}{2}$ "	7.05
XHT678	Curved Tweezers—For better view of close work, for hard to reach places. Size 6 $\frac{5}{8}$ "	7.43
XHT700	Straight Tweezers—Slender tapered points to fit in tight places. Size 7"	7.05
XHT600	Round Point Tweezers—Serrated points for sure grip, opens to $\frac{3}{4}$ " width. Size 6"	5.97



MODEL TC100ST TOOL CASE

Largest, most elaborate of the tool cases, covered with attractive durable charcoal brown leather-grain Marvelon vinyl. Removable three-panel hinged tool pallet in lid plus additional pallet in bottom. Solid brass hardware with anodized aluminum divider in bottom. Contains 53 individual tools, plus 31 Series 99 interchangeable screwdriver/nutdriver blades and handles, and two specialized screwdriver/nutdriver kits, as listed. Size: 19 $\frac{1}{2}$ " x 13 $\frac{1}{2}$ " x 6 $\frac{3}{4}$ ". Tool Case contains: **Handles:** 991 Regular, 991R Straight ratchet, 994R Tee ratchet. **Extensions:** 99X5 4", 99X10 7". **Reamer:** 9938. **Slotted screw blades:** 99125, 99250, 99312, 99811. **Phillips screw blades:** 99820, 99821, 99822. **Bristol 6-flute multiple spline blades:** (9) 9961 thru 9969. **Allen hex-socket type blades:** (7) 9920 thru 9926 and 99764, 99964. **Slotted screwdrivers:** R144, R146, R181, R184, R3164, R3166, R3323, R5325, S388, S3161, S5161, S5166. **Phillips screwdrivers:** SX101, XST100, XST101, XST102. **Hex socket screwdrivers:** P18 and P19. **Nutdrivers:** Hollow shaft HS6 thru HS18, Magnetic 8M and 10M, Midget nutdrivers P3 thru P12 and TA2 Torque Amplifier Handle. **Straight nose seizer:** 42H. **Adjustable wrench 6"**: 46CG. **Midget slip joint plier 5"**: 50CG. **Long nose plier 6"**: 51CG. **Utility nose plier 7"**: 53CG. **Diagonal plier 4"**: 54CG. **Diagonal plier 6"**: 66CG. **Needle nose plier 5 $\frac{1}{2}$ "**: 57CG. **Chain nose plier 8"**: 59CG. **Electronic snips:** 86CG. **Wire stripper/cutter:** 103S. **Electrician's knife:** K22. **Mini driver set:** M60V. **Offset ratchet screwdriver set:** XL75V. **Combination screwdriver nutdriver tool:** 600V.

Cat. No.	Description	Net Price
TC100ST	Case With Tools	\$1162.46
TC100MT	Case Only, Without Tools.	379.74
TCMB100ST	Same as TC100ST, only super tough, Black Polyethylene with rich looking Black Anodized Aluminum Hardware.	804.58
TCMB100MT	Case Only, Without Tools	367.01



MODEL TCA100ST TOOL CASE

Hi-tech aluminum tool case with smooth finish, keyless combination lock and chrome plated latches. The tongue and groove lid with rubber gasket insures a positive seal from dirt or water. The case comes complete with removable three-panel hinged tool pallet in lid plus additional panel in bottom. Contains 53 individual tools, plus 31 Series 99 interchangeable screwdriver/nutdriver blades and handles, and two specialized screwdriver/nutdriver kits. Size: 19 $\frac{1}{2}$ " x 13 $\frac{1}{2}$ " x 6 $\frac{3}{4}$ ". **NOTE:** This tool case has the same arrangement of tools as the TC100ST.

Cat. No.	Description	Net Price
TCA100ST	Tool Case With Tools	\$1340.15
TCA150ST	Same as TCA100ST in appearance, only has the same arrangement of tools as the TC150ST	1055.70



MODEL TCMG150ST TOOL CASE

Carefully selected intermediate assortment of Xcelite® hand tools. Contains 23 individual hand tools, popular WP25 Weller® 25 watt soldering iron, 24 Series 99® interchangeable screwdriver set, measuring tape, and solder (as listed). Durable, double skin blow-molded plastic case. Size: 17 3/4" x 12 5/8" x 4 3/4". Contains: **Handles:** 99 Regular 994R Tee ratchet. **Extension:** 99 x 5 4" **Allen hex socket type blades:** (9) 9920 thru 9926 and 99764, 99964. **Hex nutdriver blades:** (7) 996 thru 9912. **Hex nutdriver blades:** 99250 thru 99811. **Phillips screw blades:** 99821 thru 99822. **Reamer:** 9938. **Slotted screwdrivers:** R181, R3323, R184, R3164, S5166, S3161. **Phillips screwdriver:** SX101. **Seizer:** 42H. **Adjustable wrench:** 46CG. **Midget slip joint plier 5":** 50CG. **Utility plier 7":** 53CG. **Long nose plier 6":** 51CG. **Diagonal plier 4":** 54CG. **Diagonal plier 5":** 55CG. **Diagonal plier 5 1/2":** 57CG. **Chain nose plier 8":** 59CG. **Electronic snips:** 86CG. **Wire stripper:** 101S. **Electrician's knife:** K22. **Nutdrivers:** Hollow shaft HS14 and HS16, Magnetic 8M and 10M. **Offset ratchet screwdriver set:** XL75V. **Combination dual nutdriver handle:** 600V. **Soldering iron:** WP25. **Rosin core solder:** RC60. **10' measuring tape:** W9210ME.

Cat. No.	Description	Net Price
TCMG150ST	Tool case with tools	\$608.85
TCMG150MT	Tool case only—NO TOOLS	176.81



MODEL TCMG200ST TOOL CASE

Fine blending of quality, economy and flexibility. Contains 10 individual hand tools, 27 Series 99® interchangeable screwdriver/nutdriver blades and handles (as listed). Durable, double skin blow-molded plastic case. Size: 13 1/2" x 10 1/2" x 2 3/8". **Handles:** 991 Regular, 994 Tee. **Hex socket type blades:** (7) 9920 thru 9926 and 99764, 99964. **Reamer:** 9938. **Extension:** 99X5 4". **Phillips screw blades:** 99820, 99821, 99822. **Slotted screw blades:** 99125, 99811, 99250 and 99312. **Hex nutdriver blades:** 996, 8, 10, 11, 12, 14, and 16. **Curved nose seizer 6":** 43H. **Adjustable wrench 6":** 46CG. **Long nose plier 6 1/2":** 51CG. **Utility plier 7":** 53CG. **Diagonal pliers 4":** 64CG. **Diagonal pliers 5":** 55CG. **Needle nose pliers 5 1/2":** 57CG. **Electronic snips:** 86CG. **Wire stripper/cutter:** 101S. **Electrician's knife:** K22.

Cat. No.	Description	Net Price
TCMG200ST	Tool case with tools	\$421.28
TCMG200MT	Tool case only—NO TOOLS	153.75



MODEL TCMB100STW TOOL CASE

Contains 53 individual hand tools, 31 Series 99® interchangeable screwdriver/nutdriver blades and handles (as listed). Extra large roller bearing wheels (3 5/8") with wide base for maximum stability and easy transport over rough pavement or stairs. Extra wide, comfortable extension handle is molded into case to prevent wear. Size: 18" x 15" x 8" deep. Extension handle locks in place automatically when extended and retracted. Easy one-handed release. Two tote handles for convenience. Both are spring loaded for protection. "D" ring provided for bunji cords to carry other cases on top. Case is super tough, black polyethylene rotationally molded for maximum strength. Minimum wall thickness of 0.120". 3-panel hinged tool pallet in lid plus additional pallet in bottom. Extra large storage space for additional equipment. Extra large screen mesh literature/utility pocket. **Handles:** 991 regular, 991R regular ratchet, 994R tee. **Extension:** 99X5, 99X10. **Reamer:** 9938. **Slotted screw blade:** 99125, 99250, 99312, 99811. **Phillips screw blade:** 99820-99822. **Bristol 6-flute multi. Spline blades (9):** 9961-69. **Allen hex socket type blade:** 9920-26 (7), 99764, 99964. **Straight nose seizer:** 42H. **Adjustable wrench 6":** 46CG. **Midget slip joint pliers 5":** 50CG. **Long nose pliers 6":** 51CG. **Utility pliers 7":** 53CG. **Diagonal pliers:** 54CG 4", 66CG 6". **Needle nose pliers 5 1/2":** 57CG. **Chain nose pliers 8":** 59CG. **Electronic snips:** 86CG. **Wire stripper/cutter:** 103S. **Electrician's knife:** K22. **Mini drivers:** M60. **Offset ratchet screwdriver:** XL75. **Combination screwdriver-nutdriver tool:** 600. **Dual reversible screwdriver blade:** SB1. **Slotted screwdrivers:** R144, R146, R181, R184, R3164, R3323, R5325, S388, S3161, S5161, S5166, R3166 (insulated). **Phillips screwdrivers:** XST100-XST102. **Hex socket screwdrivers:** P18, P19. **Nutdrivers:** Hollow shaft: HS6, HS8, HS10, HS11, HS12, HS14, HS16, HS18. Magnetic: 8M, 10M. Midget: P3-12. **Torque amplifier handle:** TA2.

Cat. No.	Description	Net Price
TCMB100STW	Tool case with tools	\$1313.67
TCMB100MTW	Tool case only—NO TOOLS	541.23



MODEL TCS200ST ZIPPER TOOL CASE

Case made from rugged Cordura and features a heavy duty zipper and soft leather wrapped handles. It also has, on the outside, one large pocket on one side and two smaller pockets on the opposite side. Fine blending of quality, economy and flexibility. Contains ten individual tools and twenty-seven Series 99 interchangeable screwdriver/nutdriver blades and handles, as listed. Size: 18 1/2" x 13 1/2" x 4 3/4". Tool case contains: **Handles:** 991 Regular, 994 Tee. **Hex socket screw blades:** (7) 9920 thru 9926 and 99764, 99964. **Reamer:** 9938. **Extension:** 99X5 4". **Phillips screw blades:** 99820, 99821, 99822. **Slotted screw blades:** 99125, 99811, 99250 and 99312. **Hex nutdriver blades:** 996, 8, 10, 11, 12, 14, and 16. **Curved nose seizer 6":** 43H. **Adjustable wrench 6":** 46CG. **Long nose plier 6 1/2":** 51CG. **Utility plier 7":** 53CG. **Diagonal pliers 4":** 64CG. **Diagonal pliers 5":** 55CG. **Needle nose plier 5 1/2":** 57CG. **Electronic snips:** 86CG. **Wire stripper/cutter:** 101S. **Electrician's knife:** K22.

Cat. No.	Description	Net Price
TCS200ST	Case With Tools	\$531.45
TCS200MT	Case Only, Without Tools	142.17

platt
Cases for business
and industry



600T



800T



610T



946T



928TG/928TY



928T
TOOLS NOT INCLUDED

STANDARD SIZE TOOL CASES

Platt molded tool cases are manufactured from the highest quality materials and hardware, they are made to be durable and stand up to the rigors of technician use. The 610T case has a leather-like vinyl exterior over a molded ABS shell. This professional looking case with the appearance of an attache gets you in the front door. Cases come standard with C and B Molded Pallets. Other pallets are available (see list of pallets). All of the cases accept Platt's standard molded and sewn pallets. The 928T and 946T are available in yellow and grey in addition to standard black and include a molded tray with adjustable divider system.

Cat. No.	Inside Dimensions			Colour	Net Price
	L	W	D		
600T-CB	18"	13"	6"	Black	\$183.30
605T-C*	18"	13"	6"	Black	165.85
610T-C*	18"	13"	5"	Oxford	275.58
800T-CB	18"	13"	6"	Black	197.02
805T-C*	18"	13"	6"	Black	180.81
836T-CB	18"	13"	6"	Black	169.59
928T-CB	18"	13"	8"	Black	214.48
928TY-CB	18"	13"	8"	Yellow	225.70
928TG-CB	18"	13"	8"	Grey	225.70
946T-CB	18"	13"	6"	Black	225.70
946TY-CB	18"	13"	6"	Yellow	225.70
946TG-CB	18"	13"	6"	Grey	225.70

*Comes with one pallet.



349T
MILITARY TYPE



359T
MOLDED



369TH
WHEEL & HANDLE



410TH
ROTATIONAL MOLDED

SUPER-SIZE CASES

High-tech rugged HMW Polyethylene ribbed case in a large size, black valance with all black hardware, combination lock, and full length piano hinge. Cases come standard with Platt's SG and SH super-sized pallets. Other pallets are available (see list of pallets). Accepts only super-size pallets. 349T series come with military-type spring-loaded handle and twist draw latches. 369TH and 410TH series come with telescoping handle and ball-bearing wheels. 410TH is rotational molded.

Cat. No.	Inside Dimensions			Colour	Net Price
	L	W	D		
349T-SGSH	17½"	14½"	9"	Black	\$289.30
349TG-SGSH	17½"	14½"	9"	Grey	289.30
349TY-SGSH	17½"	14½"	9"	Yellow	289.30
357T-SGSH	17½"	14½"	7"	Black	289.30
359T-SGSH	17½"	14½"	9"	Black	289.30
359TG-SGSH	17½"	14½"	9"	Grey	274.84
359TY-SGSH	17½"	14½"	9"	Yellow	274.84
369TH-SGSH	17½"	14½"	9"	Black	416.49
369THG-SGSH	17½"	14½"	9"	Grey	416.49
369THY-SGSH	17½"	14½"	9"	Yellow	416.49
410TH-SGSH	18"	15"	10½"	Black	516.24

PLATT SEWN TOOL CASES



660ZT



665ZT
TOOLS NOT INCLUDED

TROUBLE SHOOTER

Consistently a best seller, the 660ZT series "Trouble Shooter" carrying case is designed for versatility. With 29 sewn tool pockets and a meter pouch on the inside, 2 additional meter pouches and a document pocket on the outside, this case will carry a wide variety of tools. Constructed of heavy-duty nylon with industrial strength zipper for durability this attractive soft-sided case is available in the following selection of colours. 665ZT is the same as 660ZT above, but with 27 molded tool pockets and 2 vinyl pouches. Size 13¼ x 13 x 2.

Cat. No.	Outside Dimensions			Colour	Net Price
	L	W	D		
660ZT	13"	10"	2"	Black	\$105.99
660ZTBLU	13"	10"	2"	Blue	105.99
660ZTBURG	13"	10"	2"	Burgundy	105.99
660ZTGREEN	13"	10"	2"	Green	105.99
665ZT	13½"	13"	2"	Black	130.93



669ZT



689ZT
TOOLS NOT INCLUDED


MASTER TECHNICIAN

For additional capacity, the larger 669ZT series "Master Technician" carrying case contains 47 sewn tool pockets and a meter pouch inside, as well as 2 meter pouches and document pocket on the outside. Constructed of heavy duty-nylon with industrial strength zipper for durability. This carrying case comes complete with adjustable and removable shoulder strap. Also available in the following selection of colours. Shoulder strap included. 689ZT has same pocket configuration as 669ZT with addition of a separate compartment with a padded pocket to hold your notebook computer.

Cat. No.	Outside Dimensions			Colour	Net Price
	L	W	D		
669ZT	15½"	11"	2"	Black	\$141.79
669ZTBLU	15½"	11"	2"	Blue	152.13
669ZTBURG	15½"	11"	2"	Burgundy	152.13
669ZTGREEN	15½"	11"	2"	Green	152.13
689ZT	18"	13"	6"	Black	235.68



MTB

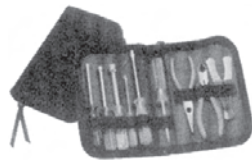

PL-ST
TOOLS NOT INCLUDED

ECONOMICAL CASES

This handy "Mechanic's Tool Bag" is similar to the G1 tool bag used for decades by the U.S. Military. Our water-repellent nylon fabric makes it much more durable and with 8 sewn-in pockets on the inside and 2 divided snap pouches on the outside, this compact utility bag will keep your smaller tools and parts organized. The PL-ST is an economy nylon tool case with heavy-duty zipper and an industrial type elastic snap to hold tools.

Cat. No.	Outside Dimensions			Colour	Net Price
	L	W	D		
MTB	12"	6"	6½"	Black	\$29.93
MTB-BLU	12"	6"	6½"	Blue	29.93
MTB-BURG	12"	6"	6½"	Burgundy	29.93
MTB-GREEN	12"	6"	6½"	Green	29.93
PL-ST	9"	6"	1½"	Black	24.51



601ZT



602ZT



602ZT
TOOLS NOT INCLUDED

MINI CASES

The compact "Mini-Tech" may be used alone or stowed inside one of our larger cases. With 14 interior sewn tool pockets and one inside pouch, it is ideal when only a limited number of tools are needed. The 602ZT contains an additional 3 exterior pockets and wrapped handles. Available in black.

Cat. No.	Outside Dimensions			Colour	Net Price
	L	W	D		
601ZT	10½"	7¾"	2"	Black	\$63.59
602ZT	10½"	7¾"	2"	Black	91.03



685ZT



675ZT
TOOLS NOT INCLUDED



630ZT

TELECOM CASES

Custom designed for Platt by professional telecom installers, the deluxe 685ZT "Master Telecom" carrying case efficiently and securely stores the specialized tools used by telecom installers. Stay organized with 24 sewn interior pockets, 5 small parts pouches, special pockets for tone generator and probe set, and hook and loop strap "buttset" holder. Unique clip-on "stay straps" allow case to function as a handy shelf when hung by the carrying handle on a ladder or wall hook. Shoulder strap included. The 675ZT Basic Telecom carrying case is slightly smaller than the Master Telecom case and features 14 sewn tool pockets and 6 small parts pouches. Includes the same unique clip-on "stay straps" to allow the case to function as a handy shelf. Shoulder strap included. The 630ZT telecom case is compact and economical yet still includes the hook and loop "butt set" holder along with 20 sewn tool pockets and 1 parts pouch.

Cat. No.	Outside Dimensions			Colour	Net Price
	L	W	D		
685ZT	15½"	13"	3"	Black	\$198.27
675ZT	13¾"	12¾"	3"	Black	154.62
630ZT	14"	10"	3"	Black	127.19



1161



1168

TOOL BAGS

The 1161 has 17 multi-use pockets inside and 6 outside to organize tools and accessories. Opens wide for easy access to bag's contents and has padded reinforced web carrying handles. The 1168 has 32 Pockets inside and 10 outside to organize tools and accessories and also contains a 13½" x 9" multi-compartment plastic tray to organize small parts and a telescoping handle extends for fast transport on large, easy-roll wheels.

Cat. No.	Outside Dimensions			Net Price
	L	W	D	
1161	12"	8½"	8"	\$38.58
1168	18"	10"	14"	137.67



747T



777TH



PLATT GUARDSMAN TOOL CASES

Heavy-duty HMW polyethylene material with unique continuous industrial frame both on the exterior and interior case for maximum strength (ATA 300). Recessed hardware, combination lock, full-length piano hinge, spring loaded handle and security type bolts. Deluxe literature pocket in lid and two molded pallets. Foam in bottom of case for miscellaneous items. Platt's rugged Guardsman ATA case is available with a telescoping handle and built-in wheels. 777TH comes with

Cat. No.	Inside Dimensions			Colour	Net Price
	L	W	D		
747T-CB	17½"	11"	9"	Black	\$497.54
777TH-SGSH	18½"	14½"	9¾"	Black	723.24

NOTE: The Guardsman ATA Tool cases are available in a variety of colours. Please contact your Electro Sonic sales representative for more information.

Platt Tool Cases

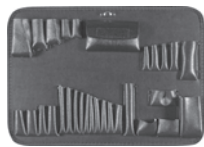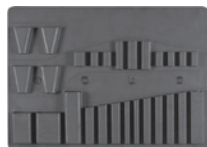

PLATT TOOL PALLETS

The Platt pallets are designed to accommodate the tools for servicing, installation and maintenance of electronic and electrical equipment. The pallets are available in either Urethane molded or sewn and riveted Neoluxe.

STANDARD SIZE PALLETS

Cat. No.	Description	Net Price
----------	-------------	-----------

INJECTION MOLDED PALLETS

A	Top, all purpose, pallet 27 pockets	\$29.93
B	Bottom, all purpose, 27 pockets	29.93
C	Top pallet, all purpose, 22 pockets	29.93
D	Bottom, all purpose, 22 pockets	29.93

SEWN & RIVETED PALLETS

E	Appliance & material handling pallet	34.92
F	Appliance & material handling pallet	37.41
G	Copier & office machine pallet	39.90
H	Copier & office machine pallet	42.40
I	High technology pallet	42.40
J	High technology pallet	42.40
K	HVAC pallet	42.40
L	HVAC pallet	42.40
M	HVAC pallet	42.40
N	HVAC pallet	42.40
O	Telecom pallet	42.40
P	Attaché pallet	32.42
Q	Padded notebook computer pocket	32.42
R	Clipboard pallet	18.71

NOTE: For super-sized pallets add prefix "S" to Cat. No. ex: SA.



CART14-B



CART15

PLATT TOOL CASE CARTS

CART01-B: Constructed of 16 gauge steel tubing .625 dia. and 3/8" dia. solid steel rod. Patented safety hook.

CART07: Glides up and down steps and curbs, yet telescopes closed in a single motion to fit in airline overheads. When open: 52" x 16 1/2" x 19".

CART08: Glides up and down steps and curbs, yet telescopes closed in a single motion to fit in airline overheads. When open: 52" x 16 1/2" x 19". Cart has a unique rear wheel assembly that supports larger loads.

CART13: For business, home, recreation or travel. Folds to 2 1/2" flat. Large 7 1/4" shock absorbent tires.

CART14: For business, home, recreation or travel. Folds to 2 1/2" flat. Large 7 1/4" shock absorbent tires.

CART15: This durable and lightweight cart fits in the airline overhead compartment and easily stores in a closet or car trunk. Folds to 2" flat.



CART01-B



CART07



CART08



CART13

Cat. No.	Load Cap.	Load Tray		Height	Colour	Net Price
		L	W			
CART01-B	275 lbs.	14"	13"	46"	Black	\$142.15
CART07	400 lbs.	16"	12 3/4"	52"	Chrome	256.88
CART08	400 lbs.	16"	12 3/4"	52"	Chrome	327.95
CART13	275 lbs.	9 1/2"	19"	40"	Aluminum	243.16
CART14	275 lbs.	16"	15 1/2"	44"	Aluminum	269.35
CART15	115 lbs.	15"	10 1/4"	40 1/2"	Aluminum	128.44



PLATT CATALOGUE CASES

Cat. No.	Inside Dimensions			Colour	Net Price
	L	W	D		
HT2191	17"	12"	8"	Oxford	\$157.12

IF YOU CAN'T FIND WHAT YOU NEED, CALL US
1-800-56-SONIC
OR EMAIL US: info@e-sonic.com
WE ARE EAGER TO HELP.