

Micro-Change® (M12) Jumper Cables




Female Connector

Cable


Length (m)

M12 Single I/O Multi-Port Jumpers

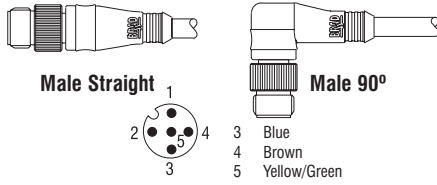



WIRING CONFIGURATION

M12 Twin I/O Multi-Port Jumpers

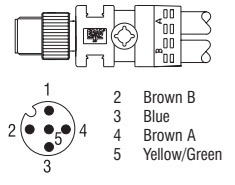

WIRING CONFIGURATION

 
 
Form C Ind (9.4mm) 2 pole + earth



- 1 Brown
- 3 Blue
- 4 Black

Cable	Length (m)	Part No.	Part No.
PVC	0.6	G85000E12M006	G85002E12M006
	1.0	G85000E12M010	G85002E12M010
	2.0	G85000E12M020	G85002E12M020
	3.0	G85000E12M030	G85002E12M030
PUR	0.6	G85000P12M006	G85002P12M006
	1.0	G85000P12M010	G85002P12M010
	2.0	G85000P12M020	G85002P12M020
	3.0	G85000P12M030	G85002P12M030

  Form C Ind (9.4mm) 2 pole + earth – 24 V LED & VDR



- 1 Brown
- 3 Blue
- 4 Black


Cable	Length (m)	Part No.	Part No.
PVC	0.6	G850B0E12M006	G850B2E12M006
	1.0	G850B0E12M010	G850B2E12M010
	2.0	G850B0E12M020	G850B2E12M020
	3.0	G850B0E12M030	G850B2E12M030
PUR	0.6	G850B0P12M006	G850B2P12M006
	1.0	G850B0P12M010	G850B2P12M010
	2.0	G850B0P12M020	G850B2P12M020
	3.0	G850B0P12M030	G850B2P12M030

Also compatible with Twin I/O Multi-Ports

Part No.
G85A00E12M006
G85A00E12M010
G85A00E12M020
G85A00E12M030
G85A00P12M006
G85A00P12M010
G85A00P12M020
G85A00P12M030



Micro-Change® (M12) Adapters and In-Line Splitters

 M12 Single I/O Multi-Port



Female Connector

  
M12 Twin I/O Multi-Port



Adapter & In-line Splitter M8 to M12



 - 1 Brown 4 Black
- 3 Blue




483030

Adapter M8 to M12




 - 1 Brown 3 Blue
- 2 White 4 Black




484030

 
In-line Splitter M12 to M12



 - 1 Brown 4 Black
- 2 White 5 Yellow/Green
- 3 Blue



484A30

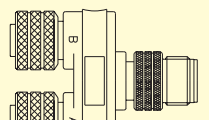

885A30