


531-285.

Type	Side Walls	Pg Knockouts	Inside Height	Ref. No.	Unit
POLYSTYRENE - COVER GREY RAL 7035					
PS 1313- 7	with Pg		63 mm	115-405	14/2
PS 1313-10	with Pg		87 mm	115-905	8/2
PS 1313- 7-o	smooth		63 mm	110-405	14/2
PS 1313-10-o	smooth		87 mm	110-905	8/2
POLYSTYRENE - COVER TRANSPARENT					
PS 1313- 7-t	withPg		63 mm	116-005	14/2
PS 1313-10-t	with Pg		87 mm	116-505	8/2
PS 1313- 7-to	smooth		63 mm	111-005	14/2
PS 1313-10-to	smooth		87 mm	111-505	8/2
POLYCARBONATE - COVER GREY RAL 7035					
PC 1313- 7	with Pg		63 mm	125-405	14/2
PC 1313-10	with Pg		87 mm	125-905	8/2
POLYCARBONATE - COVER TRANSPARENT					
PC 1313- 7-t	with Pg		63 mm	135-005	14/2
PC 1313-10-t	with Pg		87 mm	135-505	8/2

TK 1313
Empty
Enclosure
130 x 130^{mm}
Type of
Protection
IP 66

Knockouts: = Pg 16/11 = Pg 16 = Pg 21/16 = Pg 29/21

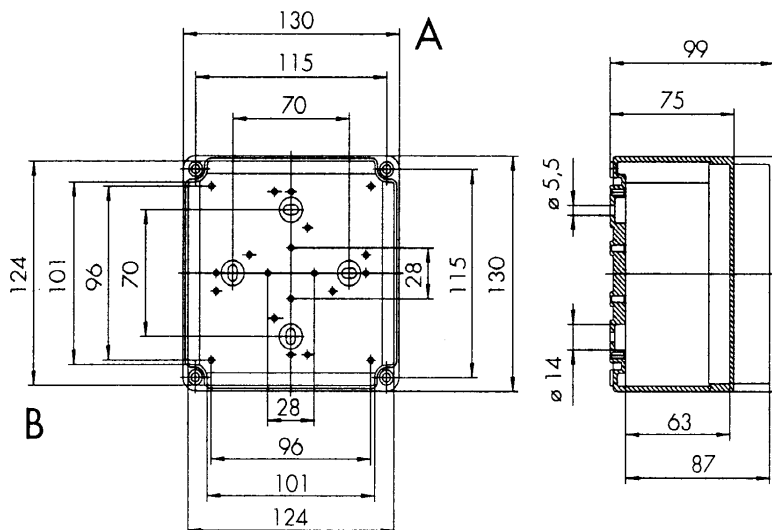

Max. number of Pg drill holes per box side

Pg	A	B
7	10	10
9	8	8
11	8	8
13.5	3	3
16	3	3
21	2	2
29	2	2
36	-	-

All dimensions in millimeters