



New, technologically advanced, injection moulded, high thickness Polypropylene tool case. This type of material makes the case extremely resistant against chemical corrosion, shock, high and low temperature. The injection technique ensures constant material thickness, even in the corners.

Large and thick aluminium trim, makes the case ideal for daily, heavy duty use. The case can accommodate up to 3 tool pallets.

General features:

- 2 metal lid safety support stays
- 2 metal locks with keys
- 3 metal hinges for maximum strength
- ergonomic handle, rubber coated grip
- address label



- Bottom area has removable dividers fixed directly on the shell body with no need of additional tray. Lightweight and higher load capacity are ensured.

- Address label



ATOMIK215 PEL-ATOMIK/R PEL

- 1 lid tool pallet with elastics on one side
- 1 bottom tool pallet with elastics on one side
- document area
- bottom area with removable dividers

FRONT



BACK



Additional tool pallet (art. PAN ATOMIK) available as accessory upon request. Front with PSS system, back with elastics.



*** All models are also available in red color**



- FLEXI POUCHES PLUS™ - Patented Tool Fixing System (for more details see page 44)

ATOMIK215 PTS-ATOMIK/R PTS

- 1 lid tool pallet with FLEXI POUCHES PLUS™ on two sides
- 1 bottom tool pallet with FLEXI POUCHES PLUS™ on one side
- document area
- bottom area with removable dividers



- PSS™ - Patented Professional Storage System (for more details see page 44)

ATOMIK215 PSS-ATOMIK/R PSS

- 1 lid tool pallet with PSS™ system on two sides
- 1 bottom tool pallet with PSS™ system on one side
- document area
- bottom area with removable dividers

INTERNAL DIMENSIONS (mm)

Model	A	B	C	D	E	
ATOMIK215 PEL (black color)	465	352	215	95	120	4,5
ATOMIK215 PTS (black color)	465	352	215	95	120	5,0
ATOMIK215 PSS (black color)	465	352	215	95	120	5,5
ATOMIK/R PEL (red color)	465	352	215	95	120	5,0
ATOMIK/R PTS (red color)	465	352	215	95	120	5,5
ATOMIK/R PSS (red color)	465	352	215	95	120	5,5






New, technologically advanced, injection moulded, high thickness Polypropylene tool case on wheels, fitted so that the travelling position is with horizontal case. This type of material, makes the case extremely resistant against chemical corrosion, shock, high and low temperature. The injection technique, ensures constant material thickness, even in the corners. Large and thick aluminium trim, makes the case ideal for daily, heavy duty use. The case can accommodate up to 3 tool pallets.

General features:

- 2 metal lid safety support stays
- 2 metal locks with keys
- 3 metal hinges for maximum strength
- ergonomic handle, rubber coated grip
- address label
- telescopic handle

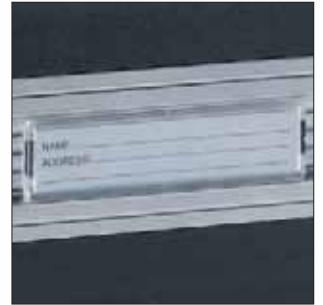

• Address label



• Bottom area has removable dividers fixed directly on the shell body with no need of additional tray. Lightweight and higher load capacity are ensured.



• Wheels on ball bearing

ATOMIK WH PEL-ATOMIK/R WH PEL

- 1 lid tool pallet with elastics on one side
- 1 bottom tool pallet with elastics on one side
- document area
- bottom area with removable dividers



FRONT



BACK



Additional tool pallet (art. PAN ATOMIK) available as accessory upon request. Front with PSS system, back with elastics.



- FLEXI POUCHES PLUS™ - Patented Tool Fixing System (for more details see page 44)

ATOMIK WH PTS-ATOMIK/R WH PTS

- 1 lid tool pallet with FLEXI POUCHES PLUS™ on two sides
- 1 bottom tool pallet with FLEXI POUCHES PLUS™ on one side
- document area
- bottom area with removable dividers




- PSS™ - Patented Professional Storage System (for more details see page 44)

ATOMIK WH PSS-ATOMIK/R WH PSS

- 1 lid tool pallet with PSS™ system on two sides
- 1 bottom tool pallet with PSS™ system on one side
- document area
- bottom area with removable dividers



*** All models are also available in red color**

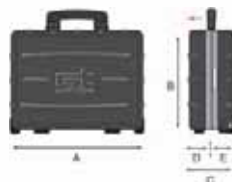

INTERNAL DIMENSIONS (mm)

Model	A	B	C	D	E	
ATOMIK WH PEL (black color)	465	352	215/255	95	120/160	5,5
ATOMIK WH PTS (black color)	465	352	215/255	95	120/160	6,0
ATOMIK WH PSS (black color)	465	352	215/255	95	120/160	6,6
ATOMIK/R WH PEL (red color)	465	352	215/255	95	120/160	5,5
ATOMIK/R WH PTS (red color)	465	352	215/255	95	120/160	6,0
ATOMIK/R WH PSS (red color)	465	352	215/255	95	120/160	6,6