


LEAF THERMOCOUPLE

A type K & J sensor mounted on a stainless steel shim

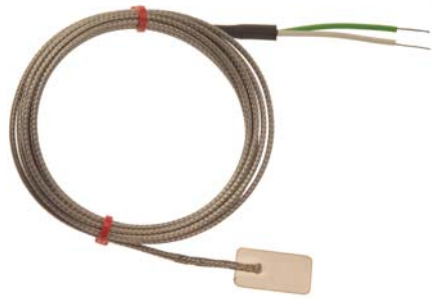

- Grounded tip for fast response
- Thermocouple types K & J to IEC584
- Rated 350°C
- 2 and 3 meter lengths
- Glass fiber stainless steel braided extension cable, 7/0.2mm
- Stainless steel shim 25mm long x 13mm wide

Type/lead length	Farnell code	Labfacility stock code	Manufacturing Code
J, 2m	8597928	XF-357-FAR	FL-J-2M
K, 2m	8597936	XF-358-FAR	FL-K-2M
K, 3m	1633486	XF-528-FAR	FL-K-3M

Data Ref: FAR 87