


SPECIFICATION

- 1. Rated Voltage12V
- 2. Operating Voltage6~18V
- 3. Max. Rated Current40mA
- 4. Coil Resistance115±12 Ω
- 5. Coil Impedance.....200 Ω
- 6. Min. Sound Pressure Level85dB/10cm
- 7. Resonant Frequency.....2048Hz
- 8. Case MaterialMPPO
- 9. Operating Temperature-30~+80°C
- 10. Store Temperature-40~+85°C
- 11. Weight7g

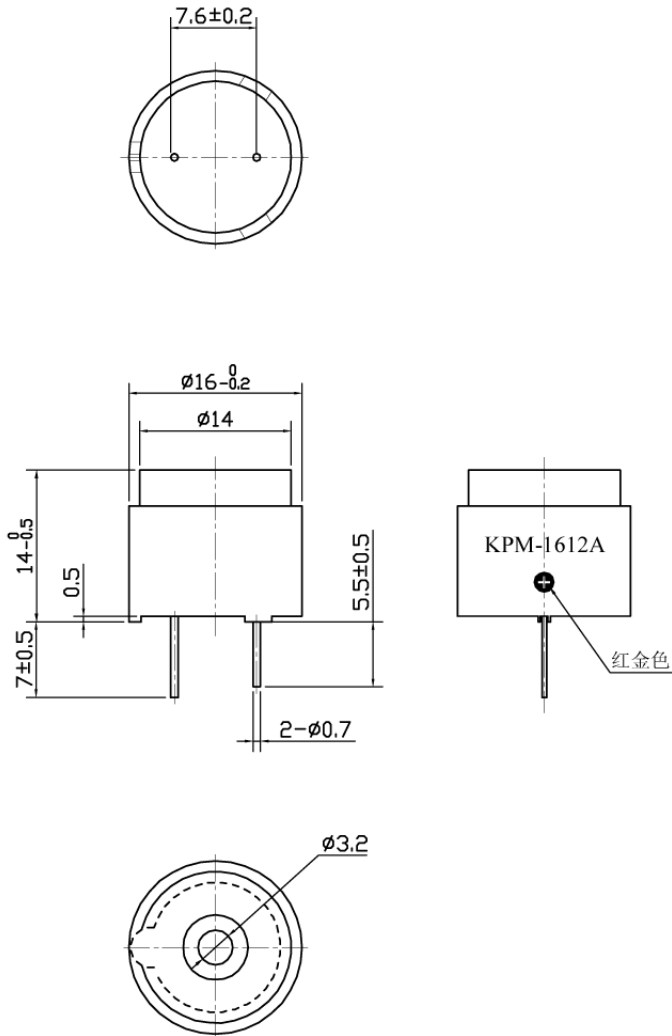

			KEPO KEPO ELECTRONIC CO., LTD. http://www.kepo.com.tw	
			Magnetic Buzzer	
			KPM-1612A	
No.	DESCRIPTION	APPROVED	DATE	
TOLERANCES UNLESS NOTED OTHERWISE: .X ± .XX ± .XXX ± 90° FORMED ±2° ANGLES ±1°		APPROVALS	DATE	
		DRAWN		
		CHECKED		
FIRST ANGLE PROJECTION		APPROVED	05.05.11	UNIT: mm DWG NO: KP3.840.685
				SCALE: NOT TO SCALE SHEET: VER: 1.2