


## Toolposts, Sets

All sets apart from T00M are supplied with flange washer and location pin

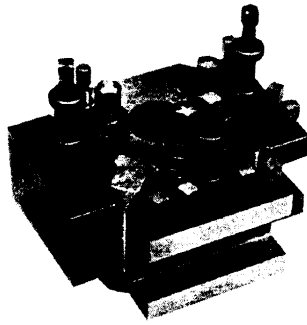

CODE NO.	TYPE	COMPOSITION	LATHE CAPACITY	PRICE £
7-275-000M	T00M MYFORD	Body only*	UP TO 89mm	82.30
7-275-002M		with 2std holders		117.31
7-275-004S		with 4std holders		146.28
7-275-004M		with 2std, 1"V", 1 P/O holders		149.61
7-275-000B	T00B BOXFORD	Body only*	UP TO 89mm	90.32
7-275-002B		with 2std holders		125.40
7-275-004B		with 2std, 1"V", 1 P/O holders		153.26
7-279-000	T0	Body only*	UP TO 114mm	117.01
7-279-002		with 2std holders		175.32
7-279-005		with 2std, 1"V", 1 P/O holders		230.00
7-279-006		with 4std, 1"V", 1Morse holder		310.65
7-279-010	T1	Body only*	114 - 127mm	129.00
7-279-012		with 2std holders		210.71
7-279-014		with 4std holders		265.80
7-279-015		with 2std, 1"V", 1 P/O holders		286.63
7-279-016		with 4std, 1"V", 1Morse holder		352.10
7-279-010X	T1X	Body only*	114 - 127mm	146.00
7-279-012X		with 2std holders		225.00
7-279-014X		with 4std holders		285.50
7-279-016X		with 4std, 1"V", 1Morse holder		398.00
7-279-020	T2	Body only*	127 - 203mm	178.26
7-279-022		with 2std holders		266.83
7-279-024		with 4std holders		363.36
7-279-026		with 4std, 1"V", 1Morse holder		408.22
7-279-020T	T2T	Body only*	127 - 203mm	193.25
7-279-022T		with 2std holders		289.55
7-279-024T		with 4std holders		391.74
7-279-026T		with 4std, 1"V", 1Morse holder		471.23
7-279-030	T3	Body only*	203 - 292mm	250.96
7-279-032		with 2std holders		375.87
7-279-034		with 4std holders		474.64
7-279-035		with 2std, 1"V", 1 P/O holder		485.99
7-279-036		with 4std, 1"V", 1Morse holder		617.68
7-279-030X	T3HX	Body only*	203 - 292mm	261.15
7-279-032X		with 2std holders		374.70
7-279-034X		with 4std holders		465.54
7-279-036X		with 4std, 1"V", 1Morse holder		635.87

\*Toolpost bodies are supplied complete with all clamp bolts, clamp pads and flange washer and location pin (except T00M and T00B).

## Toolholders

### Standard Toolholders

CODE NO.	FOR TOOLPOSTS	LENGTH x HEIGHT mm	PRICE £
7-277-001M	T00M, T00B	58 x 27	19.50
7-278-006	T0	73 x 35	36.20
7-278-011	T1, T1X	73 x 44.5	49.91
7-278-021	T2	98.5 x 50	54.45
7-278-021T	T2T	98.5 x 57	57.21
7-278-031	T3, T3HX	124 x 70	61.93

### Vee Toolholders

CODE NO.	FOR TOOLPOSTS	LENGTH mm	MAX BORE DIA mm	PRICE £
7-277-002M	T00M, T00B	58	8	20.75
7-278-007	T0	73	8	38.20
7-278-012	T1, T1X	73	11	52.35
7-278-022	T2	98.5	14	59.14
7-278-022T	T2T	98.5	14	60.80

## Parting off Toolholders

CODE NO.	FOR TOOLPOSTS	LENGTH x HEIGHT mm	PRICE £
7-277-003M	T00M, T00B	58 x 30	26.88
7-278-013	T0, T1, T1X	73 x 47.5	54.40
7-278-023	T2, T2T	98.5 x 57	77.17
7-278-033	T3, T3HX	124 x 70	88.76

## Morse Taper Toolholders

CODE NO.	FOR TOOLPOSTS	MORSE TAPER	PRICE £
7-278-008	T0	MT1	50.91
7-278-014	T1, T1X	MT1	59.55
7-278-024	T2, T2T	MT2	89.76
7-278-034	T3, T3HX	MT3	104.55

## Plain Bore Toolholders

CODE NO.	FOR TOOLPOSTS	BORE DIA	PRICE £
7-278-027	T2, T2T	25.5	89.76
7-278-037	T3, T3HX	38	104.55

## Spare Parts

For Toolposts

CODE NO.	NAME OF PART	FOR TOOLPOST	PRICE £
7-278-001	HEX WRENCH	T00M, T00B	4.54
7-280-000		T0	9.88
7-280-001		T1, T1X	13.09
7-280-002		T2, T2T	15.26
7-280-003	T3, T3X	18.55	
7-278-002	T WRENCH	T00M, T00B	2.18
7-280-005		T0	3.07
7-280-006		T1, T1X	7.90
7-280-007		T2, T2T	8.64
7-280-008	T3, T3X	9.28	
7-280-020	CLAMP BOLT	T00M, T00B	14.20
7-280-021		T0, T1, T1X	22.71
7-280-022		T2	23.18
7-280-022T		T2T	27.05
7-280-023		T3, T3HX	29.48
7-280-030	CLAMP PAD	T00M, T00B	10.30
7-280-031		T0, T1, T1X	18.56
7-280-032		T2	19.18
7-280-032T		T2T	19.18
7-280-033		T3, T3HX	24.57
7-280-040	LOCATION PIN	T0	5.17
7-280-041		T1, T1X,	6.17
7-280-042		T2, T2T	7.01
7-280-043		T3	9.41
7-280-043X		T3HX	10.30
7-280-050	SPRING	T00M, T00B	0.40
7-280-051		T0, T1, T1X	0.70
7-280-052		T2, T2T	0.70
7-280-053		T3, T3HX	0.70
7-280-071	STOP	T0, T1, T1X	8.63
7-280-072		T2, T2T	8.63
7-280-073		T3, T3HX	10.91
7-280-080	STUD	T00M, T00B	1.10
7-280-081		T0, T1, T1X	1.40
7-280-082		T2, T2T	1.40
7-280-083		T3, T3HX	1.80
7-280-091	SQUARE HEAD SCREW	T0, T1, T1X	2.86
7-280-092		T2, T2T	3.73
7-280-093		T3, T3HX	3.85
7-280-121	STOP SCREW	T0, T1, T1X	2.11
7-280-122		T2, T2T	2.39
7-280-123		T3, T3HX	3.12