


927 156


KINGSTATE **PIEZO AUDIO INDICATOR** **PC BOAD TYPE**

Shape

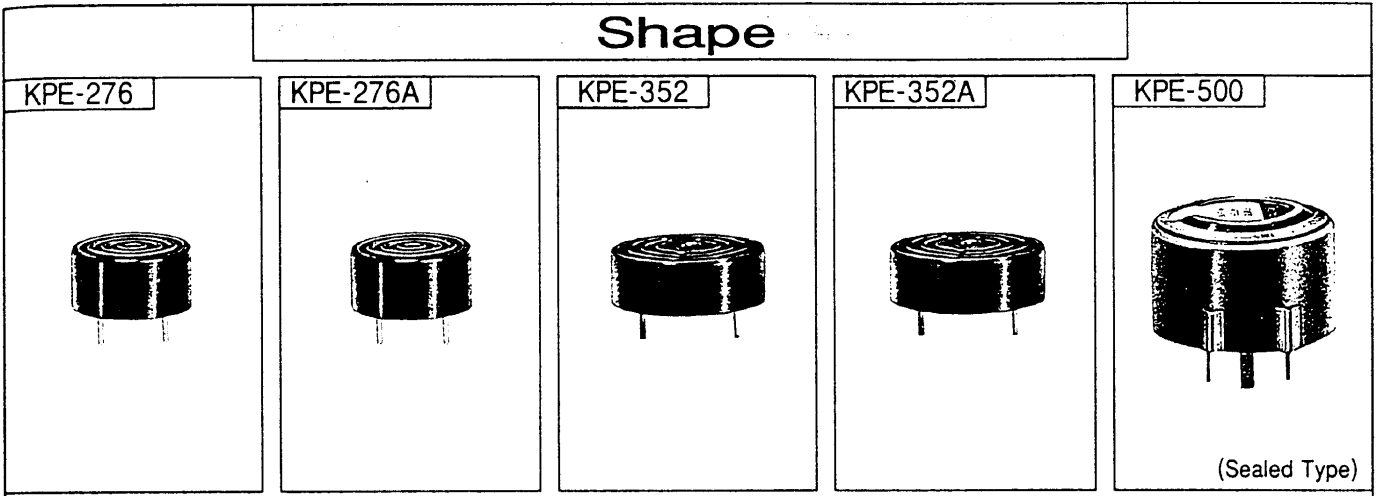

Model Number	KPE-276	KPE-276A	KPE-352	KPE-352A	KPE-500
Oscillating Frequency (KHz)	2.7 ± 0.5	2.8 ± 0.5	2.8 ± 0.5	2.8 ± 0.5	2.5 ± 0.5
Operating Voltage (VDC)	3~28	3~20	3~28	3~20	5~13
Current Consumption at 12VDC (mA, maximum)	4	8	7	10	50
Sound Pressure Level at 30cm/12VDC (dB, minimum)	79	93	89	94	104 (85 dB at 3 meters)
Tone	Continuous	Continuous	Continuous	Continuous	Continuous
Operating Temperature (°C)	-20~+60	-20~+60	-20~+60	-20~+60	-20~+60
Storage Temperature (°C)	-30~+70	-30~+70	-30~+70	-30~+70	-30~+70
Weight (Gram)	7	7.2	12	25	27.5
Packing Quantity (PCS/BOX)	140	140	80	80	28

Dimension

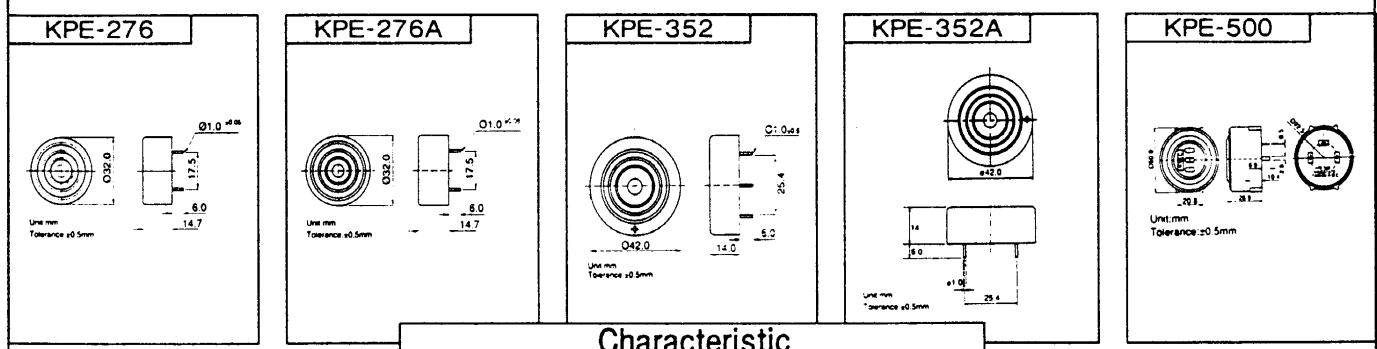

Characteristic

