


Terminals and installation accessories

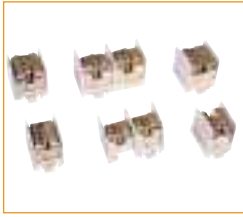

Terminal blocks

Terminal blocks

For fixing to symmetrical DIN rails. 1P and 2P blocks can be fitted together to form 3P and 4P blocks.

Technical data

- Current rating: 80A

Type	Part N°.
1P (2 x 25mm ² + 4 x 16mm ²)	14936
1P (2 x 35mm ² + 4 x 25mm ²)	14938
2P (2 x 25mm ² + 4 x 16mm ²)	14937
2P (2 x 35mm ² + 4 x 25mm ²)	14939



Connection strips

Connection strips 80 - 125A (40°C)

Cross section for stranded cables. Each strip has one M4 threaded hole for screw attachment to any support.

80A connection strip	Part N°.
4 holes (2 x 10mm ² + 2 x 16mm ²) length 32mm	14962
6 holes (3 x 10mm ² + 2 x 16mm ² + 1 x 35mm ²) length 50mm	14963
10 holes (5 x 10mm ² + 4 x 16mm ² + 1 x 35mm ²) length 74mm	14964

125A connection strip	Part N°.
14 holes (7 x 10mm ² + 6 x 16 mm ² + 1 x 35mm ²) length 98mm	14965



Terminal block supports

Terminal block supports

Terminal block support made of self extinguishing insulating material: 960°C/5s. Beige in colour.

Each support can be individually identified using clip-on markers (optional):

- Blue for neutral
- Yellow/green for earth

Fixing:

- **Clipped on to:**
 - 12 x 2 flat bar
 - Multifix or symmetrical rail
- Screwed on to any support (plain or slotted plate) using 2 ears

Cross section for stranded cables	Part N°.
80A terminal block	
4 holes (2 x 10mm ² + 2 x 16mm ²) length 68mm	14975
6 holes (3 x 10mm ² + 2 x 16mm ² + 1 x 35mm ²) length 68mm	14976
10 holes (5 x 10mm ² + 4 x 16mm ² + 1 x 35mm ²) length 115mm	14977

125A terminal block	Part N°.
14 holes (7 x 10mm ² + 6 x 16mm ² + 1 x 35 mm ²) length 115mm	14979



14989

Identification card

The markers can be used to identify terminal blocks: neutral or earth.

Type	Part N°.
2 x 50 identification card (50 blue mark, 50 yellow/green mark)	14989
Flat bar 12 x 2	07046



Terminal bars

Terminal bar for earth/neutral connections

- For panel mounting
- Including support
- Current rating 200A

Type	Part N°.
For panel mounting	
1 x 20 holes, length 183mm (19 x 16 ² + 1 x 120 ²)	99217
1 x 25 holes, length 222mm (24 x 16 ² + 1 x 120 ²)	99219
1 x 38 holes, length 332mm (37 x 16 ² + 1 x 120 ²)	99221
1 x 49 holes, length 419mm (48 x 16 ² + 1 x 120 ²)	99223
1 x 73 holes, length 624mm (72 x 16+1 x 120 ²)	99225