

**NEW** / Industry  
[Homepage](#)

[All tools](#) [All cordless tools](#)  
[All cordless drill/drivers](#)  
[\(Standard-Duty\)](#)

# GSR 14.4 V Professional

## Products

- [Tools](#)
- [Accessories](#)
- [New Deals](#)

## Service

- [3-year Warranty](#)
- [After Sales Service & Retailers](#)
- [Bosch System Specialist](#)
- [Spare Parts Service](#)
- [User Manuals](#)
- [Environmental Protection](#)
- [Blue Print Catalogue](#)

## News & Extras

- [Current News](#)
- [Downloads](#)
- [Film - For professionals from professionals](#)
- [Vibration Control](#)

## Search

[Go!](#)

**Hotline** (Local call rate)

**0844 7360107**

Mon-Fri 8.00 – 17.00

[e-mail contact](#)



## Cordless Drill/Driver GSR 14.4 V

**Compact and durable. For small to medium screw and drilling diameters**

- Compact design offers perfect handling for working overhead and in tight spaces
- Long running performance: up to 150 screws (6x60 mm) in softwood with one battery charge
- Extremely robust: fully functional, even after falling from a height of 2m onto concrete thanks to the "Dura Shield" housing

[Enlarge](#)

[Product comparison](#)



### Download

[Download operating instructions as PDF \(3,7 MB\)](#)

### Further product recommendation



[Cordless Drill/Driver GSR 18 V](#)

### Pass on

[Recommend product](#)

### Bookmarks



### Blog product details

[Show code](#)

- Scope of delivery
- Technical data & functions
- Accessories

### Part no. 0 601 995 G71

- Quick Charger AL 1419 DV
- 2 x 2.0 Ah NiCd batteries (2 607 335 264)
- Carrying case (2 605 438 622)
- Keyless chuck 13 mm (2 608 572 182)

Drill chuck, version	Keyless chuck
----------------------	---------------

### Part no. 0 601 995 G72

- Quick Charger AL 1419 DV
- 3 x 2.0 Ah NiCd batteries (2 607 335 264)
- Carrying case (2 605 438 622)
- Keyless chuck 13 mm (2 608 572 182)

Drill chuck, version	Keyless chuck
----------------------	---------------

### Part no. 0 601 995 H70

- Quick Charger AL 1419 DV
- 2 x 2.6 Ah NiMH batteries (2 607 335 686)
- Carrying case (2 605 438 622)
- Keyless chuck 13 mm (2 608 572 182)

Drill chuck, version	Keyless chuck
----------------------	---------------


### Part no. 0 601 995 H71

- Quick Charger AL 1419 DV
- 3 x 2.6 Ah NiMH batteries (2 607 335 686)
- Carrying case (2 605 438 622)
- Keyless chuck 13 mm (2 608 572 182)

Drill chuck, version	Keyless chuck
----------------------	---------------

## Technical data

Torque, max. (hard screwdriving applications)	42 Nm
Torque, max. (soft screwdriving applications)	22 Nm
No-load speed (1st gear/2nd gear)	0 – 400 / 1.400 rpm
Chuck jaw width, min./max.	1,5 / 13 mm
Drill spindle thread	1/2"
Battery voltage	14,4 V
Weight incl. battery	2,0 kg
Charging time, approx.	60 min
Torque settings	20+1
Length	225,0 mm
Height	239,0 mm
<b>Drilling diameter</b>	
Max. drilling diameter in wood	35 mm
Max. drilling diameter in steel	13 mm
<b>Screw diameter</b>	
Max. screw diameter	8 mm

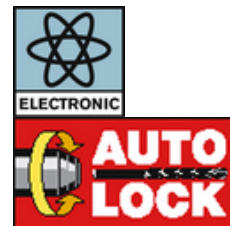

## Functions

- Multiple gears
- Self-drilling screws
- Infinitely variable speed control
- Forward/reverse operation
- Auto-Lock
- Softgrip

## Accessories

Whatever you plan to do — you can rely on original accessories from Bosch. You are guaranteed to find the appropriate accessory for your Bosch tools in our accessories catalogue.

[Go to the accessories catalogue](#)

[Print product details](#)

[▲ To top of page](#)