



Air moving solutions made simple



AC Fans
DC Fans



AC Blowers
DC Blowers



AC Impellers
DC Impellers



AC Motors



Accessories

Search

- Part/Model #
- Stock Check
- Cross-Reference
- Keyword

More Products

- Heat Sinks
- Fan Accessories
- Engineering Tools
 - Airflow Calculator
 - Thermal Calculator
 - Unit Conversions
 - Application Notes
- Custom Solutions
- Company Info
 - Contact Info
 - Technical Capability
 - Certifications
 - Terms & Conditions
 - Employment Ops

Gateway Online

Phone: 858.348.6200 FAX: 858.566.4577

Distributors

Find a Rep

Contact Us

Maltese AC - MA77B3 - 031844
 (Family) (Model) (Part Number)

Electrical Specifications

Rated Voltage:	230 VAC
AC Frequency:	60 Hz
Power Supply:	41.4 Watts
Line Current:	0.18 Amps
Locked Rotor Current	0.36 Amps
Nominal Speed:	3400 RPM

Mechanical Specifications

Dimensions:	6.77in x 5.91in x 2.17in
Weight	36.0 oz
Max Airflow @ 0 in H₂O	282.0 CFM
Max Pressure @ 0 CFM	0.840 in H₂O
Noise	56.6 dBA


Mechanical Drawing



Detailed Drawing



Printer-Friendly Datasheet

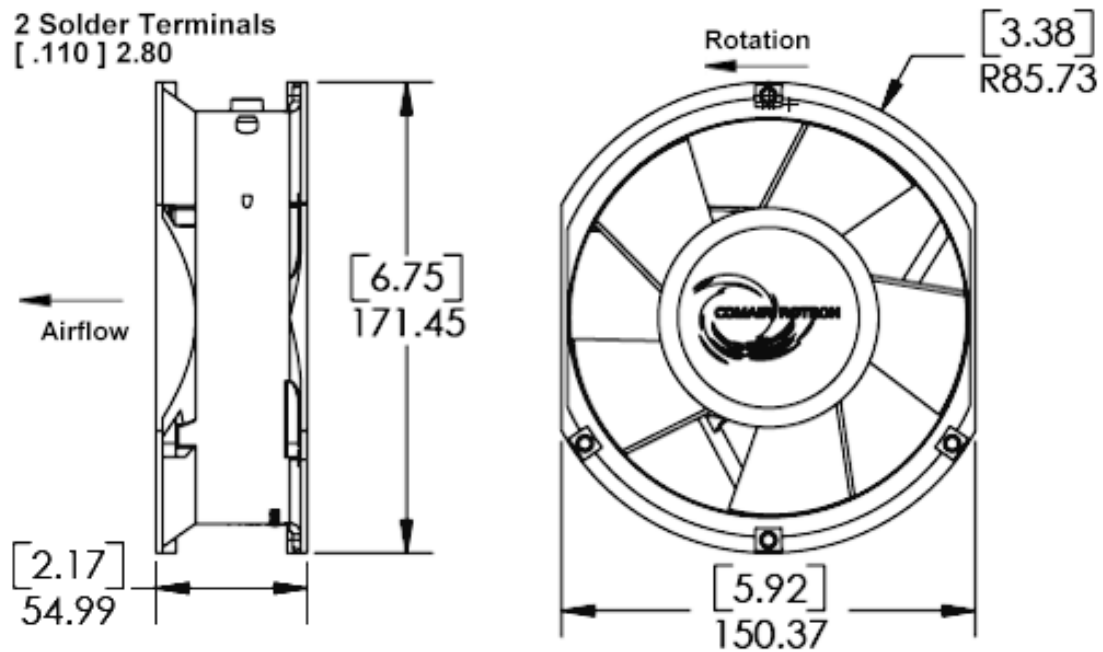


Options

Part Number	Model Number	Bearing Type	Fan Rotation	Termination	In-Stock (Click 'Yes' for current stock)
031844	MA77B3	Ball	Normal	0.110 Terminals	Yes
032962	MA77B6	Ball	Normal	12 in Leads Min	No


<<< Select the fan with desired options, then press the [Update Datasheet](#) button.

Accessories [\(Click on part number for detailed drawing.\)](#)

428056
Plug and Cord

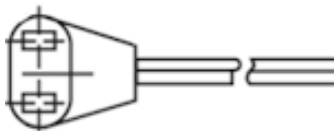

550440
Plug and Cord

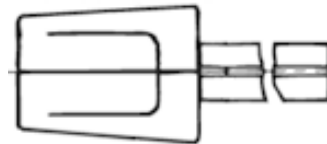

Comair Rotron, Inc.

Phone: 858.348.6200

FAX: 858.566.4577

sales@comairrotron.com

ThermaFlo, Inc.

Phone: 972.312.8609

FAX: 972.312.8617

info@thermaflo.com

Comair Rotron Europe, Ltd.

Phone: +44.1527.520525

FAX: +44.1527.520565

saleseurope@comairrotron.com

Comair Rotron Fan Company Ltd.

Phone: +86.21.52260581

FAX: +86.21.52260597

salesasia@comairrotron.com