




Fuse-holders RSH
for fuse-links 6,3 x 32 mm (1/4" x 1 1/4")

Fuse-holders OG
for fuse-links 6,3 x 32 mm (1/4" x 1 1/4")

Fuse-holders OGN
for fuse-links 5 x 20 mm




NEW

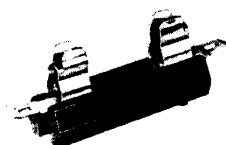


0031.6001 RSH







0031.6010 RSH

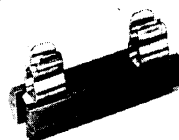

0031.8002 OG

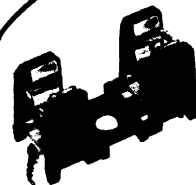

OGN 0031.8201
OGN 0031.8211

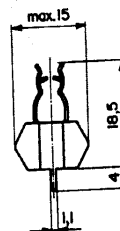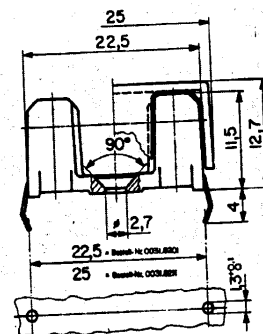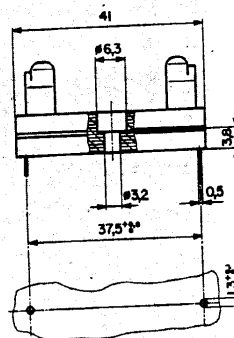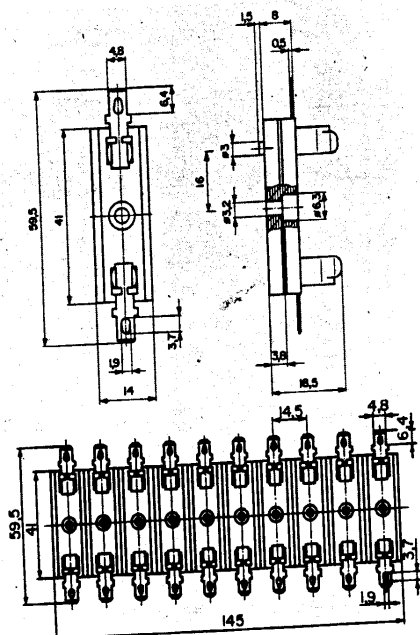

- Data: 10A / 250 V
- Fixing screw M3
- Solder/quick connect terminals 4,8 x 0,5 mm
- Thermoplastic (UL 94 V-0)
- Contact material nickel silver
- max. Power dissipation 4 W
- Approval

- Data: 10 A/250 V
- Printed circuit board mounting
- Thermoplastic (UL 94 V-0)
- max. Power dissipation 4 W
- Contact material german silver
- Contact material Copper-alloy, tin-plated

UL-Recognition (16 A / 500 V¹⁾ No. E 39328
 CSA-Certification (10 A / 250 V) No. LR 38456
 CS-Certification (10 A / 250 V) No. 4301N

• Approvals:
 SEV (10/250) No. 91.112471.02
 VDE (10/250) No. 70428
 SEMKO (10/250) No. 9147173
 UL (10/250) No. E39328
 CSA (10/250) No. LR38456
 CS (10/250) No. 4301N

¹⁾ Fuse-links according to the standards only for 250 V

¹⁾ Fuse-links according to the standards only for 250 V

Cover 0853.0551

Order No.

0031.6001	RSH	single
0031.6010	RSH	strips of 10 pieces

Order No.

0031.8002 OG

0031.8201 OGN
 pin distance 22,5 mm
 0031.8211 OGN
 pin distance 25 mm
 Replaces OG 0031.8001 /
 OGB 0031.8101