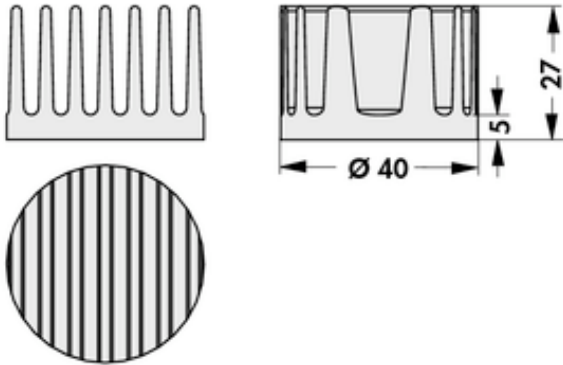


Heatsinks for LEDs / **ICK LED R 40 x 27**

$$R_{th} = 9,41 \text{ K/W}$$

Ø 40 x 27 mm, for IC design LED

Parameters of article ICK LED R 40 x 27

R_{th} [K/W]	i 9.41
dissipation loss [W]	i 12.1
mounting method	therm. conductive foil / therm. cond. adhesive
socket	universal
suitable for processor type	universal
Ø [mm]	i 40
height [mm]	27
plate thickness [mm]	5
surface treatment	black anodised

Accessories/ related articles

Thermally conductive foil both sides adhesive / **WLFT 404 D 40**

Thermally conductive foil both sides adhesive / **WLFT 405 D 40**