

Wall-mounting steel enclosures

Selection guide



CRN Wall-mounting steel enclosures												
Dimensions			No. of doors	IP	Weight (1)	Plain door with mounting plate	Plain door without mounting plate	Glazed door without mounting plate	Plain	Silkscreened	Microperforated	
H	W	D										
						Page CRN005_2			Page SPA002_2		Page SPA002_3	
200	200	150	1	66	2.5	-	NSYCRN22150 (2)	-	NSYMM22	-	-	
200	300	150	1	66	3.9	-	NSYCRN23150 (2)	-	NSYMM32	-	NSYMF32	
250	200	150	1	66	3.2	NSYCRN252150P	NSYCRN252150	-	NSYMM2520	-	-	
300	250	150	1	66	4.2	NSYCRN325150P	NSYCRN325150	NSYCRN325150T	NSYMM3025	-	-	
300	250	200	1	66	4.9	NSYCRN325200P	NSYCRN325200	NSYCRN325200T	NSYMM3025	-	-	
300	300	150	1	66	5	NSYCRN33150P	NSYCRN33150	NSYCRN33150T	NSYMM33	-	NSYMF33	
300	300	200	1	66	6	NSYCRN33200P	NSYCRN33200	NSYCRN33200T	NSYMM33	-	NSYMF33	
300	400	200	1	66	6.4	NSYCRN34200P	NSYCRN34200	NSYCRN34200T	NSYMM43	NSYMS43	NSYMF43	
300	450	150	1	66	6.7	-	NSYCRN345150 (2)	-	NSYMM3045	-	-	
400	300	150	1	66	6	NSYCRN43150P	NSYCRN43150	NSYCRN43150T	NSYMM43	NSYMS43	NSYMF43	
400	300	200	1	66	6.8	NSYCRN43200P	NSYCRN43200	NSYCRN43200T	NSYMM43	NSYMS43	NSYMF43	
400	400	200	1	66	8	NSYCRN44200P	NSYCRN44200	NSYCRN44200T	NSYMM44	NSYMS44	NSYMF44	
400	600	250	1	66	10	NSYCRN46250P	NSYCRN46250	NSYCRN46250T	NSYMM64	NSYMS64	NSYMF64	
400	600	300	1	66	11.2	NSYCRN46300P	NSYCRN46300	NSYCRN46300T	NSYMM64	NSYMS64	NSYMF64	
500	400	150	1	66	8.7	NSYCRN54150P	NSYCRN54150	NSYCRN54150T	NSYMM54	NSYMS54	NSYMF54	
500	400	200	1	66	9.8	NSYCRN54200P	NSYCRN54200	NSYCRN54200T	NSYMM54	NSYMS54	NSYMF54	
500	400	250	1	66	11	NSYCRN54250P	NSYCRN54250	NSYCRN54250T	NSYMM54	NSYMS54	NSYMF54	
500	500	250	1	66	12.8	NSYCRN55250P	NSYCRN55250	NSYCRN55250T	NSYMM55	NSYMS55	NSYMF55	
600	400	150	1	66	9.3	NSYCRN64150P	NSYCRN64150	NSYCRN64150T	NSYMM64	NSYMS64	NSYMF64	
600	400	200	1	66	10.8	NSYCRN64200P	NSYCRN64200	NSYCRN64200T	NSYMM64	NSYMS64	NSYMF64	
600	400	250	1	66	12.3	NSYCRN64250P	NSYCRN64250	NSYCRN64250T	NSYMM64	NSYMS64	NSYMF64	
600	500	150	1	66	11.3	NSYCRN65150P	NSYCRN65150	NSYCRN65150T	NSYMM65	-	NSYMF65	
600	500	200	1	66	14.3	NSYCRN65200P	NSYCRN65200	NSYCRN65200T	NSYMM65	-	NSYMF65	
600	500	250	1	66	16.2	NSYCRN65250P	NSYCRN65250	NSYCRN65250T	NSYMM65	-	NSYMF65	
600	600	200	1	66	16.3	-	NSYCRN66200	NSYCRN66200T	NSYMM66	NSYMS66	NSYMF66	
600	600	250	1	66	18.2	NSYCRN66250P	NSYCRN66250	NSYCRN66250T	NSYMM66	NSYMS66	NSYMF66	
600	600	300	1	66	19.8	NSYCRN66300P	NSYCRN66300	NSYCRN66300T	NSYMM66	NSYMS66	NSYMF66	
600	800	300	1	66	26	-	NSYCRN68300	NSYCRN68300T	NSYMM86	NSYMS86	NSYMF86	
700	500	200	1	66	17.3	NSYCRN75200P	NSYCRN75200	NSYCRN75200T	NSYMM75	NSYMS75	NSYMF75	
700	500	250	1	66	19.3	NSYCRN75250P	NSYCRN75250	NSYCRN75250T	NSYMM75	NSYMS75	NSYMF75	
800	600	200	1	66	21.8	NSYCRN86200P	NSYCRN86200	NSYCRN86200T	NSYMM86	NSYMS86	NSYMF86	
800	600	250	1	66	24.8	NSYCRN86250P	NSYCRN86250	NSYCRN86250T	NSYMM86	NSYMS86	NSYMF86	
800	600	300	1	66	26.3	NSYCRN86300P	NSYCRN86300	NSYCRN86300T	NSYMM86	NSYMS86	NSYMF86	
800	800	200	1	66	29.5	NSYCRN88200P	NSYCRN88200	NSYCRN88200T	NSYMM88	-	NSYMF88	
800	800	300	1	66	32.5	NSYCRN88300P	NSYCRN88300	NSYCRN88300T	NSYMM86	-	NSYMF88	
1000	600	250	1	66	28.4	NSYCRN106250P	NSYCRN106250	NSYCRN106250T	NSYMM106	-	NSYMF106	
1000	600	300	1	66	30.6	NSYCRN106300P	NSYCRN106300	NSYCRN106300T	NSYMM106	-	NSYMF106	
1000	800	250	1	66	34.5	NSYCRN108250P	NSYCRN108250	NSYCRN108250T	NSYMM108	-	NSYMF108	
1000	800	300	1	66	37.4	NSYCRN108300P	NSYCRN108300	NSYCRN108300T	NSYMM108	-	NSYMF108	
CRNG Wall-mounting steel enclosures with three-point locking system												
800	600	400	1	66	30	-	NSYCRNG86400	NSYCRNG86400T	NSYMM86	NSYMS86	NSYMF86	
800	1000	300	2	55	40	-	NSYCRNG810300D	-	NSYMM108	-	NSYMF108	
800	1200	300	2	55	46	-	NSYCRNG812300D	-	NSYMM128	-	NSYMF128	
1000	600	400	1	66	36	-	NSYCRNG106400	NSYCRNG106400T	NSYMM106	-	NSYMF106	
1000	800	400	1	66	43	-	NSYCRNG108400	NSYCRNG108400T	NSYMM108	-	NSYMF108	
1000	1000	300	2	55	47	-	NSYCRNG1010300D	NSYCRNG1010300T	NSYMM1010	-	NSYMF1010	
1000	1200	300	2	55	55	-	NSYCRNG1012300D	-	NSYMM1210	-	NSYMF1210	
1000	1200	400	2	55	60	-	NSYCRNG1012400D	-	NSYMM1210	-	NSYMF1210	
1200	600	300	1	66	37	-	NSYCRNG126300	NSYCRNG126300T	NSYMM126	-	NSYMF126	
1200	600	400	1	66	42	-	NSYCRNG126400	NSYCRNG126400T	NSYMM126	-	NSYMF126	
1200	800	300	1	66	45	-	NSYCRNG128300	NSYCRNG128300T	NSYMM128	-	NSYMF128	
1200	800	400	1	66	50	-	NSYCRNG128400	NSYCRNG128400T	NSYMM128	-	NSYMF128	
1200	1000	300	2	55	56	-	NSYCRNG1210300D	-	NSYMM1210	-	NSYMF1210	
1200	1000	400	2	55	61	-	NSYCRNG1210400D	-	NSYMM1210	-	NSYMF1210	
1200	1200	300	2	55	64	-	NSYCRNG1212300D	-	NSYMM1212	-	2 × NSYMF126	
1200	1200	400	2	55	90	-	NSYCRNG1212400D	-	NSYMM1212	-	2 × NSYMF126	
1400	1000	300	2	55	80	-	NSYCRNG1410300D	-	NSYMM1410	-	-	

(1) Enclosure without mounting plate.

(2) Two cable gland plates, one on the top, one on the bottom.

Spacial CRN - CRNG



	Telequick	Bakelite	DIN rails chassis	Step slides	Cable entry				
					Figure	Type of cable entry	Standard cable-gland plate	Insulated cable-gland plate	Cable-gland plate with FL21 cut-out
							Page CRN014_4	Page CRN014_3	Page CRN014_2
Page SPA002_4	Page SPA002_6	Page SPA002_7	Page SPA002_9						
-	-	-	-	-	1	0	NSYTLCRNO	-	-
-	NSYMB32	-	-	-	1	B	NSYTLCRNB	-	-
-	-	-	-	-	1	0	NSYTLCRNO	-	-
NSYMR3025	NSYMB3025	-	-	-	1	A	NSYTLCRNB	NSYTSACRNB	-
NSYMR3025	NSYMB3025	-	NSYSDCR200	-	1	A	NSYTLCRNB	NSYTSACRNB	-
NSYMR33	NSYMB33	NSYMD33	-	-	1	B	NSYTLCRNB	NSYTSACRNB	-
NSYMR33	NSYMB33	NSYMD33	NSYSDCR200	-	1	B	NSYTLCRNB	NSYTSACRNB	-
NSYMR34	NSYMB43	-	NSYSDCR200	-	1	C	NSYTLCRNC	NSYTSACRNC	NSYTFL21CRNC
-	NSYMB43	-	-	-	1	B	NSYTLCRNB	NSYTSACRNB	-
NSYMR43	NSYMB43	NSYMD43	-	-	1	B	NSYTLCRNB	NSYTSACRNB	-
NSYMR43	NSYMB43	NSYMD43	NSYSDCR200	-	1	B	NSYTLCRNB	NSYTSACRNB	-
NSYMR44	-	-	NSYSDCR200	-	1	C	NSYTLCRNC	NSYTSACRNC	NSYTFL21CRNC
NSYMR46	NSYMB64	-	NSYSDCR250	-	1	D	NSYTLCRND	NSYTSACRND	NSYTFL21CRND
NSYMR46	NSYMB64	-	NSYSDCR300	-	1	D	NSYTLCRND	NSYTSACRND	-
NSYMR54	NSYMB54	NSYMD54	-	-	2	B	NSYTLCRNB	NSYTSACRNB	-
NSYMR54	NSYMB54	NSYMD54	NSYSDCR200	-	2	C	NSYTLCRNC	NSYTSACRNC	NSYTFL21CRNC
NSYMR54	NSYMB54	NSYMD54	NSYSDCR250	-	2	C	NSYTLCRNC	NSYTSACRNC	NSYTFL21CRNC
NSYMR55	-	-	NSYSDCR250	-	2	D	NSYTLCRND	NSYTSACRND	NSYTFL21CRND
NSYMR64	NSYMB64	NSYMD64	-	-	2	B	NSYTLCRNB	NSYTSACRNB	-
NSYMR64	NSYMB64	NSYMD64	NSYSDCR200	-	2	C	NSYTLCRNC	NSYTSACRNC	NSYTFL21CRNC
NSYMR64	NSYMB64	NSYMD64	NSYSDCR250	-	2	C	NSYTLCRNC	NSYTSACRNC	NSYTFL21CRNC
NSYMR65	NSYMB65	-	-	-	2	B	NSYTLCRNB	NSYTSACRNB	-
NSYMR65	NSYMB65	-	NSYSDCR200	-	2	D	NSYTLCRND	NSYTSACRND	NSYTFL21CRND
NSYMR65	NSYMB65	-	NSYSDCR250	-	2	D	NSYTLCRND	NSYTSACRND	NSYTFL21CRND
NSYMR66	-	NSYMD66	NSYSDCR200	-	2	D	NSYTLCRND	NSYTSACRND	NSYTFL21CRND
NSYMR66	-	NSYMD66	NSYSDCR250	-	2	D	NSYTLCRND	NSYTSACRND	NSYTFL21CRND
NSYMR66	-	NSYMD66	NSYSDCR300	-	2	D	NSYTLCRND	NSYTSACRND	NSYTFL21CRND
NSYMR68	-	-	NSYSDCR300	-	2	E	NSYTLCRNC (3)	NSYTSACRNC	NSYTFL21CRNC
NSYMR75	NSYMB75	NSYMD75	NSYSDCR200	-	2	D	NSYTLCRND	NSYTSACRND	NSYTFL21CRND
NSYMR75	NSYMB75	NSYMD75	NSYSDCR250	-	2	D	NSYTLCRND	NSYTSACRND	NSYTFL21CRND
NSYMR86	NSYMB86	NSYMD86	NSYSDCR200	-	2	D	NSYTLCRND	NSYTSACRND	NSYTFL21CRND
NSYMR86	NSYMB86	NSYMD86	NSYSDCR250	-	2	D	NSYTLCRND	NSYTSACRND	NSYTFL21CRND
NSYMR86	NSYMB86	NSYMD86	NSYSDCR300	-	2	D	NSYTLCRND	NSYTSACRND	NSYTFL21CRND
NSYMR88	-	-	NSYSDCR200	-	2	E	NSYTLCRNC (3)	NSYTSACRNC (4)	NSYTFL21CRNC
NSYMR88	-	-	NSYSDCR300	-	2	E	NSYTLCRNC (3)	NSYTSACRNC (4)	NSYTFL21CRNC
NSYMR106	NSYMB106	-	NSYSDCR250	-	2	D	NSYTLCRND	NSYTSACRND	NSYTFL21CRND
NSYMR106	NSYMB106	-	NSYSDCR300	-	2	D	NSYTLCRND	NSYTSACRND	NSYTFL21CRND
NSYMR108	NSYMB108	NSYMD108	NSYSDCR250	-	2	E	NSYTLCRNC (3)	NSYTSACRNC (4)	NSYTFL21CRNC
NSYMR108	NSYMB108	NSYMD108	NSYSDCR300	-	2	E	NSYTLCRNC (3)	NSYTSACRNC (4)	NSYTFL21CRNC
NSYMR86	NSYMB86	NSYMD86	NSYSDCR400	-	3	G	NSYTLCRNB	-	NSYTFL21CRNB
NSYMR810	-	-	NSYSDCR300	-	4	G	NSYTLCRNB	-	NSYTFL21CRNB
2 × NSYMR86*	-	-	NSYSDCR300**	-	4	G	NSYTLCRNB	-	NSYTFL21CRNB
NSYMR106	NSYMB106	-	NSYSDCR400	-	3	G	NSYTLCRNB	-	NSYTFL21CRNB
NSYMR108	NSYMB108	NSYMD108	NSYSDCR400	-	3	G	NSYTLCRNB	-	NSYTFL21CRNB
NSYMR1010	NSYMB1210	-	NSYSDCR300	-	4	G	NSYTLCRNB	-	NSYTFL21CRNB
NSYMR1012	NSYMB1210	-	NSYSDCR300**	-	4	G	NSYTLCRNB	-	NSYTFL21CRNB
NSYMR1012	-	-	NSYSDCR400**	-	4	G	NSYTLCRNB	-	NSYTFL21CRNB
NSYMR126	-	-	NSYSDCR300	-	3	G	NSYTLCRNB	-	NSYTFL21CRNB
NSYMR126	-	-	NSYSDCR400	-	3	G	NSYTLCRNB	-	NSYTFL21CRNB
NSYMR128	-	NSYMD128	NSYSDCR300	-	3	G	NSYTLCRNB	-	NSYTFL21CRNB
NSYMR128	-	NSYMD128	NSYSDCR400	-	4	G	NSYTLCRNB	-	NSYTFL21CRNB
NSYMR1210	NSYMB1210	-	NSYSDCR300	-	4	G	NSYTLCRNB	-	NSYTFL21CRNB
NSYMR1210	NSYMB1210	-	NSYSDCR400	-	4	G	NSYTLCRNB	-	NSYTFL21CRNB
2 × NSYMR126	-	-	NSYSDCR300**	-	4	G	NSYTLCRNB	-	NSYTFL21CRNB
2 × NSYMR126	-	-	NSYSDCR400**	-	4	G	NSYTLCRNB	-	NSYTFL21CRNB
NSYMR1410	-	-	NSYSDCR300	-	4	G	NSYTLCRNB	-	NSYTFL21CRNB

(3) With two holes.


(4) For flange openings type E, two NSYTSACRNC are required.

*Order NSYCRNGSDR to mount double mounting plate.

**Except for double mounting plate, order in addition ref. NSYSDRSDCR300 (D300) or NSYSDRSDCR400 (D400).

Wall-mounting steel enclosures

Selection guide

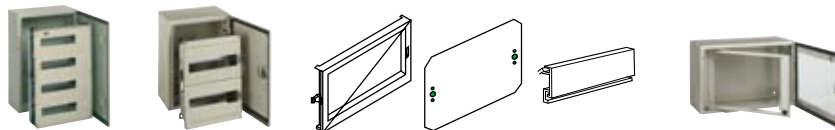


CRN Wall-mounting steel enclosures													
Dimensions			No. of doors	IP	Weight (1)	Electric distribution						Electronic and network	
H	W	D				DLA insulated distribution chassis	DL metal distribution chassis	DLM metal distribution chassis	Plain cover plate	Mounting plate	Blanking plate	Fixed 19" rack	Swing 19" rack
						Page PLM010_2	Page SPA008_3	Page SPA008_2	Page SPA008_5		Page SPA008_4	Page VDM_002_2	Page VDM_002_2
200	200	150	1	66	2.5	-	-	-	-	-	-	-	-
200	300	150	1	66	3.9	-	-	-	-	-	-	-	-
250	200	150	1	66	3.2	-	-	-	-	-	-	-	-
300	250	150	1	66	4.2	NSYDLPLM18	NSYDLCR18	-	-	-	-	-	-
300	250	200	1	66	4.9	NSYDLPLM18	NSYDLCR18	-	-	-	-	-	-
300	300	150	1	66	5	-	-	-	-	-	-	-	-
300	300	200	1	66	6	-	-	-	-	-	-	-	-
300	400	200	1	66	6.4	-	-	-	-	-	-	-	-
300	450	150	1	66	6.7	-	-	-	-	-	-	-	-
400	300	150	1	66	6	NSYDLA24	NSYDLCR24/ NSYDLCR36	NSYDLM24	NSYCTL300DLM	NSYPMP300DLM	NSYATP72G	-	-
400	300	200	1	66	6.8	NSYDLA24	NSYDLCR24* (2)/ NSYDLCR36* (2)	NSYDLM24	NSYCTL300DLM	NSYPMP300DLM	NSYATP72G	-	-
400	400	200	1	66	8	-	-	-	-	-	-	-	-
400	600	250	1	66	10	-	-	-	-	-	NSYVDM8UF	NSYVDM7UP	-
400	600	300	1	66	11.2	-	-	-	-	-	NSYVDM8UF	NSYVDM7UP	-
400	400	150	1	66	8.7	NSYDLA48	NSYDLCR48	NSYDLM48	NSYCTL400DLM	NSYPMP400DLM	NSYATP72G	-	-
500	400	200	1	66	9.8	NSYDLA48	NSYDLCR48* (2)	NSYDLM48	NSYCTL400DLM	NSYPMP400DLM	NSYATP72G	-	-
500	400	250	1	66	11	NSYDLA48	-	NSYDLM48	NSYCTL400DLM	NSYPMP400DLM	NSYATP72G	-	-
500	500	250	1	66	12.8	-	-	-	-	-	-	-	-
600	400	150	1	66	9.3	NSYDLA48P	NSYDLCR64	NSYDLM48P	NSYCTL400DLM	NSYPMP400DLM	NSYATP72G	-	-
600	400	200	1	66	10.8	NSYDLA48P	NSYDLCR64	NSYDLM48P	NSYCTL400DLM	NSYPMP400DLM	NSYATP72G	-	-
600	400	250	1	66	12.3	NSYDLA48P	-	NSYDLM48P	NSYCTL400DLM	NSYPMP400DLM	NSYATP72G	-	-
600	500	150	1	66	11.3	-	NSYDLCR88	-	-	-	-	-	-
600	500	200	1	66	14.3	-	NSYDLCR88	-	-	-	-	-	-
600	500	250	1	66	16.2	-	-	-	-	-	-	-	-
600	600	200	1	66	16.3	-	-	NSYDLM84P	NSYCTL600DLM	NSYPMP600DLM	NSYATP72G	NSYVDM12UF	NSYVDM11UP
600	600	250	1	66	18.2	-	-	NSYDLM84P	NSYCTL600DLM	NSYPMP600DLM	NSYATP72G	NSYVDM12UF	NSYVDM11UP
600	600	300	1	66	19.8	-	-	NSYDLM84P	NSYCTL600DLM	NSYPMP600DLM	NSYATP72G	NSYVDM12UF	NSYVDM11UP
600	800	300	1	66	26	-	-	-	-	-	-	-	-
700	500	200	1	66	17.3	NSYDLA66/NSYDLA88	NSYDLCR110	NSYDLM66/NSYDLM88	NSYCTL500DLM	NSYPMP500DLM	NSYATP72G	-	-
700	500	250	1	66	19.3	NSYDLA66/NSYDLA88	-	NSYDLM66/NSYDLM88	NSYCTL500DLM	NSYPMP500DLM	NSYATP72G	-	-
800	600	200	1	66	21.8	NSYDLA84/NSYDLA112	NSYDLCR135	NSYDLM84/NSYDLM112	NSYCTL600DLM	NSYPMP600DLM	NSYATP72G	NSYVDM17UF	-
800	600	250	1	66	24.8	NSYDLA84/NSYDLA112	-	NSYDLM84/NSYDLM112	NSYCTL600DLM	NSYPMP600DLM	NSYATP72G	NSYVDM17UF	NSYVDM16UP
800	600	300	1	66	26.3	NSYDLA84/NSYDLA112	-	NSYDLM84/NSYDLM112	NSYCTL600DLM	NSYPMP600DLM	NSYATP72G	NSYVDM17UF	NSYVDM16UP
800	800	200	1	66	29.5	-	-	-	-	-	-	-	-
800	800	300	1	66	32.5	-	-	-	-	-	-	-	-
1000	600	250	1	66	28.4	-	-	NSYDLM168	NSYCTL600DLM	NSYPMP600DLM	NSYATP72G	NSYVDM21UF	NSYVDM20UP
1000	600	300	1	66	30.6	-	-	NSYDLM168	NSYCTL600DLM	NSYPMP600DLM	NSYATP72G	NSYVDM21UF	NSYVDM20UP
1000	800	250	1	66	34.5	NSYDLA234	-	NSYDLM240	NSYCTL800DLM	NSYPMP800DLM	NSYATP72G	-	NSYVDM20U8P
1000	800	300	1	66	37.4	NSYDLA234	-	NSYDLM240	NSYCTL800DLM	NSYPMP800DLM	NSYATP72G	-	NSYVDM20U8P
CRNG Wall-mounting steel enclosures													
800	600	400	1	66	30	NSYDLA84/NSYDLA112	-	NSYDLM84/NSYDLM112	NSYCTL600DLM	NSYPMP600DLM	NSYATP72G	NSYVDM17UF	NSYVDM16UP
800	1000	300	2	55	40	-	-	-	-	-	-	-	-
800	1200	300	2	55	46	-	-	-	-	-	-	-	-
1000	600	400	1	66	36	-	-	NSYDLM168	NSYCTL600DLM	NSYPMP600DLM	NSYATP72G	NSYVDM21UF	NSYVDM20UP
1000	800	400	1	66	43	NSYDLA234	-	NSYDLM240	NSYCTL800DLM	NSYPMP800DLM	NSYATP72G	-	NSYVDM20U8P
1000	1000	300	2	55	47	-	-	-	-	-	-	-	-
1000	1200	300	2	55	55	-	-	-	-	-	-	-	-
1000	1200	400	2	55	60	-	-	-	-	-	-	-	-
1200	600	300	1	66	37	-	-	-	-	-	-	-	-
1200	600	400	1	66	42	-	-	-	-	-	-	-	-
1200	800	300	1	66	45	-	-	-	-	-	-	-	NSYVDM25U8P
1200	800	400	1	66	50	-	-	-	-	-	-	-	NSYVDM25U8P
1200	1000	300	2	55	56	-	-	-	-	-	-	-	-
1200	1000	400	2	55	61	-	-	-	-	-	-	-	-
1200	1200	300	2	55	64	-	-	-	-	-	-	-	-
1200	1200	400	2	55	90	-	-	-	-	-	-	-	-
1400	1000	300	2	55	80	-	-	-	-	-	-	-	-

(1) Enclosure without mounting plate.

(2) To be coupled in 200 mm depth enclosure, the lifting bracket ref. **NSYEX608** must be ordered separately.

Spacial CRN - CRNG

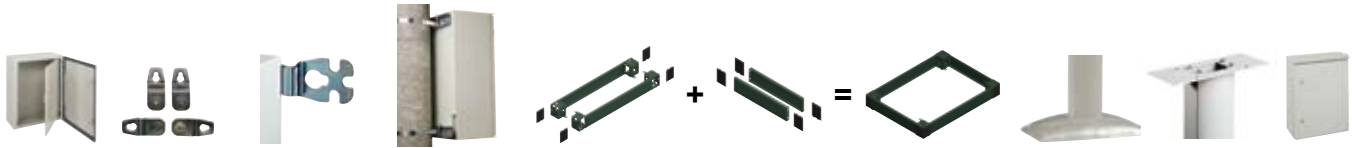

Installation system											
	Inner door	Wall-fixing lugs	Set for heavy-load fixing brackets*	Post-fixing device	Single plinths side plate**		Single plinths front plate**		Supporting pole	Coupling plates	Canopies
					100 mm	200 mm	100 mm	200 mm			
	Page CRN013_4	Page CRN012_2	Page SPB001_2	Page SPB001_3	Page SPB001_4				Page CRN012_3	Page SPB003_3	
-	-	NSYPFCR	-	-	-	-	-	-	-	-	-
-	-	NSYPFCR	-	-	-	-	-	-	-	-	-
-	-	NSYPFCR	-	-	-	-	-	-	NSYCOCN80	-	NSYTJ2015
-	-	NSYPFCR	-	-	-	-	-	-	NSYCOCN80	NSYCHCOA	NSYTJ2515
-	-	NSYPFCR	-	-	-	-	-	-	NSYCOCN80	NSYCHCOA	NSYTJ2520
-	-	-	-	NSYSFPSC30	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ3015
-	-	-	-	NSYSFPSC30	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ3020
-	-	-	-	NSYSFPSC40	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ4020
-	-	NSYPFCR	-	-	-	-	-	-	-	-	-
NSYPIN43	NSYPFCR	-	-	NSYSFPSC30	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ3015
NSYPIN43	NSYPFCR	-	-	NSYSFPSC30	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ3020
-	NSYPFCR	-	-	NSYSFPSC40	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ4020
-	NSYPFCR	-	-	NSYSFPSC60	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ6025
-	NSYPFCR	-	-	NSYSFPSC60	NSYS3100SD	NSYS3200SD	NSYS3100SD	NSYS3200SD	NSYCOCN80	NSYCHCOB	NSYTJ6030
NSYPIN54	NSYPFCR	-	-	NSYSFPSC40	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ4015
NSYPIN54	NSYPFCR	-	-	NSYSFPSC40	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ4020
NSYPIN54	NSYPFCR	-	-	NSYSFPSC40	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ4025
-	NSYPFCR	-	-	NSYSFPSC50	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ5025
NSYPIN64	NSYPFCR	-	-	NSYSFPSC40	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ4015
NSYPIN64	NSYPFCR	-	-	NSYSFPSC40	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ4020
NSYPIN64	NSYPFCR	-	-	NSYSFPSC40	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ4025
-	NSYPFCR	-	-	NSYSFPSC50	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ5015
-	NSYPFCR	-	-	NSYSFPSC50	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ5020
-	NSYPFCR	-	-	NSYSFPSC50	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ5025
-	NSYPFCR	-	-	NSYSFPSC60	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ6020
-	NSYPFCR	-	-	NSYSFPSC60	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ6025
-	NSYPFCR	-	-	NSYSFPSC60	NSYS3100SD	NSYS3200SD	NSYS3100SD	NSYS3200SD	NSYCOCN80	NSYCHCOB	NSYTJ6030
-	NSYPFCR	-	-	NSYSFPSC80	NSYS3100SD	NSYS3200SD	NSYS3100SD	NSYS3200SD	NSYCOCN80	NSYCHCOB (3)	NSYTJ8030
NSYPIN75	NSYPFCR	-	-	NSYSFPSC50	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ5020
NSYPIN75	NSYPFCR	-	-	NSYSFPSC50	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ5025
NSYPIN86	NSYPFCR	-	-	NSYSFPSC60	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ6020
NSYPIN86	NSYPFCR	-	-	NSYSFPSC60	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ6025
NSYPIN86	NSYPFCR	-	-	NSYSFPSC60	NSYS3100SD	NSYS3200SD	NSYS3100SD	NSYS3200SD	NSYCOCN80	NSYCHCOB	NSYTJ6030
-	NSYPFCR	-	-	NSYSFPSC80	NSYS3100SD	NSYS3200SD	NSYS3100SD	NSYS3200SD	NSYCOCN80	NSYCHCOB (3)	NSYTJ8020
-	NSYPFCR	-	-	NSYSFPSC80	NSYS3100SD	NSYS3200SD	NSYS3100SD	NSYS3200SD	NSYCOCN80	NSYCHCOB (3)	NSYTJ8030
NSYPIN106	NSYPFCR	-	-	-	-	-	-	-	NSYCOCN80	NSYCHCOB	NSYTJ6025
NSYPIN106	NSYPFCR	-	-	-	NSYS3100SD	NSYS3200SD	NSYS3100SD	NSYS3200SD	NSYCOCN80	NSYCHCOB	NSYTJ6030
NSYPIN108	NSYPFCR	-	-	-	-	-	-	-	NSYCOCN80	NSYCHCOB (3)	NSYTJ8025
NSYPIN108	NSYPFCR	-	-	-	NSYS3100SD	NSYS3200SD	NSYS3100SD	NSYS3200SD	NSYCOCN80	NSYCHCOB (3)	NSYTJ8030
NSYPIN86	NSYAEFPFSC	NSYAEFAHLBSC	NSYAEFAHLBSC	NSYSFPSC60	NSYS34100SD	NSYS34200SD	NSYS34100SD	NSYS34200SD	-	-	NSYTJ6040
-	NSYAEFPFSC	NSYAEFAHLBSC	NSYAEFAHLBSC	-	NSYS3100SD	NSYS3200SD	NSYS3100SD	NSYS3200SD	-	-	NSYTJ10030
-	NSYAEFPFSC	NSYAEFAHLBSC	NSYAEFAHLBSC	-	NSYS3100SD	NSYS3200SD	NSYS3100SD	NSYS3200SD	-	-	NSYTJ12030
NSYPIN106	NSYAEFPFSC	NSYAEFAHLBSC	NSYAEFAHLBSC	-	NSYS34100SD	NSYS34200SD	NSYS34100SD	NSYS34200SD	-	-	NSYTJ6040
NSYPIN108	NSYAEFPFSC	NSYAEFAHLBSC	NSYAEFAHLBSC	-	NSYS34100SD	NSYS34200SD	NSYS34100SD	NSYS34200SD	-	-	NSYTJ8040
-	NSYAEFPFSC	NSYAEFAHLBSC	NSYAEFAHLBSC	-	NSYS3100SD	NSYS3200SD	NSYS3100SD	NSYS3200SD	-	-	NSYTJ10030
-	NSYAEFPFSC	NSYAEFAHLBSC	NSYAEFAHLBSC	-	NSYS3100SD	NSYS3200SD	NSYS3100SD	NSYS3200SD	-	-	NSYTJ12030
-	NSYAEFPFSC	NSYAEFAHLBSC	NSYAEFAHLBSC	-	NSYS34100SD	NSYS34200SD	NSYS34100SD	NSYS34200SD	-	-	NSYTJ12040
NSYPIN126	NSYAEFPFSC	NSYAEFAHLBSC	NSYAEFAHLBSC	-	NSYS3100SD	NSYS3200SD	NSYS3100SD	NSYS3200SD	-	-	NSYTJ6030
NSYPIN126	NSYAEFPFSC	NSYAEFAHLBSC	NSYAEFAHLBSC	-	NSYS34100SD	NSYS34200SD	NSYS34100SD	NSYS34200SD	-	-	NSYTJ6040
NSYPIN128	NSYAEFPFSC	NSYAEFAHLBSC	NSYAEFAHLBSC	-	NSYS3100SD	NSYS3200SD	NSYS3100SD	NSYS3200SD	-	-	NSYTJ8030
NSYPIN128	NSYAEFPFSC	NSYAEFAHLBSC	NSYAEFAHLBSC	-	NSYS34100SD	NSYS34200SD	NSYS34100SD	NSYS34200SD	-	-	NSYTJ8040
-	NSYAEFPFSC	NSYAEFAHLBSC	NSYAEFAHLBSC	-	NSYS3100SD	NSYS3200SD	NSYS3100SD	NSYS3200SD	-	-	NSYTJ10030
-	NSYAEFPFSC	NSYAEFAHLBSC	NSYAEFAHLBSC	-	NSYS34100SD	NSYS34200SD	NSYS34100SD	NSYS34200SD	-	-	NSYTJ10040
-	NSYAEFPFSC	NSYAEFAHLBSC	NSYAEFAHLBSC	-	NSYS3100SD	NSYS3200SD	NSYS3100SD	NSYS3200SD	-	-	NSYTJ12030
-	NSYAEFPFSC	NSYAEFAHLBSC	NSYAEFAHLBSC	-	NSYS34100SD	NSYS34200SD	NSYS34100SD	NSYS34200SD	-	-	NSYTJ12040
-	NSYAEFPFSC	NSYAEFAHLBSC	NSYAEFAHLBSC	-	NSYS3100SD	NSYS3200SD	NSYS3100SD	NSYS3200SD	-	-	NSYTJ10030

(3) 2 coupling plates and supporting poles are required.
* Order the NSYAEFPFSC wall-fixing brackets separately.

**To install the plinth to a wall-mounting enclosure, order ref. NSYAPFWM.