



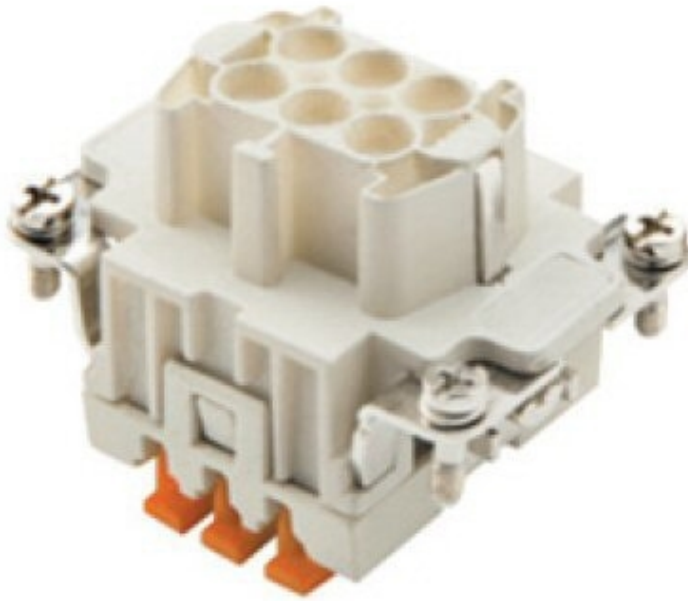

Product Sheet

Part Number: CSHF 06

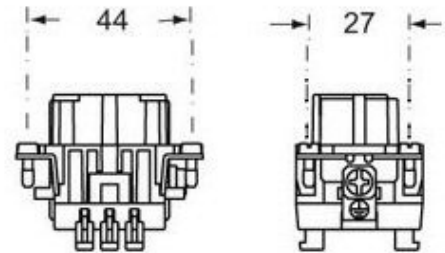

Dimensions in mm



Family	inserts
Version	Spring connection contacts SQUICH
Series	CSH
Product type	with female contacts
Model	female insert
Reference standard	EN 61984 (2001-11)
Contact type	silver plated
No. of poles	6 poles + 
Voltage (V)	500V
Current (A)	16A (A.C. and D.C.)
Wire section	0,14mm ² - 2,5mm ²
Awg size	26 - 14
Quality mark	
IP degree of protection	IP20 degree of protection without enclosure; IP65, IP66, IP68 (EN 60529) and IP69K (DIN 40050 - 9) with enclosure
Fixing centre distance	size "44.27"
Impulse withstand voltage	6kV
Pollution degree	3

The information and the dimensions are not binding and may be changed without prior notice.