

SMART FLOOD

An excellent low energy fitting ideal for sign lighting and a host of commercial & domestic, courtesy and security flood lighting uses.

The low energy Compact Fluorescent lamps provides compliance with L1 building requirements for the provision of energy saving lighting.

The low energy smart flood has been expertly designed with an attention to detail. The compact and robust impact resistant UV stabilised polycarbonate casing offers a lightweight, shatterproof unit with a host of features to help speed up installation time.


- Low Energy Flood Light.
- IP65.
- Integral Photocell Option. (external use only).
- Polycarbonate Case and Diffuser.
- Light Weight.
- Compact & Robust construction.
- Extremely Easy to Install.
- Asymmetric Reflector.
- Hinged Front Facia.
- Available in: Black, White and Titanium finishes.

Lamp & Operating options

- 13w – 26w TCD.
- 32w – 42w TCT (high frequency only).
- Switch Start PFC and High frequency operating options.

Designed with a host of features to speed installation time

- Brass Inserts.
- Light Weight.
- Mounting Angle Referencing.
- Quick fix mounting bracket – attach the luminaire with the fitting attached.
- Ratchet System on Bracket.

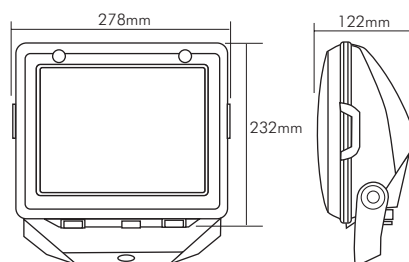



Description	13W PFC	13W PFC PC	13W HF	13W HF PC
Black	SFL/B113F	SFL/B113FC	SFL/B113E	SFL/B113EC
White	SFL/W113F	SFL/W113FC	SFL/W113E	SFL/W113EC
Titanium	SFL/X113F	SFL/X113FC	SFL/X113E	SFL/X113EC
Description	18W PFC	18W PFC PC	18W HF	18W HF PC
Black	SFL/B118F	SFL/B118FC	SFL/B118E	SFL/B118EC
White	SFL/W118F	SFL/W118FC	SFL/W118E	SFL/W118EC
Titanium	SFL/X118F	SFL/X118FC	SFL/X118E	SFL/X118EC
Description	26W PFC	26W PFC PC	26W HF	26W HF PC
Black	SFL/B126F	SFL/B126FC	SFL/B126E	SFL/B126EC
White	SFL/W126F	SFL/W126FC	SFL/W126E	SFL/W126EC
Titanium	SFL/X126F	SFL/X126FC	SFL/X126E	SFL/X126EC
Description	32W HF	32W HF PC	42W HF	42W HF PC
Black	SFL/B132E	SFL/B132EC	SFL/B142E	SFL/B142EC
White	SFL/W132E	SFL/W132E	SFL/W142E	SFL/W142EC
Titanium	SFL/X132E	SFL/X132EC	SFL/X142E	SFL/X142EC

SMART FLOOD sign extension

Description	400mm
Black	SLF/B4SE
White	SLF/W4SE
Titanium	SLF/X4SE



Lamp Types

- 13W/26W 3500K TC-D 4-Pin G24q-3 Cap.
- 32W/42W. 3500K TC-D 4Pin G24q-3 Cap.



PLEASE NOTE – Emergency and high frequency versions are all 4-Pin.

Materials

- Body: Vandal resistant polycarbonate self-extinguishing fire properties in black/white/titanium.
- Reflector: Asymmetric specular reflector.
- Diffuser: Clear vandal resistant polycarbonate.

Installation

- Cable gland entry.
- 3 way mains terminal block. 4 way terminal block for Photocell versions.
- Quick fix mounting bracket.
- Ratchet system on bracket.
- Innovative snap handles.
- Adjustable Stirrup bracket with angle dial.

Standards

- IP65.
- 'F' Mark.
- CE.
- BS EN 60598-2-1.
- Class I.



Specification Guideline

Low energy flood light . Polycarbonate case
In black/white/titanium. With _____
lamp wattage and _____ type control gear.
With optional _____

Options:

- Photocell Versions – add to code: **C**
- Tamper proof screws* - add to code: **T**