


Dynagrip **PRO** screwdriver range

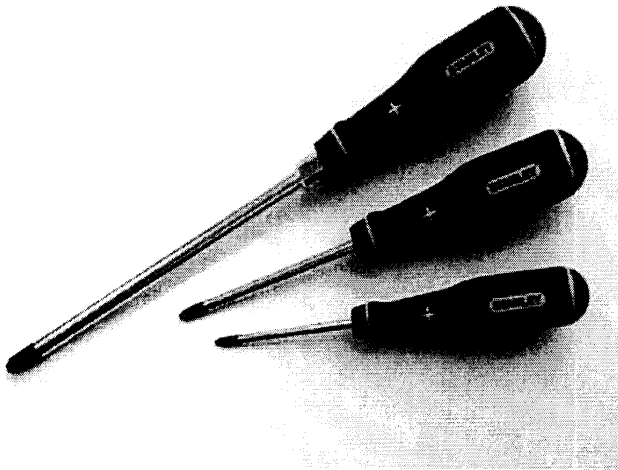

The ultimate Industrial quality screwdriver for strength, comfort, durability and value

Intensive End User research puts this screwdriver ahead of all its competitors

Features / Benefits

- Top quality steel bars, hardened and tempered to give the best tip performance
- Patented ergonomically designed bi-material handle for superb comfort in use over long periods, without compromising strength
 - shape and size created in conjunction with users to ensure most comfortable design IN USE
 - soft material has a diamond texture for best grip and thereby, most torque for least effort
 - tri-lobe shape reduces user fatigue - 120 deg. turn considered most comfortable - helps to prevent repetitive strain injury to the wrist and arm
 - patented permanent tip ID in design and colour code format to help quick user selection
- Handle moulded on to the bar in a way which makes the handle to bar torque the strongest on the market - the bar will never move in the handle
- Handle withstands impact beyond all worldwide standard requirements and is chemical resistant against most commonly used industrial and household solvents
- Bars are chrome plated for rust resistance and supplied with bolsters on larger tip sizes for additional torque to be applied if required
- Tips are shot blasted to prevent chrome damage / flake in use
- Broad range of bar lengths and tip types / sizes to address most user requirements.
- Unique package design gives feel-appeal and in-store security, PLUS it can be used as a permanent storage device