

# Specification




**IDEAL POWER**  
IDEAL POWER SOLUTIONS

**Model Name : AC 0812A**

Input Voltage	115 / 230Vac [ AUTO SW. ]
Input Frequency	47 ~ 63Hz
Max. In-rush Current	Cold start , 20A for 115Vac , 40A for 230Vac
Input Current	2.9A Max for 115Vac 1.45A Max for 230Vac
Output Voltage	14.6Vdc $\pm$ 0.2V ( Absorption Charge ) 13.7Vdc $\pm$ 0.2V ( Float Charge )
Start Point of Floating	1.0A $\pm$ 0.2A
Max. Charging Current	8A
Ripple / Noise	220mVp-p
FAN Control	Fan on fast speed ( Bulk / Absorption Charge ) Fan on slow speed ( Float Charge )
LED Indication	LED1 : RED LED $\rightarrow$ POWER ON LED2 : RED LED $\rightarrow$ CHARGING GREEN LED $\rightarrow$ FULL CHARGE
Dimensions	7.32 inch ( 186 mm ) Length 3.46 inch ( 88 mm ) Width 1.87 inch ( 47.5 mm ) Height
AC Power Cord	NAMA SVT 18AWG X3C



**IDEAL POWER**  
IDEAL POWER SOLUTIONS

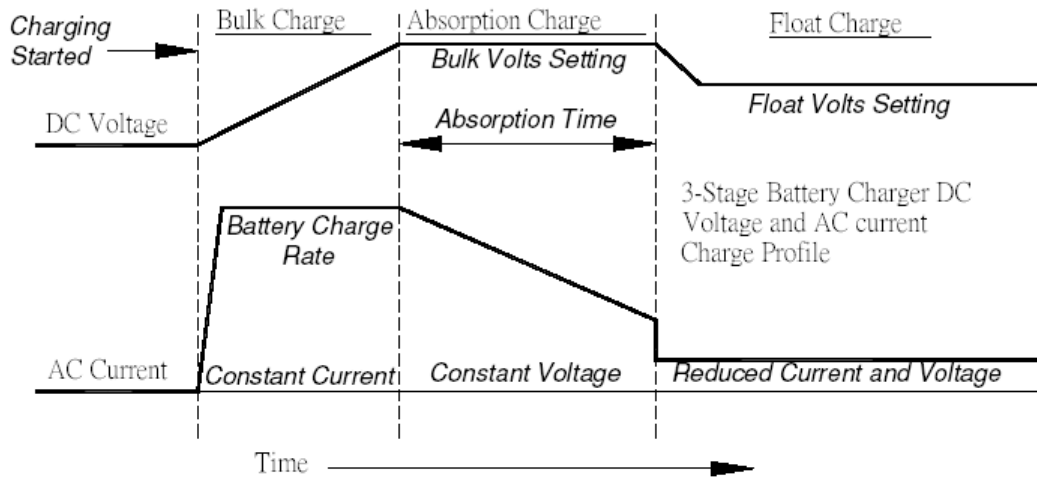

Case Drawing

Body View





**IDEAL POWER**  
IDEAL POWER SOLUTIONS

Front Panel



Rear Panel

